


Molded Case Circuit Breakers

External Accessories

Door-Mounted Operators

Section 3

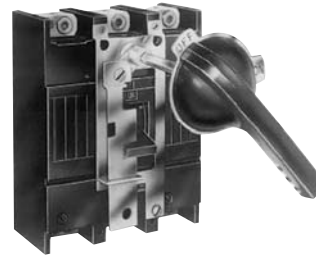

TDM Operating Handle, Fixed or Adjustable Shaft

TDM Handle Operating Mechanisms, Door Mounted

Complete mechanism with handle UL listed, E-57253

Operating mechanism only, UL Component Recognized, E-57253

| Breaker Type | Box Depth in Inches | Complete Mechanism ¹ with NEMA 1, 3R, 12 Handle | | Operating Mechanism Only | | Handle Only | | | |
|--------------------------------------|---|--|-------------------|--------------------------|-------------------|----------------|-------------------|-----------------------|-------------------|
| | | Product Number | List Price GO-144 | Product Number | List Price GO-144 | NEMA 1, 3R, 12 | | NEMA 4/4X | |
| | | | | | | Product Number | List Price GO-144 | Product Number | List Price GO-144 |
| TQD, THQD | Shallow Mount 3 7/16 | TQDHM1 | \$69.00 | TQDOM1 | \$42.00 | | | | |
| | Extended Shaft 4 5/16 - 14 5/16 | TQDHM2 | \$82.00 | TQDOM2 ² | \$55.00 | | | | |
| TEB, TEC, TB1, TED, THED | Shallow Mount 4 3/16 | TEFHM1 | \$69.00 | TEFOM1 | \$42.00 | | | | |
| | Extended Shaft 5 1/8 - 5 7/32 5 1/8 - 5 13/16 5 1/8 - 15 | TEFHM3 | \$82.00 | TEFOM3 | \$55.00 | TH1 | \$27.00 | | |
| | | TEFHM4 | \$82.00 | TEFOM4 | \$55.00 | | | | |
| | | TEFHM2 | \$82.00 | TEFOM2 | \$55.00 | | | | |
| TFC, TFJ, TFK, THFK | Shallow Mount 5 7/8 | TFKHM1 | \$103.50 | TFKOM1 | \$76.50 | | | THCH45 ^{3,4} | \$303.00 |
| | Extended Shaft 6 7/8 - 15 1/2 | TFKHM2 | \$107.50 | TFKOM2 ² | \$80.50 | | | | |
| TJC, TJD, TJJ, TJK, THJK, TB4, TBC4 | Shallow Mount 5 7/8 | TJKHM1 | \$143.00 | TJKOM1 | \$102.00 | | | | |
| | Extended Shaft 5 5/8 - 15 5/8 | TJKHM2 | \$147.00 | TJKOM2 ⁴ | \$106.00 | TH2 | \$41.00 | | |
| TKC, TKM, THKM, TB6, TBC6, TB8, TBC8 | Shallow Mount 7 7/16 | TKMHM1 | \$143.00 | TKMOM1 | \$102.00 | | | | |
| | Extended Shaft 7 1/32 - 17 5/16 | TKMHM2 | \$147.00 | TKMOM2 ⁴ | \$106.00 | | | | |
| SE150 (GEH-5611) ⁵ | 4 3/16 | SEFHM1 | \$79.00 | SEFOM1 | \$52.00 | TH1 | \$7.00 | | |
| | 6 1/8 - 15 | SEFHM2 | \$81.50 | SEFOM2 ² | \$55.00 | | | | |
| SF250 (GEH-5611) ⁵ | 5 7/8 | SEFHM1 | \$79.00 | SEFOM1 | \$52.00 | | | THCH45 ^{3,4} | \$303.00 |
| | 7 3/4 - 15 1/2 | SEFHM2 | \$81.50 | SEFOM2 ² | \$55.00 | | | | |
| SG600 (GEH-5653) ⁵ | 5 7/8 | SGHM1 | \$143.00 | SGOM1 | \$102.00 | TH2 | \$41.00 | | |
| | 5 5/8 - 15 5/8 | SGHM2 | \$147.00 | SGOM2 ⁴ | \$106.00 | | | | |
| SK1200 (GEH-5612) ⁵ | 6 | SKHM1 | \$143.00 | SKOM1 | \$102.00 | | | | |
| | 7 | SKHM2 | \$147.00 | SKOM2 ⁴ | \$106.00 | | | | |

¹Handle assembly and operating mechanism separately packaged.

²For 15-inch long shaft order Product Number 788A831G10, List Price \$40.00, GO-135B. For 20-inch long shaft order Product Number 788A831G21 List Price \$40.00, GO-135B.

³Provides interlocking for J600, SG600 SK1200, and K1200 breakers when used with the extended shaft operating mechanism. For interlocking with E150/SE150, F225 and SF250 order special shaft Product Number 788A832G1, List Price \$40.00, GO-135B.

⁴For 15-inch long shaft order Product Number 788A832G2, List Price \$40.00, GO-135B. For 20-inch long shaft order Product Number 788A832G5, List Price \$40.00, GO-135B.

⁵Installation instructions publication number.

⁶MOD 1 is 7 7/16; MOD 2 is 8 3/32.

⁷MOD 1 is 7 3/16 - 17 3/16; MOD 2 is 7 15/16 - 17 15/16.

Handle Accessories for TDM Operating Mechanisms

| Device | Product Number | List Price GO-139 |
|---|----------------|-------------------|
| Replacement neoprene gaskets for NEMA 1, 3R and 12 enclosures | | |
| Use with TH1 | 788A742P3 | \$2.80 |
| Use with TH2 | 788A742P4 | \$6.10 |

