

JUNO® lighting

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

TRAC-LITES FLARED STEP SERIES R551 and R552

PRODUCT DESCRIPTION


Construction Drawn steel housing.

Socket Medium base porcelain socket with nickel plated copper screw shell.

Aiming 90° vertical aiming capability and 358° rotation.


Adaptor Copper alloy contacts provide precise spring action • True, positive electrical ground • On/off switch included • Patented embossed polarity arrows on bottom of adaptor • Spring-loaded locking latch with embossed polarity arrows secures trac light to trac • "Pull-up" contact to up position for use on two-circuit trac.

Labels UL/CUL listed.

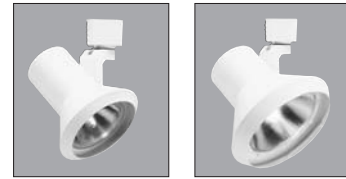

Line Voltage PAR20

Catalog Number	Finish	Lamp
R551WH	White	50W PAR20
R551BL	Black	50W PAR20
R551SC	Satin Chrome	50W PAR20

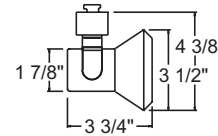

Line Voltage PAR30

Catalog Number	Finish	Lamp
R552WH	White	75W PAR30
R552BL	Black	75W PAR30
R552SC	Satin Chrome	75W PAR30

