


NEMA 1 ENCLOSURES

1100 covers




Hinged Flush Cover

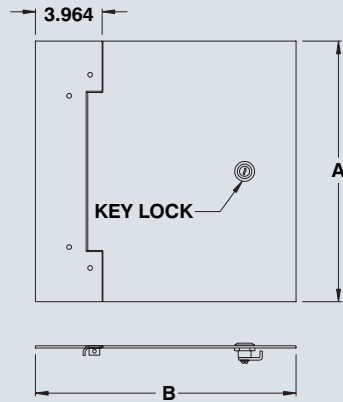


CATALOG NUMBER	DIMENSIONS		SHIP WGHT LBS.	CATALOG NUMBER	DIMENSIONS		SHIP WGHT LBS.
	A	B			A	B	
1100 HCF0606	9.5	9.5	2	1100 HCF1818	21.5	21.5	10
1100 HCF0806	11.5	9.5	3	1100 HCF2016	23.5	19.5	9
1100 HCF0808	11.5	11.5	3	1100 HCF2020	23.5	23.5	11
1100 HCF1008	13.5	11.5	3	1100 HCF2418	27.5	21.5	11
1100 HCF1010	13.5	13.5	4	1100 HCF2420	27.5	23.5	13
1100 HCF1206	15.5	9.5	4	1100 HCF2424	27.5	27.5	15
1100 HCF1208	15.5	11.5	4	1100 HCF3020	33.5	23.5	16
1100 HCF1210	15.5	13.5	5	1100 HCF3024	33.5	27.5	18
1100 HCF1212	15.5	15.5	5	1100 HCF3030	33.5	33.5	22
1100 HCF1512	18.5	15.5	6	1100 HCF3624	39.5	27.5	21
1100 HCF1515	18.8	18.5	7	1100 HCF3630	39.5	33.5	26
1100 HCF1612	19.5	15.5	7	1100 HCF3636	39.5	39.5	30
1100 HCF1616	19.5	19.5	8	1100 HCF4830	51.5	33.5	33
1100 HCF1812	21.5	15.5	7	1100 HCF4836	51.5	39.5	39
1100 HCF1815	21.5	18.5	8	1100 HCF4848	51.5	51.5	51

Hinged Surface Cover

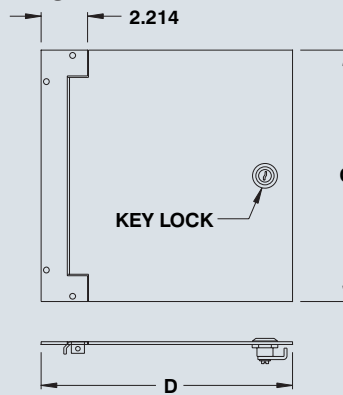


CATALOG NUMBER	DIMENSIONS		SHIP WGHT LBS.	CATALOG NUMBER	DIMENSIONS		SHIP WGHT LBS.
	C	D			C	D	
1100 HCS0606	6	6	1	1100 HCS1818	18	18	6
1100 HCS0806	8	6	1	1100 HCS2016	20	16	6
1100 HCS0808	8	8	1	1100 HCS2020	20	20	7
1100 HCS1008	10	8	1	1100 HCS2418	24	18	8
1100 HCS1010	10	10	2	1100 HCS2420	24	20	9
1100 HCS1206	12	6	1	1100 HCS2424	24	24	11
1100 HCS1208	12	8	2	1100 HCS3020	30	20	11
1100 HCS1210	12	10	2	1100 HCS3024	30	24	13
1100 HCS1212	12	12	3	1100 HCS3030	30	30	17
1100 HCS1512	15	12	3	1100 HCS3624	36	24	16
1100 HCS1515	15	15	4	1100 HCS3630	36	30	20
1100 HCS1612	16	12	4	1100 HCS3636	36	36	24
1100 HCS1616	16	16	5	1100 HCS4830	48	30	27
1100 HCS1812	18	12	4	1100 HCS4836	48	36	32
1100 HCS1815	18	15	5	1100 HCS4848	48	48	43

Screw-on Flush Cover

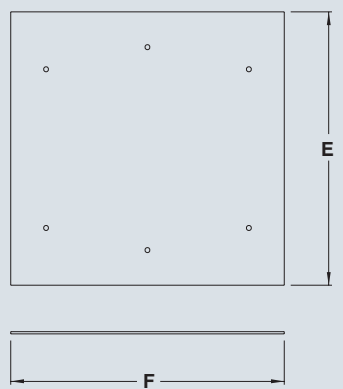

CATALOG NUMBER	DIMENSIONS		SHIP WGHT LBS.	CATALOG NUMBER	DIMENSIONS		SHIP WGHT LBS.
	E	F			E	F	
1100 FCD0606	9.5	9.5	2	1100 FCD1818	21.5	21.5	10
1100 FCD0806	11.5	9.5	3	1100 FCD2016	23.5	19.5	9
1100 FCD0808	11.5	11.5	3	1100 FCD2020	23.5	23.5	11
1100 FCD1008	13.5	11.5	3	1100 FCD2418	27.5	21.5	11
1100 FCD1010	13.5	13.5	4	1100 FCD2420	27.5	23.5	13
1100 FCD1206	15.5	9.5	4	1100 FCD2424	27.5	27.5	15
1100 FCD1208	15.5	11.5	4	1100 FCD3020	33.5	23.5	16
1100 FCD1210	15.5	13.5	5	1100 FCD3024	33.5	27.5	18
1100 FCD1212	15.5	15.5	5	1100 FCD3030	33.5	33.5	22
1100 FCD1512	18.5	15.5	6	1100 FCD3624	39.5	27.5	21
1100 FCD1515	18.8	18.5	7	1100 FCD3630	39.5	33.5	26
1100 FCD1612	19.5	15.5	7	1100 FCD3636	39.5	39.5	30
1100 FCD1616	19.5	19.5	8	1100 FCD4830	51.5	33.5	33
1100 FCD1812	21.5	15.5	7	1100 FCD4836	51.5	39.5	39
1100 FCD1815	21.5	18.5	8	1100 FCD4848	51.5	51.5	51

Wood Panel

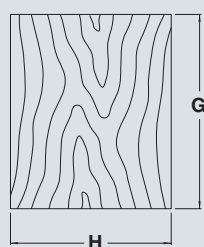

CATALOG NUMBER	DIMENSIONS		SHIP WGHT LBS.	CATALOG NUMBER	DIMENSIONS		SHIP WGHT LBS.
	G	H			G	H	
881 WP1212	7	10.750	1	881 WP3624	31	22.750	10
881 WP1812	13	10.750	2	881 WP3630	31	28.750	13
881 WP1818	13	16.750	3	881 WP3636	31	34.750	16
881 WP2418	19	16.750	5	881 WP4830	43	28.750	16
881 WP2424	19	22.750	6	881 WP4836	43	34.750	22
881 WP3024	25	22.750	8	881 WP4848	43	44.750	29
881 WP3030	25	28.750	11				

Data subject to change without notice.