

wall mounted master control



- controls up to eight dimmers/lighting zones of all load types
- 5 preset scenes plus off
- rocker for raise/lower
- IR receiver for remote control
- when using 120V and 277V products in the same backbox, use 600V rated cable (follow NEC standards) see application note #133

5-scene master control*


wall mounted

SPS-5WC-

wall mounted master control with IR blasters



- same features as above
- controls up to *four* dimmers/lighting zones of all load types per blaster
- requires two traveler wires between master control and IR blasters

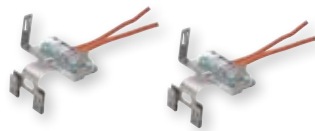

remote 5-scene master control with two IR blasters*

wall mounted

SPS-5WCR-

* requires neutral wire connection

SPS-5WC- must be ganged in the same continuous backbox with Spacer System® dimmers; its IR signal travels *within the backbox* to four dimmers in either direction. Remote-mounted SPS-5WCR- talks to Spacer System® dimmers via IR blasters (two included). IR blasters clip to the dimmer backbox and emit IR signals for up to two dimmers in either direction.

See page 115 for available colors.

To order, add color suffix to model number.
Example: **SPS-5WC- WH**

dimmers with IR receiver



- tap on to favorite level; tap off
- touch rocker to adjust light level
- tap twice for full on
- press, hold and release for delayed fade-to-off
- provides true dimming from each location (with companion dimmers)

incandescent/halogen†

| | | |
|-----------------|--------|-------------------|
| single-location | 600 W | SPS-600- |
| single-location | 1000 W | SPS-1000- |
| multi-location | 600 W | SPS-600M- |
| multi-location | 1000 W | SPS-1000M- |

magnetic low-voltage†

| | | |
|-----------------|--------------------|---------------------|
| single-location | 600 VA (450 W) | SPSLV-600- |
| single-location | 1000 VA (800 W) | SPSLV-1000- |
| multi-location | 600 VA (450 W) | SPSLV-600M- |
| multi-location | 1000 VA (800 W) | SPSLV-1000M- |


Suggested maximum lighting load for magnetic low-voltage dimming is 450W for 600VA products and 800W for 1000VA products, to allow for transformer losses.

electronic low-voltage*

| | | |
|-----------------|-------|---------------------|
| single-location | 600 W | SPSELV-600- |
| multi-location | 600 W | SPSELV-600M- |

* requires neutral wire connection

† minimum load is 60 W

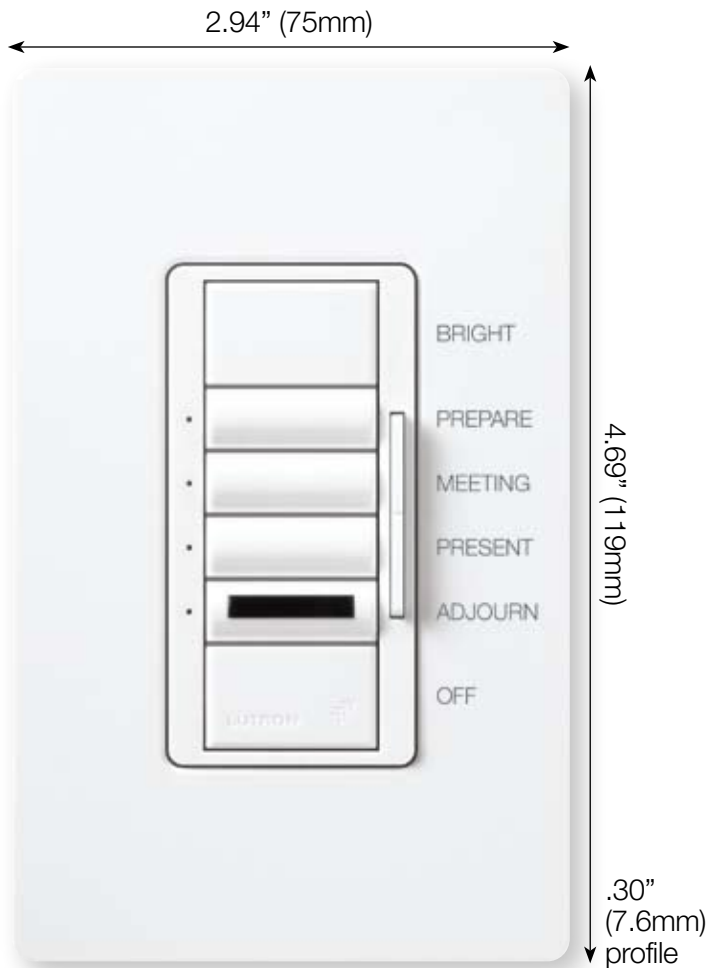

Shown actual size: Spacer System® 5-scene wall mounted master and 1-gang Claro® wallplate with custom engraving in white (WH)



product family features

- true multi-location dimming from each location
- tap dimmer on to favorite level; tap off; tap dimmer twice for full on
- touch rocker to adjust light level
- delayed off provides light as you exit the room
- line frequency compensation maintains stable light
- coordinating Claro® wallplates and accessories available separately (including stainless steel)
- IR remote control convenience
- install with standard wiring – replace existing switches or dimmers
- perfect for restaurants, conference rooms, great rooms, master bathrooms, home gyms, dining areas, and home theaters

available models

source type

- incandescent/halogen lighting
- magnetic low-voltage lighting
- electronic low-voltage lighting
- LED lighting
- fluorescent lighting

control locations

- single pole (one location)
- multi-location dimming (up to nine locations)

available colors (see page 12 for color swatches)

colors (gloss finish)

- | | |
|------------------------|-----------------|
| WH white | GR gray |
| IV ivory | BR brown |
| AL almond | BL black |
| LA light almond | |

Questions on installation or selection?
Call Lutron® 24 hours/7 days a week at
1.800.523.9466 or visit www.lutron.com

CAD file downloads available at
www.lutron.com/cad



1.51" (38mm) wide
4.63" (118mm) high
0.55" (14mm) deep

Shown: Spacer System® 4-scene remote control IR transmitter in royal plum (RP)