

Decorator Standard Grade Receptacles

2P3W Grounding
15A 125V



INDUSTRIAL
COMMERCIAL
RESIDENTIAL

B-8 DECORATOR DEVICES

TESTING & CODE COMPLIANCE

- Meets all UL 498 requirements, (file no. E15058), Fed. Specs. WC-596G.
- CSA Certified, C22.2 no. 42.
- Standard Grade: (file no. 6914 (6233-01))
- NOM Certified

MATERIAL CHARACTERISTICS

Meets flammability requirements per UL94, V2 rated.
Temperature Rating:
Standard Grade
-40°C to 65°C.

Duplex Receptacles

FEATURES


- Longer, wider strap provides 40% more contact area to wall board. Virtually eliminates floating installations.
- Patented built-in wire stripper for #14 and #12 wire to speed installation.
- Patented built-in wire looper for pre-looping.
- Combination slot/Phillips head mounting and terminal screws ease installation with power screwdrivers. (Slot/Robertson screws in Canada where available).
- Terminal screws backed out – ready for wiring.
- Side wire terminals accept up to #10 solid or stranded wire.
- Push-in terminals accept #14 solid wire.

Side Wire and Push Wire

| Rating | | | | |
|--------|------|-------|--------------|-------------|
| A | V/AC | NEMA | Color | Catalog No. |
| 15 | 125 | 5-15R | Almond | 1107A |
| | | | Brown | 1107B |
| | | | Gray | 1107GY |
| | | | Ivory | 1107V |
| | | | Light Almond | 1107LA |
| | | | White | 1107W |

Automatic Grounding – Side Wire and Push Wire

| Rating | | | | |
|--------|------|-------|--------------|-------------|
| A | V/AC | NEMA | Color | Catalog No. |
| 15 | 125 | 5-15R | Almond | 1107-9A |
| | | | Black | 1107-9BK |
| | | | Brown | 1107-9B |
| | | | Gray | 1107-9GY |
| | | | Ivory | 1107-9V |
| | | | Light Almond | 1107-9LA |
| | | | White | 1107-9W |

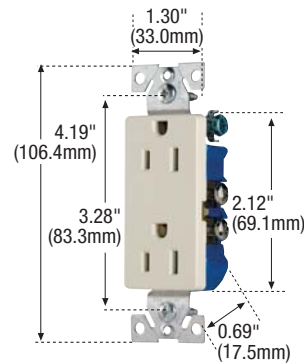

1107



5-15R