



# Decorator Industrial Specification Grade Stainless Steel Wallplates

Standard Size  
Mid-Size  
Oversize

INDUSTRIAL  
COMMERCIAL  
RESIDENTIAL

## B-11 DECORATOR DEVICES

### TESTING & CODE COMPLIANCE

- UL Listed, (file no. E92003)
- Meets current Federal Specifications as tested to UL 514
- Meets all CSA requirements, C22.2 no. 42.1, CSA (file no. 9294 (4413-02)).

### MATERIAL CHARACTERISTICS


Type 304 Stainless Steel, non-magnetic, 0.032" (0.81mm) nominal thickness. Contains 18% chromium and 8% nickel for superior corrosion resistance.

### Stainless Steel Wallplates


#### FEATURES

- All wallplates are of type 304 stainless steel alloy for superior non-magnetic corrosion-resistant properties.
- Plates are 0.032" (0.82mm) thick.
- Brushed satin finish resists finger marks.
- Mid-size wallplates are 0.375" (9.53mm) longer and wider than standard size to cover large wall board openings.
- Oversize wallplates are 0.750" (19.05mm) longer and wider than standard size to cover large wall board openings.
- Matching stainless steel mounting screws provided.

#### Standard Size

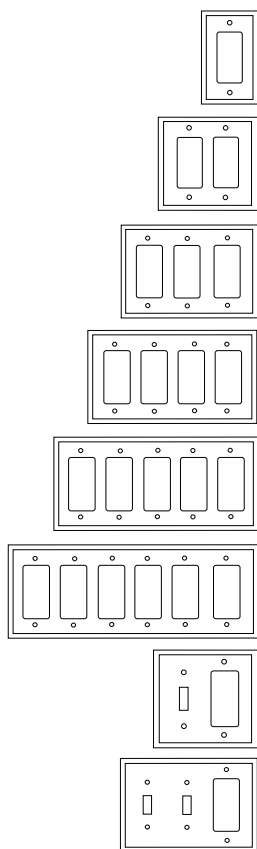

Description	Catalog No.		
	Standard	Mid-Size	Oversize
1 Gang	93401	93934	93834
2 Gang	93402	93935	—
3 Gang	93403	93936	—
4 Gang	93404	—	—
5 Gang	93405	—	—
6 Gang	93406	—	—
2 Gang Combination - Toggle and Decorator	93432	93937	—
3 Gang Combination - 2 Toggles and Decorator	93443	—	—

 

# Decorator Commercial Specification Grade Thermoplastic Wallplates

Standard Size

## Thermoplastic Wallplates

### FEATURES

- High impact-resistant; non-flammable, unbreakable thermoplastic.
- Screw-Catch™ feature holds plate mounting screw captive for ease of installation.
- Flush-fitting, warp-resistant design.
- Matching mounting screws provided.

INDUSTRIAL  
COMMERCIAL  
RESIDENTIAL

## B-13 DECORATOR DEVICES

### TESTING & CODE COMPLIANCE

- UL and cUL Listed, UL (file no. E33216)
- Meets current Federal Specifications as tested to UL 514
- Meets all CSA requirements, C22.2 no. 42.1, CSA (file no. 9294 (4413-02)).

### MATERIAL CHARACTERISTICS

 
Meets flammability requirements per UL 94, V2 rated.  
Temperature Rating:  
-40°C to 70°C.



### Standard Size


#### 1 Gang Decorator

Color	Catalog No.
Almond	5151A
Brown	5151B
Black	5151BK
Blue	5151BL
Gray	5151GY
Red	5151RD
Light Almond	5151LA
Ivory	5151V
White	5151W



#### 2 Gang Decorator

 Color	Catalog No.
Almond	5152A
Brown	5152B
Black	5152BK
Gray	5152GY
Ivory	5152V
Light Almond	5152LA
White	5152W



### Combination

#### 2 Gang Decorator/Toggle

Color	Catalog No.
Almond	5153A
Brown	5153B
Black	5153BK
Gray	5153GY
Ivory	5153V
Light Almond	5153LA
White	5153W

# Decorator Commercial Specification Grade Thermoplastic Wallplates

Mid-Size



INDUSTRIAL  
COMMERCIAL  
RESIDENTIAL

## B-14 DECORATOR DEVICES

### TESTING & CODE COMPLIANCE

- UL and cUL Listed, UL (file no. E33216)
- Meets current Federal Specifications as tested to UL 514
- Meets all CSA requirements, C22.2 no. 42.1, CSA (file no. 9294 (4413-02)).

### MATERIAL CHARACTERISTICS

Meets flammability requirements per UL 94, V2 rated.  
Temperature Rating:  
-40°C to 70°C.

 
## Thermoplastic Wallplates

### FEATURES

- Mid-Size wallplates are 0.375" (9.53mm) longer and wider on all sides than standard to cover large wallboard openings.
- Assures NEC®-required gap coverage for most wallboard-to-box openings.
- Virtually unbreakable polycarbonate construction = high structural rigidity, long-term form retention.
- Screw-Catch™ feature holds plate mounting screw captive for ease of installation.
- Superior abrasion and impact resistance.
- Color-matched mounting screws captive in 1 and 2 gang plates for faster installation – helps eliminate lost screws on the job.


### 1 Gang Decorator

Color	Catalog No.
Almond	PJ26A
Brown	PJ26B
Black	PJ26BK
Blue	PJ26BL
Gray	PJ26GY
Red	PJ26RD
Ivory	PJ26V
Light Almond	PJ26LA
White	PJ26W



### 2 Gang Decorator

 Color	Catalog No.
Almond	PJ262A
Brown	PJ262B
Black	PJ262BK
Blue	PJ262BL
Gray	PJ262GY
Orange	PJ262RN
Red	PJ262RD
Ivory	PJ262V
Light Almond	PJ262LA
White	PJ262W



### 3 Gang Decorator

Color	Catalog No.
Almond	PJ263A
Brown	PJ263B
Black	PJ263BK
Gray	PJ263GY
Ivory	PJ263V
Light Almond	PJ263LA
White	PJ263W

