



Decorator Industrial Specification Grade Stainless Steel Wallplates

Standard Size
Mid-Size
Oversize

INDUSTRIAL
COMMERCIAL
RESIDENTIAL

B-11 DECORATOR DEVICES

TESTING & CODE COMPLIANCE

- UL Listed, (file no. E92003)
- Meets current Federal Specifications as tested to UL 514
- Meets all CSA requirements, C22.2 no. 42.1, CSA (file no. 9294 (4413-02)).

MATERIAL CHARACTERISTICS


Type 304 Stainless Steel, non-magnetic, 0.032" (0.81mm) nominal thickness. Contains 18% chromium and 8% nickel for superior corrosion resistance.

Stainless Steel Wallplates


FEATURES

- All wallplates are of type 304 stainless steel alloy for superior non-magnetic corrosion-resistant properties.
- Plates are 0.032" (0.82mm) thick.
- Brushed satin finish resists finger marks.
- Mid-size wallplates are 0.375" (9.53mm) longer and wider than standard size to cover large wall board openings.
- Oversize wallplates are 0.750" (19.05mm) longer and wider than standard size to cover large wall board openings.
- Matching stainless steel mounting screws provided.

Standard Size

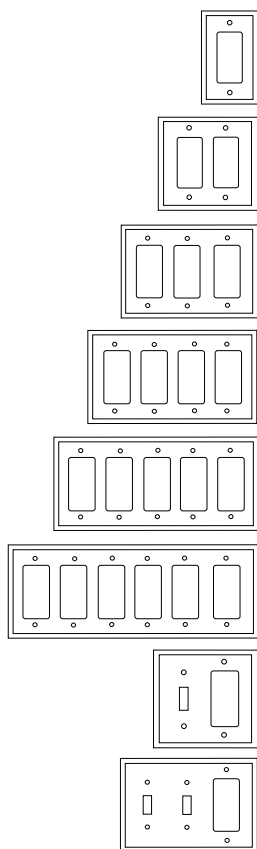

| Description | Catalog No. | | |
|--|-------------|----------|----------|
| | Standard | Mid-Size | Oversize |
| 1 Gang | 93401 | 93934 | 93834 |
| 2 Gang | 93402 | 93935 | — |
| 3 Gang | 93403 | 93936 | — |
| 4 Gang | 93404 | — | — |
| 5 Gang | 93405 | — | — |
| 6 Gang | 93406 | — | — |
| 2 Gang Combination - Toggle and Decorator | 93432 | 93937 | — |
| 3 Gang Combination - 2 Toggles and Decorator | 93443 | — | — |

 

Decorator Commercial Specification Grade Thermoplastic Wallplates

Standard Size

Thermoplastic Wallplates

FEATURES

- High impact-resistant; non-flammable, unbreakable thermoplastic.
- Screw-Catch™ feature holds plate mounting screw captive for ease of installation.
- Flush-fitting, warp-resistant design.
- Matching mounting screws provided.

INDUSTRIAL
COMMERCIAL
RESIDENTIAL

 
B-13 DECORATOR DEVICES

TESTING & CODE COMPLIANCE

- UL and cUL Listed, UL (file no. E33216)
- Meets current Federal Specifications as tested to UL 514
- Meets all CSA requirements, C22.2 no. 42.1, CSA (file no. 9294 (4413-02)).

MATERIAL CHARACTERISTICS


Meets flammability requirements per UL 94, V2 rated.
Temperature Rating:
-40°C to 70°C.



Standard Size


1 Gang Decorator

| Color | Catalog No. |
|--------------|-------------|
| Almond | 5151A |
| Brown | 5151B |
| Black | 5151BK |
| Blue | 5151BL |
| Gray | 5151GY |
| Red | 5151RD |
| Light Almond | 5151LA |
| Ivory | 5151V |
| White | 5151W |

 

2 Gang Decorator

| Color | Catalog No. |
|--------------|-------------|
| Almond | 5152A |
| Brown | 5152B |
| Black | 5152BK |
| Gray | 5152GY |
| Ivory | 5152V |
| Light Almond | 5152LA |
| White | 5152W |

 

Combination

2 Gang Decorator/Toggle

| Color | Catalog No. |
|--------------|-------------|
| Almond | 5153A |
| Brown | 5153B |
| Black | 5153BK |
| Gray | 5153GY |
| Ivory | 5153V |
| Light Almond | 5153LA |
| White | 5153W |

Decorator Commercial Specification Grade Thermoplastic Wallplates

Mid-Size



INDUSTRIAL
COMMERCIAL
RESIDENTIAL

B-14 DECORATOR DEVICES

TESTING & CODE COMPLIANCE

- UL and cUL Listed, UL (file no. E33216)
- Meets current Federal Specifications as tested to UL 514
- Meets all CSA requirements, C22.2 no. 42.1, CSA (file no. 9294 (4413-02)).

MATERIAL CHARACTERISTICS

Meets flammability requirements per UL 94, V2 rated.
Temperature Rating:
-40°C to 70°C.


Thermoplastic Wallplates

FEATURES

- Mid-Size wallplates are 0.375" (9.53mm) longer and wider on all sides than standard to cover large wallboard openings.
- Assures NEC®-required gap coverage for most wallboard-to-box openings.
- Virtually unbreakable polycarbonate construction = high structural rigidity, long-term form retention.
- Screw-Catch™ feature holds plate mounting screw captive for ease of installation.
- Superior abrasion and impact resistance.
- Color-matched mounting screws captive in 1 and 2 gang plates for faster installation – helps eliminate lost screws on the job.


1 Gang Decorator

| Color | Catalog No. |
|--------------|-------------|
| Almond | PJ26A |
| Brown | PJ26B |
| Black | PJ26BK |
| Blue | PJ26BL |
| Gray | PJ26GY |
| Red | PJ26RD |
| Ivory | PJ26V |
| Light Almond | PJ26LA |
| White | PJ26W |

 

2 Gang Decorator

| Color | Catalog No. |
|--------------|-------------|
| Almond | PJ262A |
| Brown | PJ262B |
| Black | PJ262BK |
| Blue | PJ262BL |
| Gray | PJ262GY |
| Orange | PJ262RN |
| Red | PJ262RD |
| Ivory | PJ262V |
| Light Almond | PJ262LA |
| White | PJ262W |

 

3 Gang Decorator

| Color | Catalog No. |
|--------------|-------------|
| Almond | PJ263A |
| Brown | PJ263B |
| Black | PJ263BK |
| Gray | PJ263GY |
| Ivory | PJ263V |
| Light Almond | PJ263LA |
| White | PJ263W |

