

# DH-PLZ20C0-D

## 12 MegaPixel 4K Lens




## Specifications

Model		DH-PLZ20C0-D
Parameter		
Image format		1/1.7"
Focal length		3.7-16mm
Aperture		F1.5
Field Angle		W:145° x109° x79° T: 35.6° x28.5° x21.4°
M.O.D.		0.5m
TV Distortion		-30%(Wide)
IR Correction		Yes
Lens Control	Focus	Manual
	Zoom	Manual
	Iris	DC-Iris
Mount		CS
Dimension		ø54x82.8mm
Weight		270g
Operating temperature		-30℃ ~ +70℃

# DH-PLZ20C0-D

## Dimensions (mm)

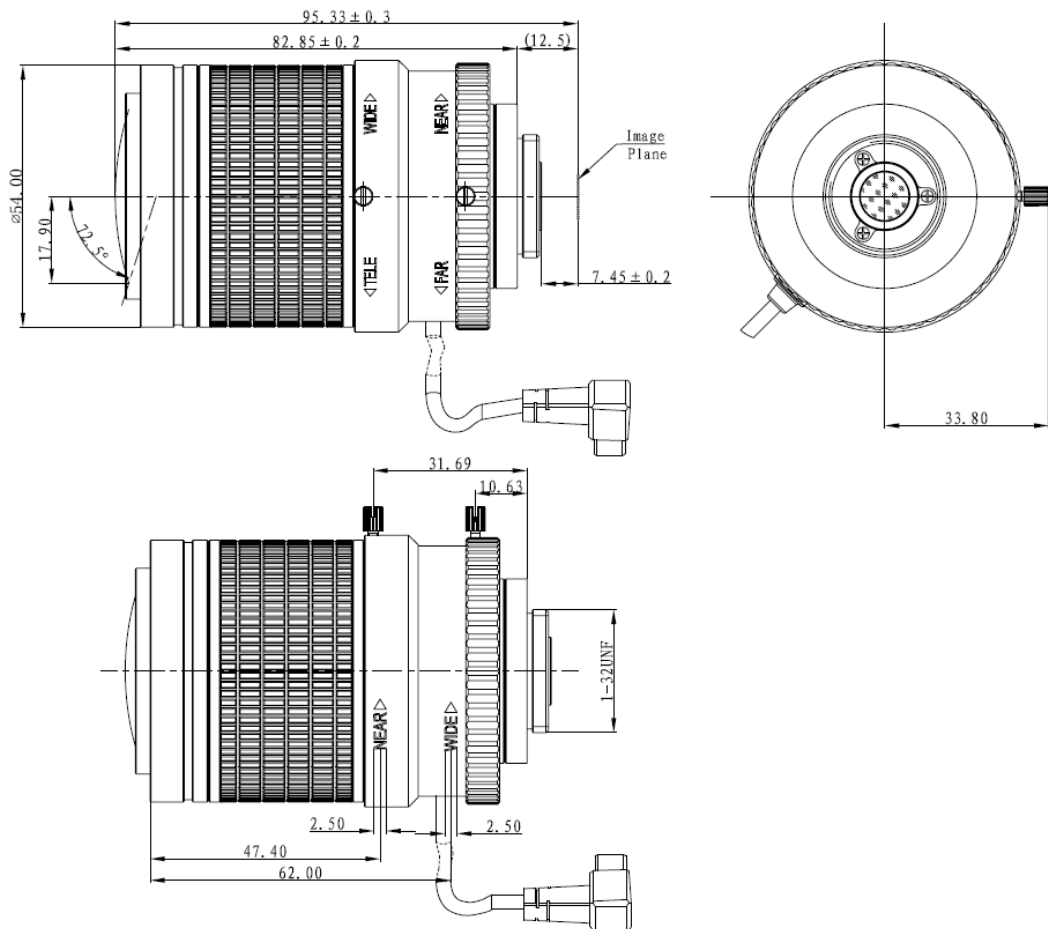

### Dahua Technology Co., Ltd.

1199 BinAn Road, Binjiang District, Hangzhou, China

Tel: +86-571-87688883

Fax: +86-571-87688815

Email: [overseas@dahuatech.com](mailto:overseas@dahuatech.com)

[www.dahuasecurity.com](http://www.dahuasecurity.com)

\*Design and specifications are subject to change without notice.

© 2014 Dahua Technology Co., Ltd.