

2-115-T Aqua GU10



The small-aperture Aqua brings surprising performance and excellent glare control to wet locations. The fixture is a die cast trim which offers performance, versatility and excellent glare control. The Aqua trim features a silicone sealed glass lens.

FEATURES

- Utilizes GU10
- Wet location listed
- 35° aiming
- Die-cast aluminum fixture
- Powder coated and plated trim ring finishes
- Trim clips designed for 5/8" ceiling thickness
- Trimless version available (see separate specifications)

DETAILS


Trim Class: 4"
Category: Recessed Downlight
Shape: Round
Adjustability: Aiming




2-115-T-Aqua-GU10-Specs • Subject to change without notice • Rev 2017.01.13 • 1/4

Features & Lighting

DIMENSIONS

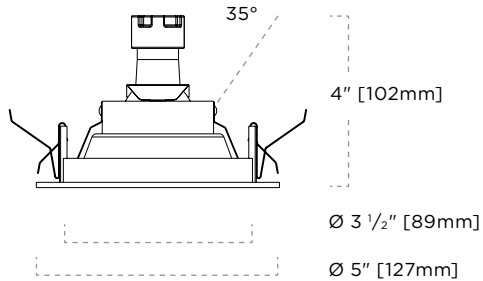

CEILING CUTOUT

 

FLANGE FINISHES

- White
- Chrome Plated
- Black
- Matte Silver
- Bronze
- Matte Nickel

GLASS

- Frosted
- Clear

2-115-T Aqua GU10

Project

Type

Notes

Product Code

1 2 3 4

1. Trim

2-115-T Aqua

2. Lamp

GU10 Halogen

3. Flange Finish

01 White

02 Chrome Plated

04 Black

05 Matte Silver

06 Bronze

11 Matte Nickel

CC Custom Color ¹

4. Glass

C Clear Glass ²

F Frosted Glass ³

Notes

¹ **CC** custom color requires consultation with Lightheaded sales personnel.

² **C** clear glass reflector color is painted to match trim finish.

³ **F** frosted glass requires all reflectors painted white.

2-115-T-Aqua-GU10-Specs • Subject to change without notice • Rev 2017.01.13 • 4/4