

2-182-T Flare Wall Wash XTM



Flare's lens, kicker, and baffle are engineered to work in concert to provide uniform vertical illumination. Smoothly washed walls build a hierarchy of brightnesses and visually invite occupants to venture further into the space. Flare is ideal for wall washing or grazing applications. The Xicato module produces a light consistency within 2 SDCM (MacAdam Ellipse).

FEATURES

- Utilizes Xicato XTM LED
- Lumen output: 700-2700
- Die-cast aluminum fixture
- Powder coated ring finishes
- Ideal spacing 30" on center and 24" away from the wall
- Trim clips designed for 5/8" ceiling thickness
- L80 @ 50,000 hours
- Trimless version available (see separate specifications)

DETAILS


Trim Class: 4"
Category: Recessed Downlight
Shape: Round
Adjustability: Wall Wash




2-182-T-Flare-Wall-Wash-XTM-Specs • Subject to change without notice • Rev. 2017.07.06 • 1/5

Features & Lighting


3 SERIES

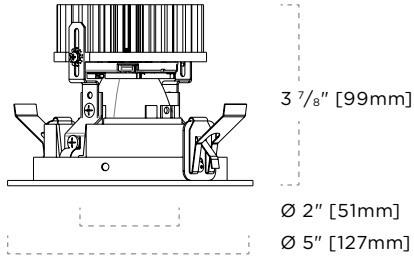


5, 7 & 9 SERIES

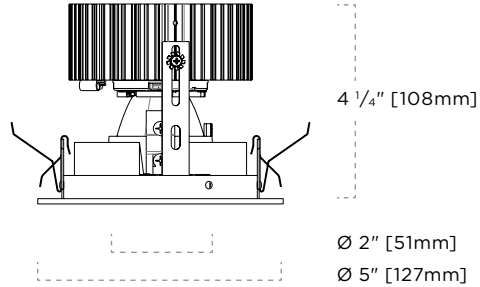

CEILING CUTOUT

 

BEAM SPREADS

 

FLANGE FINISHES

- White
- Black
- Matte Silver
- Bronze
- Matte Nickel

COLOR TEMPERATURES

- 2700
- 2700 Beauty
- 3000
- 3000 Vibrant
- 3500
- 4000

CRI & LUMENS

SERIES	3		5		7		9	
CRI VALUE	83	98	83	98	83	98	83	98
LUMEN OUTPUT	1000	700	1500	1000	2000	1300	2700	2100
LED WATTAGE	10	9	14	12	20	17	24	24
TITLE 24	—	24	—	24	—	—	—	—

2-182-T-Flare-Wall-Wash-XTM-Specs • Subject to change without notice • Rev. 2017.07.06 • 2/5

2-182-T Flare Wall Wash XTM

Project

Type

Notes

Product Code

1 2 3 4 5 6

1. Trim

2-182-T Flare Wall Wash

2. Flange Finish

01 White

04 Black

05 Matte Silver

06 Bronze

11 Matte Nickel

CC Custom Color ¹

3. Module & Beam Spread

XTM40 40° Beam

4. Color Temperature

27 2700K

30 3000K

35 3500K

40 4000K

BM27 Beauty 2700K ²

VB30 Vibrant 3000K

5. CRI, Lumens, Series

8310 83 CRI, 1000 lm, 3 Series

9807 98 CRI, 700 lm, 3 Series

8315 83 CRI, 1500 lm, 5 Series

9810 98 CRI, 1000 lm, 5 Series

8320 83 CRI, 2000 lm, 7 Series

9813 98 CRI, 1300 lm, 7 Series

8327 83 CRI, 2700 lm, 9 Series

9821 98 CRI, 2100 lm, 9 Series

6. Options

EXT Extension Clips (Maximum 2")

WB White Baffle ³

WK White Kicker ⁴

Notes

¹ **CC** custom color requires consultation with Lightheaded sales personnel.

² **BM27** beauty color temperature is only available in **9807, 9810, 9813**.

³ **WB** white baffle. Baffle is painted black standard.

⁴ **WK** white kicker. Standard kicker is painted to match trim finish.

2-182-T-Flare-Wall-Wash-XTM-Specs • Subject to change without notice • Rev. 2017.07.06 • 5/5