

2-520-T Miro XTM



Miro's light source is deeply regressed above the square reflector, cutting off glare from the lamp but opening possibilities for interest in the aperture. Select beam spreads, reflector finishes, and trim color for optimal effect. The Xicato module produces a light consistency within 2 SDCM (MacAdam Ellipse).

FEATURES

- Utilizes Xicato XTM LED
- Lumen output: 700-2700
- 20° adjustable aiming (3 series)
- Die-cast aluminum fixture
- Powder coated and plated trim ring finishes
- Trim clips designed for 5/8" ceiling thickness
- Accepts up to 2 optional media
- L80 @ 50,000 hours
- Trimless version available (see separate specifications)

DETAILS


Trim Class: 4"
Category: Recessed Downlight
Shape: Square
Adjustability: Aiming




2-520-T-Miro-XTM-Specs • Subject to change without notice • Rev 2016.12.19 • 1/6

Features & Lighting

3 SERIES

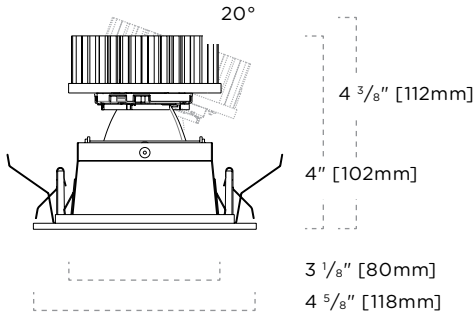


5, 7 & 9 SERIES

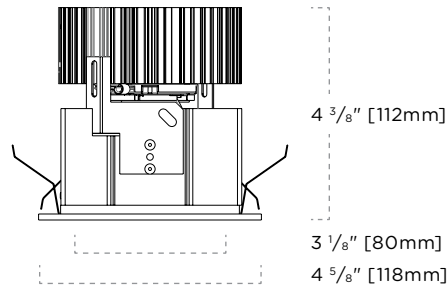


24 TITLE 24 COMPLIANT

 CEILING CUTOUT



BEAM SPREADS

 

FLANGE FINISHES

- White
- Chrome Plated
- Black
- Matte Silver
- Bronze
- Matte Nickel

REFLECTOR FINISHES

- 24 Black Open
- 24 Silver Specular
- 24 Silver Satin
- 24 White Open

COLOR TEMPERATURES

- 2700 24
- 2700 Beauty 24
- 3000 24
- 3000 Vibrant 24
- 3500 24
- 4000 24

CRI & LUMENS

SERIES	3		5		7		9	
CRI VALUE	83	98	83	98	83	98	83	98
LUMEN OUTPUT	1000	700	1500	1000	2000	1300	2700	2100
LED WATTAGE	10	9	14	12	20	17	24	24
TITLE 24	—	24	—	24	—	—	—	—

2-520-T Miro XTM

Project

Type

Notes

Product Code

1 2 3 4 5 6 7 8

1. Trim

2-520-T Miro

2. Flange Finish

- 01** White
- 02** Chrome Plated
- 04** Black
- 05** Matte Silver
- 06** Bronze
- 11** Matte Nickel
- CC** Custom Color ¹

3. Reflector Finish

- BLO** Black Open ²
- SA** Silver Specular ²
- SAS** Satin Silver ²
- WHO** White Open ³

4. Module & Beam Spread

- XTM28** 28° Beam
- XTM40** 40° Beam
- XTM60** 60° Beam

5. Color Temperature

- 27** 2700K
- 30** 3000K
- 35** 3500K
- 40** 4000K
- BM27** Beauty 2700K ⁴
- VB30** Vibrant 3000K

6. CRI, Lumens, Series

- 8310** 83 CRI, 1000 lm, 3 Series
- 9807** 98 CRI, 700 lm, 3 Series
- 8315** 83 CRI, 1500 lm, 5 Series
- 9810** 98 CRI, 1000 lm, 5 Series ⁵
- 8320** 83 CRI, 2000 lm, 7 Series
- 9813** 98 CRI, 1300 lm, 7 Series
- 8327** 80 CRI, 2700 lm, 9 Series
- 9821** 98 CRI, 2100 lm, 9 Series

7. Optional Media (2 Maximum)

- CL** Clear
- EL** Elongating
- FRO** Frosted
- HC** Honeycomb
- PER** Perimeter Frosted
- SL** Solite Softening
- SPDL** Spread

8. Options

- EXT** Extension Clips (Maximum 2")

Notes

¹ **CC** custom color requires consultation with Lightheaded sales personnel.

² Reflector finishes lamp holder is painted black standard.

³ **WHO** reflector finish lamp holder is painted white standard.

⁴ **BM27** beauty color temperature is only available in **9807, 9810, 9813**.

⁵ When selecting a housing, 5 series L, LE and LH dimming is not available in Title 24.