

2-500-T Quadra BRO



A clear modern aesthetic shines through in the Quadra family of square-aperture recessed downlights. Quadra was integrally engineered for multiple lamping options, including LED, to ensure ultra-low glare from the deeply regressed light source. The Bridgelux module produces a light consistency within 3 SDCM (MacAdam Ellipse).

FEATURES

- Utilizes Bridgelux LED
- Lumen output: 800-3000
- Clear lens standard
- Die-cast aluminum fixture
- Powder coated and plated trim ring finishes
- Trim clips designed for 5/8" ceiling thickness
- Accepts up to 2 optional media
- L70 @ 50,000 hours

DETAILS


Trim Class: 4"
Category: Recessed Downlight
Shape: Square
Adjustability: Fixed




2-500-T-Quadra-BRO-Specs • Subject to change without notice • Rev 2017.08.03 • 1/6

Features & Lighting

3 SERIES

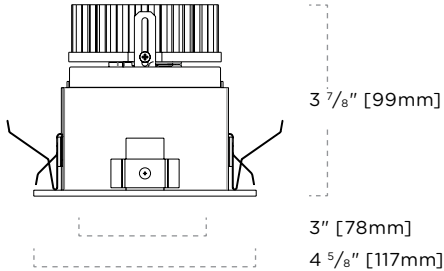


5 & 7 SERIES

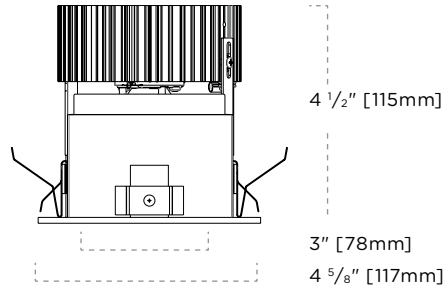


24 TITLE 24 COMPLIANT

 CEILING CUTOUT



BEAM SPREADS

 

FLANGE FINISHES

- White
- Chrome Plated
- Black
- Matte Silver
- Bronze
- Matte Nickel

COLOR TEMPERATURES

- 2700
- 3000
- 3500
- 4000

CRI & LUMENS

SERIES	3		5		7		9	
CRI VALUE	80	90	80	90	80	90	80	90
LUMEN OUTPUT	1000	800	1800	1400	2300	1800	3000	2300
LED WATTAGE	9	9	17	17	24	24	28	28
TITLE 24								

2-500-T Quadra BRO

Project

Type

Notes

Product Code

1 2 3 4 5 6 7

1. Trim

2-500-T Quadra

2. Flange Finish

- 01** White
- 02** Chrome Plated
- 04** Black
- 05** Matte Silver
- 06** Bronze
- 11** Matte Nickel
- CC** Custom Color ¹

3. Module & Beam Spread

- BRO20** 20° Beam
- BRO28** 28° Beam
- BRO40** 40° Beam

4. Color Temperature

- 27** 2700K
- 30** 3000K
- 35** 3500K ²
- 40** 4000K ²

5. CRI, Lumens, Series

- 8010** 80 CRI, 1000 lm, 3 Series
- 9008** 90 CRI, 800 lm, 3 Series
- 8018** 80 CRI, 1800 lm, 5 Series
- 9014** 90 CRI, 1400 lm, 5 Series
- 8023** 80 CRI, 2300 lm, 7 Series
- 9018** 90 CRI, 1800 lm, 7 Series
- 8030** 80 CRI, 3000 lm, 9 Series
- 9023** 90 CRI, 2300 lm, 9 Series

6. Optional Media (2 Maximum)

- EL** Elongating
- FRO** Frosted
- HC** Honeycomb
- PER** Perimeter Frosted
- SL** Solite Softening
- SPDL** Spread

7. Options

- WP** White Painted Interior ³

Notes

¹ **CC** custom color requires consultation with Lightheaded sales personnel.

² **35** & **40K** color temperatures are only available in 80 CRI.

³ **WP** white painted interior. Trim interior is painted black standard.