

2-550-T Nemo GU10



The small Nemo trim, with its sealed and flush glass face, brings nuanced architectural lighting to wet locations: baths, covered walkways, entryways, and outdoor living spaces.

FEATURES

- Utilizes GU10
- Wet location listed
- 360° rotation
- 30° aiming
- Die-cast aluminum fixture
- Flush glass lens design
- Powder coated and plated trim ring finishes
- Trim clips designed for 5/8" ceiling thickness
- Accepts up to 2 optional media

DETAILS


Trim Class: 4"
Category: Recessed Downlight
Shape: Square
Adjustability: Aiming With Rotation




2-550-T-Nemo-GU10-Specs • Subject to change without notice • Rev 2016.12.19 • 1/4

Features & Lighting

DIMENSIONS

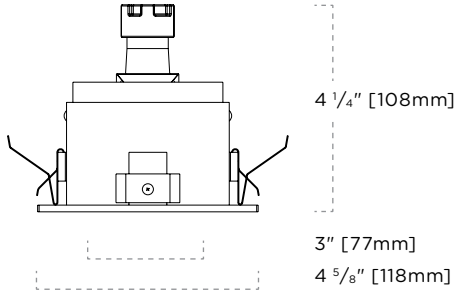

CEILING CUTOUT

 

FLANGE FINISHES

- White
- Chrome Plated
- Black
- Matte Silver
- Bronze
- Matte Nickel

GLASS

- Frosted
- Clear

2-550-T-Nemo-GU10-Specs • Subject to change without notice • Rev 2016.12.19 • 2/4

2-550-T Nemo GU10

Project

Type

Notes

Product Code

1 2 3 4 5

1. Trim

2-550-T Nemo

2. Lamp

GU10 Halogen

3. Flange Finish

01 White

02 Chrome Plated

04 Black

05 Matte Silver

06 Bronze

11 Matte Nickel

CC Custom Color ¹

4. Glass

C Clear Glass

F Frosted Glass

5. Options

WP White painted housing interior ²

Notes

¹ **CC** custom color requires consultation with Lightheaded sales personnel.

² **WP** white trim interior. Trim interior is painted black standard.

2-550-T-Nemo-GU10-Specs • Subject to change without notice • Rev 2016.12.19 • 4/4