

2-500-T Quadra GU10



A clear modern aesthetic shines through in the Quadra family of square-aperture recessed downlights. Quadra was integrally engineered to ensure ultra-low glare from the deeply regressed light source.

FEATURES

- Utilizes GU10
- 360° rotation
- 30° aiming
- Powder coated and plated trim ring finishes
- Trim clips designed for 5/8" ceiling thickness
- Accepts up to 2 optional media
- Clear glass lens included
- Relamp from below the ceiling

DETAILS


Trim Class: 4"
Category: Recessed Downlight
Shape: Square
Adjustability: Tilt With Rotation




2-500-T-Quadra-GU10-Specs • Subject to change without notice • Rev 2017.08.03 • 1/4

Features & Lighting

DIMENSIONS

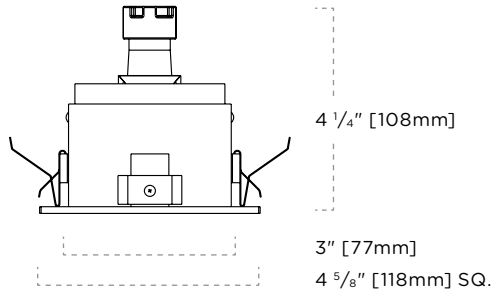

CEILING CUTOUT

 

FLANGE FINISHES

- White
- Chrome Plated
- Black
- Matte Silver
- Bronze
- Matte Nickel

2-500-T Quadra GU10

Project

Type

Notes

Product Code

1 2 3 4 5

1. Trim

2-500-T Quadra

2. Lamp

GU10 Halogen

3. Flange Finish

01 White

02 Chrome Plated

04 Black

05 Matte Silver

06 Bronze

11 Matte Nickel

CC Custom Color ¹

4. Optional Media (2 Maximum)

CL Clear

EL Elongating

FRO Frosted

HC Honeycomb

PER Perimeter Frosted

SL Solite Softening

SPDL Spread

5. Options

WP White Painted Interior ²

Notes

¹ **CC** custom color requires consultation with Lightheaded sales personnel.

² **WP** white painted interior. Trim interior painted black standard.

2-500-T-Quadra-GU10-Specs • Subject to change without notice • Rev 2017.08.03 • 4/4