



PROJECT	TYPE
CATALOG NUMBER	

### FEATURES

- 24VDC operation. Requires remote driver
- Dry location
- Available in both standard and high output
- Dimmable
- Available in 16'-4" and 98'-6" reels
- Available with connectors (see below)
- Cuttable every 4" for std. output
- Cuttable every 6-1/2" for high output
- 5 year warranty

### ELECTRICAL

- 24VDC
- 2.2W per foot - standard output
- 4.4W per foot - high output
- 50,000 hour LED life

### OPTICS

- 2700K, 3000K, 4000K
- Up to 317 lumens per foot
- 94 CRI

### LABEL

- UL listed

### POWER SUPPLIES

- For a complete list of applicable 24VDC power supplies, please see our website at [gmlighting.net](http://gmlighting.net), or click on this link.

### MOUNTING CHANNELS

- GM Lighting manufactures lensed architectural mounting channels in a wide array of configurations. Please see our website at [gmlighting.net](http://gmlighting.net) or click on this link.


### PHOTOMETRICS

- Please see our website at [gmlighting.net](http://gmlighting.net) or click on this link.

### PRODUCT DESCRIPTION

A 94 CRI flexible LED linear ribbon that features superior construction and easy mounting. Available in standard or high output, and on 16'-4" or 98'-6" reels.

Custom cuts available - consult factory.

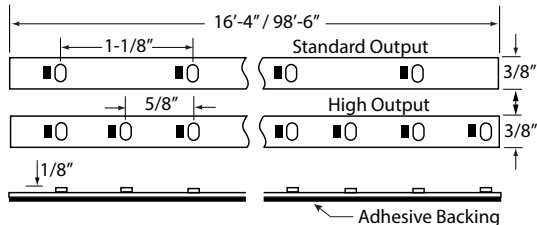

### ORDERING INFORMATION

Catalog No.	Length	Output	LED Wattage	Lumens per Foot	Color Temp.*
ESR15024-S0-27	16'-4"	Standard	2.2W /ft.	146	2700K
ESR15024-S0-30	16'-4"	Standard	2.2W /ft.	152	3000K
ESR15024-S0-40	16'-4"	Standard	2.2W /ft.	161	4000K
ESR30024-H0-27	16'-4"	High	4.4W /ft.	292	2700K
ESR30024-H0-30	16'-4"	High	4.4W /ft.	304	3000K
ESR30024-H0-40	16'-4"	High	4.4W /ft.	317	4000K
ESR90024-100-S0-27	98'-6"	Standard	2.2W /ft.	146	2700K
ESR90024-100-S0-30	98'-6"	Standard	2.2W /ft.	152	3000K
ESR90024-100-S0-40	98'-6"	Standard	2.2W /ft.	161	4000K
ESR180024-100-H0-27	98'-6"	High	4.4W /ft.	292	2700K
ESR180024-100-H0-30	98'-6"	High	4.4W /ft.	304	3000K
ESR180024-100-H0-40	98'-6"	High	4.4W /ft.	317	4000K

16'-4" reel includes 24" of lead and (3) ESTW-60 connectors. 98'-6" reel includes 24" of lead and (15) ESTW-60 connectors. \* Kelvin temperature (color) ±200K

### SURE-TITE CONNECTORS

Catalog No.	Description
ESTC-1	RIBBON TO RIBBON CONNECTOR
ESTLK-60	RIBBON TO RIBBON CONNECTOR - ONE END WITH 60" 18 AWG LEAD AND EXTRA CONNECTOR. ADJUSTABLE TO ANY LENGTH DESIRED AND CUTTABLE IN FIELD.
ESTW-60	RIBBON TO POWER SUPPLY CONNECTOR - ONE END WITH 60" 18 AWG LEAD. ADJUSTABLE TO ANY LENGTH DESIRED AND CUTTABLE IN FIELD.

\* ESTLK-60 and ESTW-60 are adjustable to any length desired, and cuttable in the field.