



GR

GOOF RING

Product codes

GR575 : 5.50" Int - 7.50" Ext


GR1000 : 10.00" Int - 12.00" Ext

GR400 : 4.00" Int - 6.00" Ext

GR475 : 4.75" Int - 6.75" Ext

GR650 : 6.50" Int - 8.50" Ext

GR825 : 8.25" Int - 10.25" Ext

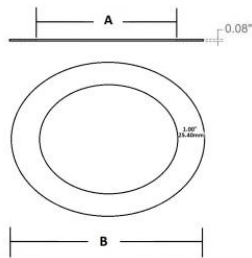

	A	B
GR400	4.00" (101.60mm)	6.00" (152.40mm)
GR475	4.75" (120.65mm)	6.75" (171.45mm)
GR575	5.50" (139.70mm)	7.50" (190.50mm)
GR650	6.50" (165.10mm)	8.50" (215.90mm)
GR825	8.25" (209.55mm)	10.25" (260.35mm)
GR1000	10.00" (254.00mm)	12.00" (304.80mm)

Données techniques

Max Hole Size (GR400) 5.00"

Max Hole Size (GR475) 5.50"

Max Hole Size (GR575) 6.50"

Max Hole Size (GR650) 7.50"

Max Hole Size (GR825) 9.25"

Max Hole Size (GR1000) 11.00"