 




WHITE



BLACK



SATIN
CHROME

RZR-LED-430

4.00" ULTRA THIN LED SQUARE RAZOR SERIES - 9W

Product codes

RZR-430-9W-3K-WH : WHITE - 3K

RZR-430-9W-3K-BLK : BLACK - 3K

RZR-430-9W-3K-SC : SATIN CHROME - 3K

RZR-430-9W-4K-WH : WHITE - 4K

RZR-430-9W-4K-BLK : BLACK - 4K

RZR-430-9W-4K-SC : SATIN CHROME - 4K

RZR-430-9W-3K-BRZ : BRONZE - 3K


RZR-430-9W-4K-BRZ : BRONZE - 4K

RZR-430-9W-5K-WH : WHITE - 5K

This ultra-thin recessed unit is IC and AIR TIGHT rated and with its thin profile allows installation in almost any location. (Remodel or New Construction applications) It is suitable for wet locations, such as a shower and outdoors in soffits. Included with the unit is a junction box with driver, pressure fit clips and Quick Connect wire connectors for quick and easy installation. The junction box has integrated screw holes to allow the box to be secured to studs or joists, if needed. The maximum number of the 9W fixtures that can be installed with a standard 150W LED dimmer is 16 units. This product is ETL listed in USA & Canada, certified to UL standard 1598 and CSA standard C22.2 NO. 250.0-08, and includes the following:

The wiring compartment accommodates up to (6) 14 gauge insulated conductors to satisfy luminaire junction box volume requirements.

A complete listing of compatible dimmers may be found in our "Product Knowledge" section of our site. Although this product is AIR-TIGHT rated, some municipalities will require the use of a vapor barrier. Verify local building codes prior to installation.

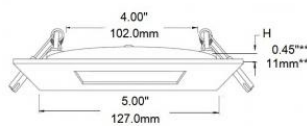

Données techniques

Cutting hole 4.25"

Beam Angle 107° 1/2

Color Temperature 3K / 4K / 5K

CRI >80

Dimmable Y

LED Life 50,000hrs

Mounting Plate MP/AMP/MPUB 105