



WHITE



BLACK



SATIN
CHROME



BRONZE

RZR-LED-611

6.00" LOW PROFILE REGRESSED LED RAZOR SERIES- 12W

Product codes


RZR-611-12W-27K-WH : WHITE - 27K
 RZR-611-12W-3K-WH : WHITE - 3K
 RZR-611-12W-3K-BLK : BLACK - 3K
 RZR-611-12W-3K-SC : SATIN CHROME - 3K
 RZR-611-12W-3K-BRZ : BRONZE - 3K
 RZR-611-12W-4K-WH : WHITE - 4K
 RZR-611-12W-4K-BLK : BLACK - 3K
 RZR-611-12W-4K-SC : SATIN CHROME - 4K
 RZR-611-12W-4K-BRZ : BRONZE - 4K
 RZR-611-12W-5K-WH : WHITE - 5K

This new and improved low profile regressed unit is IC and AIR TIGHT rated and with its low profile allows installation in almost any location. (Remodel or New Construction applications) This unit has the LED's installed on the back of the unit, verses a traditional side lite installation. This improvement allows for a much greater lumen output. It is suitable for wet locations. Included with the unit is a junction box with driver, pressure fit clips and Quick Connect wire connectors for quick and easy installation. The junction box has integrated screw holes to allow the box to be secured to studs or joists, if needed. The maximum number of the 12W fixtures that can be installed with a standard 150W LED dimmer is 12 units. This product is ETL listed in USA & Canada, certified to UL standard 1598 and CSA standard C22.2 NO. 250.0-08, and includes the following:

The wiring compartment accommodates up to (6) 14/2 gauge insulated conductors to satisfy luminaire junction box volume requirements.

A complete listing of compatible dimmers may be found in our "Product Knowledge" section of our site.

Although this product meets all industry certifications and ratings, some municipalities will require the use of a vapor barrier and/or mounting plate. Verify local building codes prior to installation.

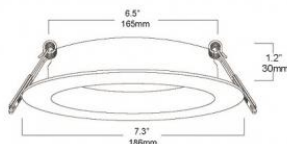

Données techniques

| | |
|--------------|------------------|
| Cutting hole | 6.33" (160.8 mm) |
| Beam Angle | 107° ½ |

