



WHITE



BLACK



SATIN
CHROME

RZR-LED-420

4.00" LOW PROFILE GIMBAL LED RAZOR SERIES - 9W

Product codes

RZR-420-9W-3K-WH : WHITE - 3K

RZR-420-9W-3K-BLK : BLACK - 3K

RZR-420-9W-3K-SC : SATIN CHROME - 3K

RZR-420-9W-4K-WH : WHITE - 4K

RZR-420-9W-4K-BLK : BLACK - 4K


 
RZR-420-9W-4K-SC : SATIN CHROME - 4K

RZR-420-9W-5K-WH : WHITE - 5K

This low profile gimbal unit is IC and AIR TIGHT rated and with its low profile allows installation in almost any location. (Remodel or New Construction applications) It is suitable for damp locations, such as a shower and outdoors in soffits. Included with the unit is a junction box with driver, pressure fit clips and Quick Connect wire connectors for quick and easy installation. The junction box has integrated screw holes to allow the box to be secured to studs or joists, if needed. The maximum number of the 9W fixtures that can be installed with a standard 150W LED dimmer is 16 units. This product is ETL listed in USA & Canada, certified to UL standard 1598 and CSA standard C22.2 NO. 250.0-08, and includes the following:

The wiring compartment accommodates up to (6) 14 gauge insulated conductors to satisfy luminaire junction box volume requirements.

A complete listing of compatible dimmers may be found in our "Product Knowledge" section of our site. Although this product meets all industry certifications and ratings, some municipalities will require the use of a vapor barrier and/or mounting plate. Verify local building codes prior to installation.

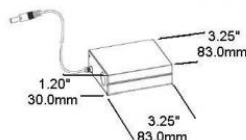

Données techniques

| | |
|--------------|------------------|
| Cutting hole | 4.50" (114.3 mm) |
|--------------|------------------|

| | |
|------------|------------|
| Beam Angle | 107° ± 1/2 |
|------------|------------|

| | |
|------------------|-----------|
| Adjustment angle | 20° ± 1/2 |
|------------------|-----------|

| | |
|-------------------|--------------|
| Color Temperature | 3K / 4K / 5K |
|-------------------|--------------|

| | |
|-----|-----|
| CRI | >80 |
|-----|-----|

| | |
|----------|---|
| Dimmable | Y |
|----------|---|

| | |
|----------------|-----------------|
| Mounting Plate | MP/AMP/MPHB 450 |
|----------------|-----------------|

| | |
|----------|-----------|
| LED Life | 50 000hrs |
|----------|-----------|