



WHITE



BLACK

RZR-LED-800

8.00" ULTRA THIN LED RAZOR SERIES - 18W

Product codes

RZR-800-18W-4K-BLK : BLACK - 4K

RZR-800-18W-3K-WH : WHITE - 3K

RZR-800-18W-3K-BLK : BLACK - 3K


 
RZR-800-18W-4K-WH : WHITE - 4K

RZR-800-18W-5K-WH : WHITE - 5K

This ultra-thin recessed unit is IC and AIR TIGHT rated and with its thin profile allows installation in almost any location. (Remodel or New Construction applications) It is suitable for wet locations, such as a shower and outdoors in soffits. Included with the unit is a junction box with driver, pressure fit clips and Quick Connect wire connectors for quick and easy installation. The junction box has integrated screw holes to allow the box to be secured to studs or joists, if needed. The maximum number of the 18W fixtures that can be installed with a standard 150W LED dimmer is 8 units. This product is ETL listed in USA & Canada, certified to UL standard 1598 and CSA standard C22.2 NO. 250.0-08, and includes the following:

The wiring compartment accommodates up to (6) 14 gauge insulated conductors to satisfy luminaire junction box volume requirements.

A complete listing of compatible dimmers may be found in our "Product Knowledge" section of our site. Bien que ce produit réponde à toutes les certifications et classifications de l'industrie, certaines municipalités exigeront l'utilisation d'un coupe vapeur ou d'une plaque de montage. Verify local building codes prior to installation.

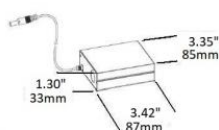

**Height including clip
**Hauteur avec pince
1.13"
29mm

Données techniques

| | |
|-----------------------|--------------|
| Cutting hole | 8.00" |
| Beam Angle | 107° ± ½ |
| Color Temperature | 3K / 4K / 5K |
| CRI | >80 |
| Mounting Plate | MPHB-800 |
| Dimmable | Y |
| LED Life | 50,000hrs |
| Light Output - Lumen | 1450LM |
| Operating Temperature | -20°C + 40°C |