



WHITE

BLACK

SATIN
CHROME

RZR-LED-630

6.00" ULTRA THIN LED SQUARE RAZOR SERIES - 12W


Product codes

- RZR-630-12W-3K-WH : WHITE - 3K
- RZR-630-12W-3K-BLK : BLACK - 3K
- RZR-630-12W-3K-SC : SATIN CHROME - 3K
- RZR-630-12W-4K-WH : WHITE - 4K
- RZR-630-12W-4K-BLK : BLACK - 4K
- RZR-630-12W-4K-SC : SATIN CHROME - 4K
- RZR-630-12W-3K-BRZ : BRONZE - 3K
- RZR-630-12W-4K-BRZ : BRONZE - 4K
- RZR-630-12W-5K-WH : WHITE - 5K

This ultra-thin recessed unit is IC and AIR TIGHT rated and with its thin profile allows installation in almost any location. (Remodel or New Construction applications) It is suitable for wet locations, such as a shower and outdoors in soffits. Included with the unit is a junction box with driver, pressure fit clips and Quick Connect wire connectors for quick and easy installation. The junction box has integrated screw holes to allow the box to be secured to studs or joists, if needed. The maximum number of the 12W fixtures that can be installed with a standard 150W LED dimmer is 12 units. This product is ETL listed in USA & Canada, certified to UL standard 1598 and CSA standard C22.2 NO. 250.0-08, and includes the following:

The wiring compartment accommodates up to (6) 14 gauge insulated conductors to satisfy luminaire junction box volume requirements.

A complete listing of compatible dimmers may be found in our "Product Knowledge" section of our site. Although this product meets all industry certifications and ratings, some municipalities will require the use of a vapor barrier and/or mounting plate. Verify local building codes prior to installation.

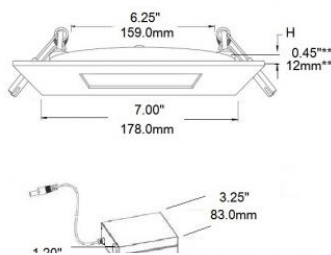

Données techniques

Cutting hole	6.33"
Beam Angle	107° ± 1/2°
Color Temperature	3K / 4K / 5K
CRI	>80
Mounting Plate	AMP/MPHB 600
Dimmable	Y