

SL5-RGB(W) – INDOOR DIFFUSION LED STRIP

DESCRIPTION

Diffusion SL-5-RGB is a flexible 10mm wide linear LED strip. Diffusion SL-5-RGBW is a flexible 12mm wide linear LED strip. Both are available in 16' and 100' rolls that can be cut every 6 LEDs (100mm or 4").

FEATURES

- * 3M industrial strength adhesive tape
- * Long life LED: 50,000 hrs
- * Dimmable with dimming power supply
- * 2' power feeds on both ends of every roll

CUSTOM LENGTHS AVAILABLE UPON REQUEST

SPECIFICATIONS

RGB LED: 14.4 W/m (4.32 W/ft)
 RGBW LED: 19.2 W/m (6 W/ft)
 Lamp Life: 50,000 hrs LM80
 LED/Meter: 60/m (18/ft)
 Power Input: 24V DC

LUMENS

RGB = Up to 591 lm/m (180 lm/ft)
 W(2700K) = Up to 400 lm/m (122 lm/ft)




ORDERING
CODE

LENGTH

VOLTAGE

COLOUR

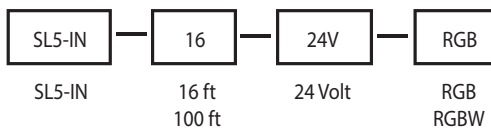

Project: _____
 Type: _____
 Date: _____
 Part #: _____