

NEW PRODUCTS FROM MILWAUKEE®

SHOCKWAVE™ IMPACT DUTY™

STEP BITS


MOST DURABLE. FASTEST HOLES.

UP TO
2x FASTER
WITH RAPID STRIKE™ TIP

TITANIUM ALUMINUM
COATING

UP TO
5x LIFE

OPTIMIZED
SHOCK ZONE
ABSORBS
PEAK TORQUE™

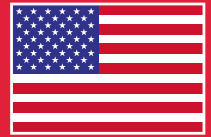


MADE IN USA
WITH GLOBAL MATERIALS

FOR
IMPACTS & DRILLS




FASTEST HOLE SPEED

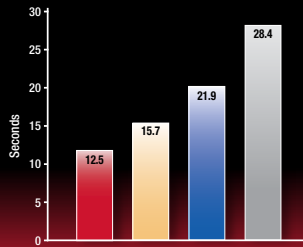

Average Completed Hole Speed

*Tested with #9 bit in 14 gauge 1008 steel using M18 FUEL™ 2753-22 1/4" Hex Impact Driver with 5.0 a/hr battery in Slide Fixture


LONGEST LIFE IN IMPACT DRIVERS

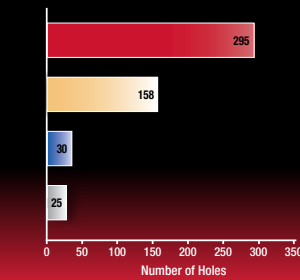

Completed Holes Over Bit Life

*Tested with #9 bit in 14 gauge 1008 steel using M18 FUEL™ 2753-22 1/4" Hex Impact Driver with 5.0 a/hr battery in Slide Fixture

LONGEST LIFE IN DRILLS

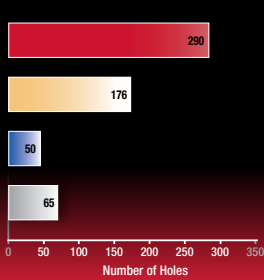

Completed Holes Over Bit Life

*Tested with #9 bit in 14 gauge 1008 steel using M18 FUEL™ 1/2" Drill/Driver with 5.0 a/hr battery in Clamping Fixture

- MILWAUKEE®
- DeWalt®
- Champion®
- Ideal®

SHOCKWAVE™ IMPACT STEP BITS

| Description | No. of Holes | Milwaukee No. | Fastenal No. |
|---|--------------|---------------|--------------|
| #1 SHOCKWAVE™ Impact Step Bit 1/8" – 1/2" | 13 | 48-89-9241 | 2173307 |
| #2 SHOCKWAVE™ Impact Step Bit 3/16" – 1/2" | 6 | 48-89-9242 | 2173308 |
| #3 SHOCKWAVE™ Impact Step Bit 3/16" – 3/4" | 10 | 48-89-9243 | 2173309 |
| #4 SHOCKWAVE™ Impact Step Bit 3/16" – 7/8" | 12 | 48-89-9244 | 2173310 |
| #8 SHOCKWAVE™ Impact Step Bit 1/2" – 1" | 9 | 48-89-9248 | 2173311 |
| #9 SHOCKWAVE™ Impact Step Bit 7/8" & 1-1/8" | 2 | 48-89-9249 | 2173312 |

SHOCKWAVE™ IMPACT STEP BIT SETS

| Description | Milwaukee No. | Fastenal No. |
|--|---------------|--------------|
| 3 Pc SHOCKWAVE™ Impact Step Bit Set (#1, #2, #4) | 48-89-9254 | 2173302 |
| 3 Pc SHOCKWAVE™ Impact Step Bit Mechanical Set (#2, #3, #8) | 48-89-9256 | 2173304 |
| 3 Pc SHOCKWAVE™ Impact Step Bit Electrician Set (#1, #4, #9) | 48-89-9257 | 2173306 |



OPTIMIZED FOR CORDLESS DRILLS IN HIGH SPEED

STEP DRILL BITS

| Description | No. of Holes | Milwaukee No. | Fastenal No. |
|--|--------------|---------------|--------------|
| #1 Step Drill Bit 1/8" – 1/2" | 13 | 48-89-9201 | 2115755 |
| #2 Step Drill Bit 3/16" – 1/2" | 6 | 48-89-9202 | 2115756 |
| #3 Step Drill Bit 1/4" – 3/4" | 9 | 48-89-9203 | 2115757 |
| #4 Step Drill Bit 3/16" – 7/8" | 12 | 48-89-9204 | 2115758 |
| #5 Step Drill Bit 1/4" – 1-3/8" | 10 | 48-89-9205 | 2115759 |
| #6 Step Drill Bit 3/8" & 1/2" | 2 | 48-89-9206 | 2115760 |
| #7 Step Drill Bit 7/8" | 1 | 48-89-9207 | 2115761 |
| #8 Step Drill Bit 1/2" – 1" | 8 | 48-89-9208 | 2115762 |
| #9 Step Drill Bit 7/8" & 1-1/8" | 2 | 48-89-9209 | 2115763 |
| #10 Step Drill Bit 7/8", 1-1/8", 1-7/32" | 3 | 48-89-9211 | 2115764 |
| #11 Step Drill Bit 7/8", 1-1/8", 1-7/32", 1-3/8" | 4 | 48-89-9212 | 2115765 |

STEP DRILL BIT SETS

| Description | Milwaukee No. | Fastenal No. |
|--|---------------|--------------|
| 3 Pc Step Drill Bit Set (#1, #2, #4) | 48-89-9221 | 2115766 |
| 4 Pc Step Drill Bit Set (#1, #4, #7, #12) | 48-89-9223 | 2115767 |
| 6 Pc Step Drill Bit Set (#1, #4, #6, #7, #9) | 48-89-9224 | 2115768 |

RAPID STRIKE™ Tip

- Black Oxide Coating
- Dual Flute Design
- Laser Engraved ID
- Reduced 3-Flat Shank
- 3-FLAT SECURE-GRIP™



Patent Pending

JAM-FREE PERFORMANCE

UP TO
2x FASTER
WITH RAPID STRIKE™ TIP

UP TO
4x LIFE

50% MORE HOLES
PER CHARGE

BUY \$50 OR MORE IN MILWAUKEE® SAWZALL® BLADES, HOLE DOZER® OR BIG HAWG®

GET ONE OF THESE FREE VIA E-REBATE



FOR EVERY \$50 SPENT ON MILWAUKEE® SAWZALL® BLADES, HOLE DOZER®, HOLE SAWS, BIG HAWG® OR CIRCULAR SAW BLADES GET YOUR CHOICE BETWEEN A LIMITED EDITION CARBIDE TEETH HAT OR TUMBLER.

ALL BI-METAL & CARBIDE TEETH SAWZALL BLADES, HOLE DOZER HOLE SAWS, BIG HAWG HOLE SAWS, & WOOD CUTTING CIRCULAR SAW BLADE ELIGIBLE FOR PROMOTION (INCLUDING SINGLE PACKS, MULTI-PACKS, SETS & BULK). *CARBIDE CUTTERS, STEEL HAWG™, & METAL CUTTING CIRCULAR SAW BLADES NOT ELIGIBLE FOR PROMOTION.



TORCH™
CARBIDE TEETH

LONGEST LIFE IN THICK METALS

50X LIFE™

FASTEST CUTS IN CAST IRON



| | LENGTH | 1 PACK | 3 PACK | 5 PACK |
|--|--------|----------------------|----------------------|----------------------|
| | 6" | 2180468 / 48-00-5201 | 2180471 / 48-00-5301 | 2127441 / 48-00-5501 |
| | 9" | 2180469 / 48-00-5202 | 2180472 / 48-00-5302 | 2180728 / 48-00-5502 |



AX™
CARBIDE TEETH

LONGEST LIFE IN STAINLESS STEEL

50X LIFE™

THERMOSET COATING
2X FASTER



| | LENGTH | 1 PACK | 3 PACK | 5 PACK |
|--|--------|----------------------|----------------------|----------------------|
| | 6" | 2162013 / 48-00-5221 | 2180730 / 48-00-5321 | 2180733 / 48-00-5521 |
| | 9" | 2162014 / 48-00-5226 | 2180731 / 48-00-5326 | 2180734 / 48-00-5526 |
| | 12" | 2162015 / 48-00-5227 | 2180732 / 48-00-5327 | 2180735 / 48-00-5527 |



HOLE DOZER™
CARBIDE TEETH

1,000 MORE CUTS

50X LIFE™



| DESCRIPTION | MILWAUKEE # / FASTENAL # | DESCRIPTION | MILWAUKEE # / FASTENAL # |
|---------------------------------------|--------------------------|---------------------------------------|--------------------------|
| 3/4" HOLE DOZER™ with CARBIDE TEETH | 49-56-0702 / 2185520 | 2-1/4" HOLE DOZER™ with CARBIDE TEETH | 49-56-0724 / 2185530 |
| 7/8" HOLE DOZER™ with CARBIDE TEETH | 49-56-0704 / 2185521 | 2-3/8" HOLE DOZER™ with CARBIDE TEETH | 49-56-0726 / 2185531 |
| 1" HOLE DOZER™ with CARBIDE TEETH | 49-56-0707 / 2185522 | 2-1/2" HOLE DOZER™ with CARBIDE TEETH | 49-56-0727 / 2185532 |
| 1-1/8" HOLE DOZER™ with CARBIDE TEETH | 49-56-0708 / 2185523 | 2-5/8" HOLE DOZER™ with CARBIDE TEETH | 49-56-0729 / 2185533 |
| 1-1/4" HOLE DOZER™ with CARBIDE TEETH | 49-56-0710 / 2185524 | 3" HOLE DOZER™ with CARBIDE TEETH | 49-56-0734 / 2185534 |
| 1-3/8" HOLE DOZER™ with CARBIDE TEETH | 49-56-0712 / 2185525 | 3-1/2" HOLE DOZER™ with CARBIDE TEETH | 49-56-0738 / 2185535 |
| 1-1/2" HOLE DOZER™ with CARBIDE TEETH | 49-56-0713 / 2185526 | 3-5/8" HOLE DOZER™ with CARBIDE TEETH | 49-56-0739 / 2185536 |
| 1-3/4" HOLE DOZER™ with CARBIDE TEETH | 49-56-0717 / 2185527 | 4" HOLE DOZER™ with CARBIDE TEETH | 49-56-0742 / 2185537 |
| 1-7/8" HOLE DOZER™ with CARBIDE TEETH | 49-56-0719 / 2185528 | 4-1/4" HOLE DOZER™ with CARBIDE TEETH | 49-56-0744 / 2185538 |
| 2" HOLE DOZER™ with CARBIDE TEETH | 49-56-0720 / 2185529 | 4-1/2" HOLE DOZER™ with CARBIDE TEETH | 49-56-0746 / 2185539 |

THE TORCH™ SAWZALL BLADES

| MET# | FASTENAL# | DESCRIPTION |
|------------|-----------|--------------------|
| 48-00-5713 | 0254035 | TORCH™ 10T 9L 5PK |
| 48-00-5782 | 0254037 | TORCH™ 14T 6L 5PK |
| 48-00-5787 | 0254039 | TORCH™ 14T 9L 5PK |
| 48-00-5784 | 0254038 | TORCH™ 18T 6L 5PK |
| 48-00-5788 | 0254040 | TORCH™ 18T 9L 5PK |
| 48-00-5789 | 0254041 | TORCH™ 14T 12L 5PK |

THIN KERF™ SAWZALL BLADES

| MET# | FASTENAL# | DESCRIPTION |
|------------|-----------------|--------------|
| 48-01-6182 | 5261-48-01-6182 | 14T 6LG 50PK |
| 48-01-6184 | 5261-48-01-6184 | 18T 6LG 50PK |
| 48-01-6188 | 0254062 | 18T 9LG 50PK |

REDEEM PROMOTIONS VIA E-REBATE AT [HTTPS://MILWAUKEETOOL-REBATES.HEROKUAPP.COM/#/HOME/FASTENAL](https://MILWAUKEETOOL-REBATES.HEROKUAPP.COM/#/HOME/FASTENAL) PROMOTIONS VALID AUGUST 1 - OCTOBER 31, 2018.