

# NEW PRODUCTS FROM MILWAUKEE®

## SHOCKWAVE IMPACT DUTY™

### STEP BITS

### MOST DURABLE. FASTEST HOLES.

UP TO  
**2x FASTER**  
WITH RAPID STRIKE™ TIP

TITANIUM ALUMINUM  
COATING

UP TO  
**5x LIFE**

OPTIMIZED  
**SHOCK  
ZONE**  
ABSORBS  
PEAK TORQUE™




**MADE IN USA**  
WITH GLOBAL MATERIALS

FOR  
**IMPACTS & DRILLS**




#### FASTEST HOLE SPEED

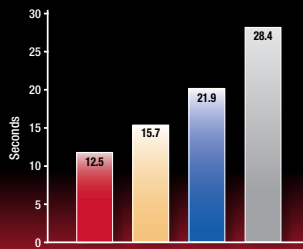

Average Completed Hole Speed

\*Tested with #9 bit in 14 gauge 1008 steel using M18 FUEL™ 2753-22 1/4" Hex Impact Driver with 5.0 a/hr battery in Slide Fixture


#### LONGEST LIFE IN IMPACT DRIVERS

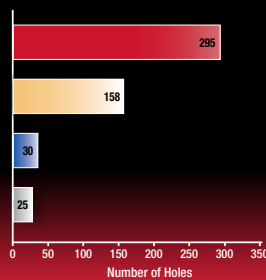

Completed Holes Over Bit Life

\*Tested with #9 bit in 14 gauge 1008 steel using M18 FUEL™ 2753-22 1/4" Hex Impact Driver with 5.0 a/hr battery in Slide Fixture

#### LONGEST LIFE IN DRILLS

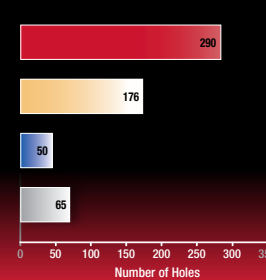

Completed Holes Over Bit Life

\*Tested with #9 bit in 14 gauge 1008 steel using M18 FUEL™ 1/2" Drill/Driver with 5.0 a/hr battery in Clamping Fixture

- MILWAUKEE®
- DeWalt®
- Champion®
- Ideal®

#### SHOCKWAVE™ IMPACT STEP BITS

Description	No. of Holes	Milwaukee No.	Fastenal No.
#1 SHOCKWAVE™ Impact Step Bit 1/8" – 1/2"	13	48-89-9241	2173307
#2 SHOCKWAVE™ Impact Step Bit 3/16" – 1/2"	6	48-89-9242	2173308
#3 SHOCKWAVE™ Impact Step Bit 3/16" – 3/4"	10	48-89-9243	2173309
#4 SHOCKWAVE™ Impact Step Bit 3/16" – 7/8"	12	48-89-9244	2173310
#8 SHOCKWAVE™ Impact Step Bit 1/2" – 1"	9	48-89-9248	2173311
#9 SHOCKWAVE™ Impact Step Bit 7/8" & 1-1/8"	2	48-89-9249	2173312

#### SHOCKWAVE™ IMPACT STEP BIT SETS

Description	Milwaukee No.	Fastenal No.
3 Pc SHOCKWAVE™ Impact Step Bit Set (#1, #2, #4)	48-89-9254	2173302
3 Pc SHOCKWAVE™ Impact Step Bit Mechanical Set (#2, #3, #8)	48-89-9256	2173304
3 Pc SHOCKWAVE™ Impact Step Bit Electrician Set (#1, #4, #9)	48-89-9257	2173306



OPTIMIZED FOR  
**CORDLESS DRILLS IN HIGH SPEED**


#### STEP DRILL BITS

Description	No. of Holes	Milwaukee No.	Fastenal No.
#1 Step Drill Bit 1/8" – 1/2"	13	48-89-9201	2115755
#2 Step Drill Bit 3/16" – 1/2"	6	48-89-9202	2115756
#3 Step Drill Bit 1/4" – 3/4"	9	48-89-9203	2115757
#4 Step Drill Bit 3/16" – 7/8"	12	48-89-9204	2115758
#5 Step Drill Bit 1/4" – 1-3/8"	10	48-89-9205	2115759
#6 Step Drill Bit 3/8" & 1/2"	2	48-89-9206	2115760
#7 Step Drill Bit 7/8"	1	48-89-9207	2115761
#8 Step Drill Bit 1/2" – 1"	8	48-89-9208	2115762
#9 Step Drill Bit 7/8" & 1-1/8"	2	48-89-9209	2115763
#10 Step Drill Bit 7/8", 1-1/8", 1-7/32"	3	48-89-9211	2115764
#11 Step Drill Bit 7/8", 1-1/8", 1-7/32", 1-3/8"	4	48-89-9212	2115765

#### STEP DRILL BIT SETS

Description	Milwaukee No.	Fastenal No.
3 Pc Step Drill Bit Set (#1, #2, #4)	48-89-9221	2115766
4 Pc Step Drill Bit Set (#1, #4, #7, #12)	48-89-9223	2115767
6 Pc Step Drill Bit Set (#1, #4, #6, #7, #9)	48-89-9224	2115768

RAPID STRIKE™ Tip

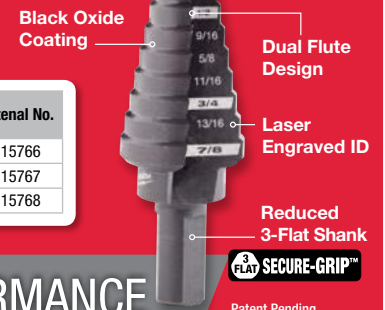

## JAM-FREE PERFORMANCE

UP TO  
**2x FASTER**  
WITH RAPID STRIKE™ TIP

UP TO  
**4x LIFE**

**50%  
MORE HOLES  
PER CHARGE**

# BUY \$50 OR MORE IN MILWAUKEE® SAWZALL® BLADES, HOLE DOZER® OR BIG HAWG®

## GET ONE OF THESE FREE VIA E-REBATE



**FOR EVERY \$50 SPENT ON MILWAUKEE® SAWZALL® BLADES, HOLE DOZER®, HOLE SAWS, BIG HAWG® OR CIRCULAR SAW BLADES GET YOUR CHOICE BETWEEN A LIMITED EDITION CARBIDE TEETH HAT OR TUMBLER.**

ALL BI-METAL & CARBIDE TEETH SAWZALL BLADES, HOLE DOZER HOLE SAWS, BIG HAWG HOLE SAWS, & WOOD CUTTING CIRCULAR SAW BLADE ELIGIBLE FOR PROMOTION (INCLUDING SINGLE PACKS, MULTI-PACKS, SETS & BULK). \*CARBIDE CUTTERS, STEEL HAWG™, & METAL CUTTING CIRCULAR SAW BLADES NOT ELIGIBLE FOR PROMOTION.



**TORCH™**  
CARBIDE TEETH

**LONGEST LIFE IN THICK METALS**

**50X LIFE™**

**FASTEST CUTS IN CAST IRON**



	LENGTH	1 PACK	3 PACK	5 PACK
	6"	2180468 / 48-00-5201	2180471 / 48-00-5301	2127441 / 48-00-5501
	9"	2180469 / 48-00-5202	2180472 / 48-00-5302	2180728 / 48-00-5502



**AX™**  
CARBIDE TEETH

**LONGEST LIFE IN STAINLESS STEEL**

**50X LIFE™**

**THERMOSET COATING 2X FASTER**



	LENGTH	1 PACK	3 PACK	5 PACK
	6"	2162013 / 48-00-5221	2180730 / 48-00-5321	2180733 / 48-00-5521
	9"	2162014 / 48-00-5226	2180731 / 48-00-5326	2180734 / 48-00-5526
	12"	2162015 / 48-00-5227	2180732 / 48-00-5327	2180735 / 48-00-5527



**HOLE DOZER™**  
CARBIDE TEETH

**1,000 MORE CUTS**

**50X LIFE™**



DESCRIPTION	MILWAUKEE # / FASTENAL #	DESCRIPTION	MILWAUKEE # / FASTENAL #
3/4" HOLE DOZER™ with CARBIDE TEETH	49-56-0702 / 2185520	2-1/4" HOLE DOZER™ with CARBIDE TEETH	49-56-0724 / 2185530
7/8" HOLE DOZER™ with CARBIDE TEETH	49-56-0704 / 2185521	2-3/8" HOLE DOZER™ with CARBIDE TEETH	49-56-0726 / 2185531
1" HOLE DOZER™ with CARBIDE TEETH	49-56-0707 / 2185522	2-1/2" HOLE DOZER™ with CARBIDE TEETH	49-56-0727 / 2185532
1-1/8" HOLE DOZER™ with CARBIDE TEETH	49-56-0708 / 2185523	2-5/8" HOLE DOZER™ with CARBIDE TEETH	49-56-0729 / 2185533
1-1/4" HOLE DOZER™ with CARBIDE TEETH	49-56-0710 / 2185524	3" HOLE DOZER™ with CARBIDE TEETH	49-56-0734 / 2185534
1-3/8" HOLE DOZER™ with CARBIDE TEETH	49-56-0712 / 2185525	3-1/2" HOLE DOZER™ with CARBIDE TEETH	49-56-0738 / 2185535
1-1/2" HOLE DOZER™ with CARBIDE TEETH	49-56-0713 / 2185526	3-5/8" HOLE DOZER™ with CARBIDE TEETH	49-56-0739 / 2185536
1-3/4" HOLE DOZER™ with CARBIDE TEETH	49-56-0717 / 2185527	4" HOLE DOZER™ with CARBIDE TEETH	49-56-0742 / 2185537
1-7/8" HOLE DOZER™ with CARBIDE TEETH	49-56-0719 / 2185528	4-1/4" HOLE DOZER™ with CARBIDE TEETH	49-56-0744 / 2185538
2" HOLE DOZER™ with CARBIDE TEETH	49-56-0720 / 2185529	4-1/2" HOLE DOZER™ with CARBIDE TEETH	49-56-0746 / 2185539

### THE TORCH™ SAWZALL BLADES

MET#	FASTENAL#	DESCRIPTION
48-00-5713	0254035	TORCH™ 10T 9L 5PK
48-00-5782	0254037	TORCH™ 14T 6L 5PK
48-00-5787	0254039	TORCH™ 14T 9L 5PK
48-00-5784	0254038	TORCH™ 18T 6L 5PK
48-00-5788	0254040	TORCH™ 18T 9L 5PK
48-00-5789	0254041	TORCH™ 14T 12L 5PK

### THIN KERF™ SAWZALL BLADES

MET#	FASTENAL#	DESCRIPTION
48-01-6182	5261-48-01-6182	14T 6LG 50PK
48-01-6184	5261-48-01-6184	18T 6LG 50PK
48-01-6188	0254062	18T 9LG 50PK

REDEEM PROMOTIONS VIA E-REBATE AT [HTTPS://MILWAUKEETOOL-REBATES.HEROKUAPP.COM/#/HOME/FASTENAL](https://MILWAUKEETOOL-REBATES.HEROKUAPP.COM/#/HOME/FASTENAL) PROMOTIONS VALID AUGUST 1 - OCTOBER 31, 2018.