

## IRONWORKER'S

UP TO **2X MORE CUTS**

Iron-Carbide  
Edge  
For Twisting &  
Cutting Rebar Ties



Comfort Grips –  
Will not peel



Part #	Description
48-22-6102	Ironworker's Pliers

## CRIMPING

UP TO **2X CRIMPING FORCE\***

Reaming  
Head  
Wire Cutter  
Crimper for  
Insulated &  
Non-Insulated  
Terminals



Comfort Grips –  
Will not peel



Part #	Description
48-22-6103	Crimping Pliers

## CABLE CUTTING

**CLEAN CUTS**

Clean Cuts  
Cuts up to  
2/0 Cu, 4/0 Al



Comfort Grips –  
Will not peel



Part #	Description
48-22-6104	Cable Cutting Pliers

## PVC / OIL FILTER

**3-1/2" JAW CAPACITY**



Comfort Grips –  
Will not peel



Part #	Description
48-22-6321	PVC / Oil Filter Pliers

 
## NIPPING

**CURVED HEAD  
PROTECTS SURFACES**

Blades Will Not  
Mar Surfaces



Comfort Grips –  
Will not peel



Part #	Description
48-22-6407	7" Nipping Pliers

## FENCING

**FORGED STRENGTH**

Staple  
Gripper  
Wire  
Crimper  
Hammer  
Staple Puller  
Wire Cutter  
Wire Puller



Comfort Grips –  
Will not peel




Part #	Description
48-22-6410	Fencing Pliers



# LOCKING PLIERS & C-CLAMPS

## TORQUE LOCK™ FASTER SET-UP

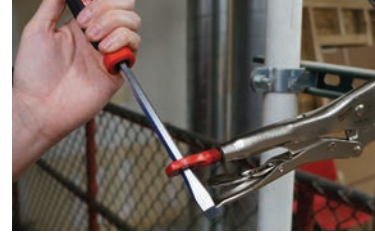

### LOCKING PLIERS WITH MAX BITE™

#### MAX BITE™ 3X GRIPPING FORCE



7"



10"

Part #	Description
48-22-3607	7" Curved Jaw Locking Pliers with MAX BITE™
48-22-3610	10" Curved Jaw Locking Pliers with MAX BITE™

### LOCKING PLIERS



Part #	Description
48-22-3405	5" Curved Jaw Locking Pliers With Grip
48-22-3406	6" Long Nose Locking Pliers With Grip
48-22-3407	7" Curved Jaw Locking Pliers With Grip
48-22-3409	9" Long Nose Locking Pliers With Grip
48-22-3410	10" Curved Jaw Locking Pliers With Grip
48-22-3402	2 Pc 7" & 10" Curved Jaw Locking Pliers With Grip Set

Part #	Description
48-22-3420	10" Curved Jaw Locking Pliers
48-22-3506	6" Long Nose Locking Pliers
48-22-3507	7" Straight Jaw Locking Pliers
48-22-3510	10" Straight Jaw Locking Pliers
48-22-3602	2 Pc 6" Long Nose & 10" Curved Jaw Locking Pliers Set



### C-CLAMPS



Part #	Description
48-22-3521	11" Swivel Jaw Locking C-Clamp
48-22-3522	6" Swivel Jaw Locking C-Clamp
48-22-3531	11" Locking C-Clamp
48-22-3532	6" Locking C-Clamp

## ADJUSTABLE WRENCHES

**JAWS WON'T  
BACK OFF**  
*Proprietary Screw*

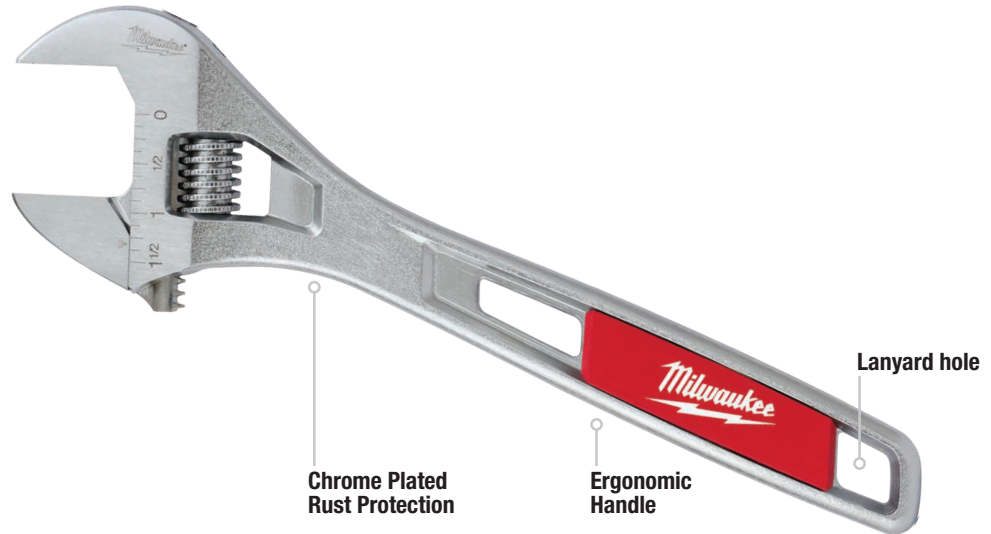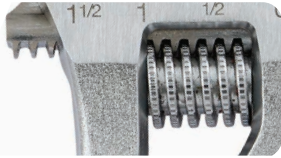

Perfectly Parallel Jaws

Part #	Description	Length
48-22-7400	2 Pc 6" & 10" Adjustable Wrench Set	6" & 10"
48-22-7406	6" Adjustable Wrench	6"
48-22-7408	8" Adjustable Wrench	8"
48-22-7410	10" Adjustable Wrench	10"
48-22-7412	12" Adjustable Wrench	12"
48-22-7415	15" Adjustable Wrench	15"
48-22-7508	8" Wide Jaw Adjustable Wrench	8"

## BASIN WRENCHES


**EASIEST  
SWAP-OUTS**



Ratchet-Ready—  
Less Jaw Readjusting



Screwdriver-Ready—  
Up to 2X Breakaway Torque

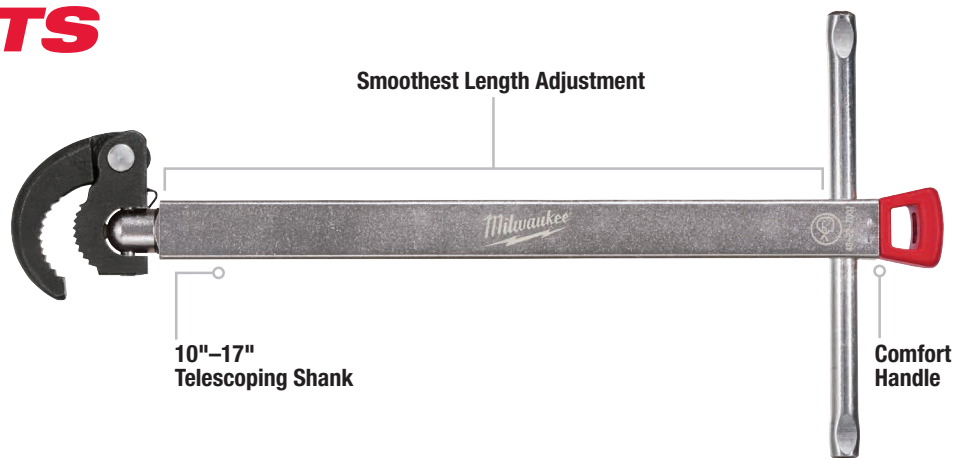

Part #	Description	Capacity
48-22-7001	1-1/4" Basin Wrench	1-1/4"
48-22-7002	2-1/2" Basin Wrench	2-1/2"