

# ComPoint® Intercom Systems



## ISK2 Advanced Keypad

Single-gang Decora style keypad. 5-character LCD display, assignable zone names and volume level. Select zones and door stations, controls receive volume, sets “do not disturb”. Internal microphone with automatic gain control. Built-in amplifier powers one or two external speakers. Speaker relay to share speakers with an audio system for communications. 110 punch-down. Installer-selectable amber or green backlighting. Wall plate and speakers not included.



Dimensions:  
1.875" W x 4" H x 2.625" D  
(4.8 x 10.2 x 6.7 cm)

Shipping Weight: 5.6 oz (159 g)

2300-525384 ISK2 White



## ISK3-AB Door Station

Weather-resistant call station fits a single-gang deep wall box. Solid metal cover plate mounts flush to exterior wall. Internal microphone with automatic gain control. Built-in amplifier and speaker. 110 punch-down connector for CAT-5 cable. Internal relay with screw terminals for connecting to an external doorbell. Amber backlit call key. Maximum 2 door stations per system.



Dimensions:  
3" W x 5.125" H x 3" D  
(7.6 x 13.0 x 7.6 cm)

Shipping Weight: 9 oz (0.26 kg)

2300-525407 ISK3 Antique Brass



## ISSP ComPoint Speaker


Single-gang Decora-style in-wall speaker. Installs beside a ComPoint keypad in double-gang wall box. Allows ComPoint to be used as a stand-alone system. High-quality driver in the ISSP is ideally matched to the keypad amplifier. Moisture-resistant design is suitable for bathrooms and kitchens. Wall plate not included.



Dimensions:  
3" W x 5.125" H x 3" D  
(7.6 x 13.0 x 7.6 mm)

Shipping Weight: 8 oz (227 g)

2300-528279 ISSP

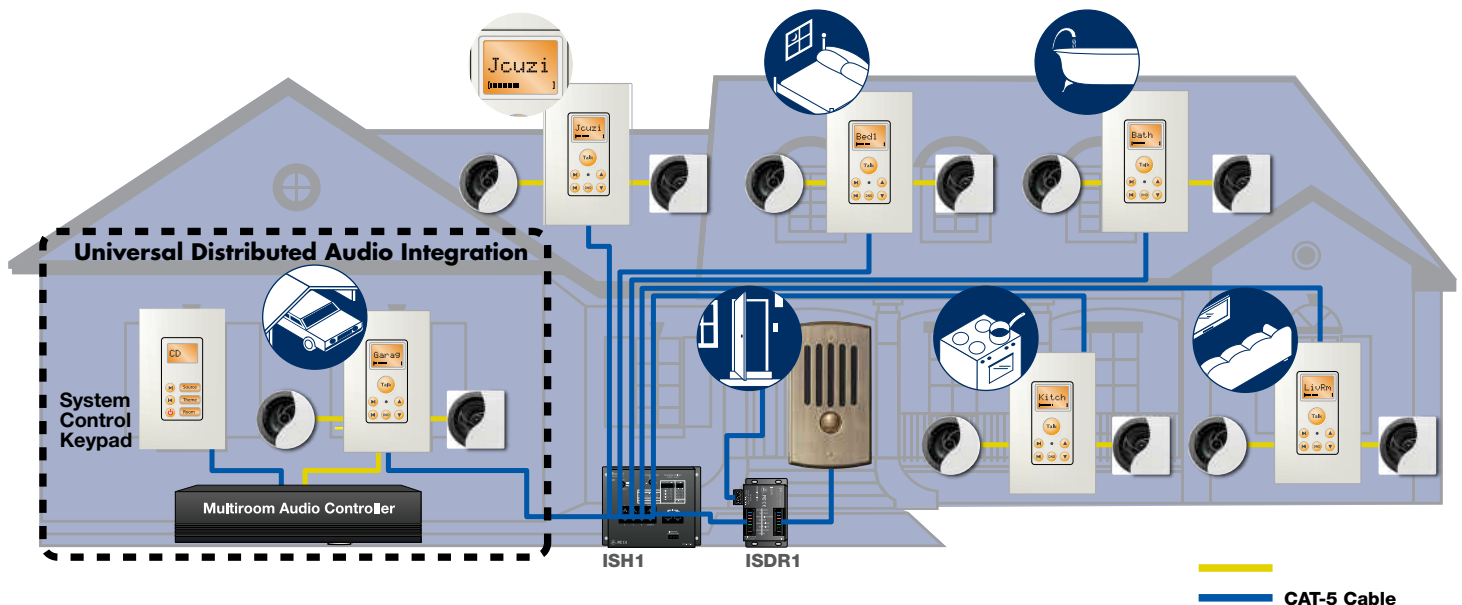

## ComPoint Intercom Systems



### ISH1 ComPoint Hub

6-zone surface- or panel-mount controller. Up to 6 hubs can link together for a total of 36 zones. Supports 2 door and provides 7 doorbell chimes, individually selectable for each door. Gain control for doorbell chime and alert tone volume. RJ-45 connectors for keypads, door stations, and hub linking. Firmware updatable. Power supply not included.



Dimensions:  
6" W x 5" H x 2" D  
(152 x 127 x 51 mm)

Shipping Weight: 2 lbs (0.9 kg)

**2300-526459 ISH1**



### ISDR1 Door Strike Release Module

Surface-mount module connects in a secure location in line with the CAT-5 cable between the hub and a door station to provide relay contacts for a third-party door strike release or other device. 110 punch-down connector for CAT-5 cable. Screw terminals for access to common, NC and NO relay contacts. Relay rated for 1 A @ 12 VDC.



Dimensions: 3" W x 1.875" H x 1" D (7.6 x 4.8 x 2.5 cm)

Shipping Weight: 9 oz (0.12 kg)

**2300-525445 ISDR1**



### ISPS Power Supply

15V DC 3.5A. Autosensing 100V-240VAC, detachable power cord, compact size.



Dimensions:  
4.56" W x 1.93" H x 1.33" D (115.8 x 49 x 33.8 mm)

Shipping Weight: 1lb (0.5 kg)

**2300-526282 ISPS**  
**2300-526763 ISPS-EU**  
**2300-526770 ISPS-UK**



### Advanced Programming Cable

Advanced programming cable for ComPoint components (ISK1, ISK2, ISK3, ISH1). Female DB-9 connection (PC end) and flat device pin connection (device end)



Length: 72" (182.9 cm)

Shipping Weight: 1 lb (0.45 kg)

**2500-521065**