


## Straps for Nonmetallic-Sheathed (NM) and Underground Feeder (UF) Cable

CAT. NO.	MAXIMUM CABLE SIZE	COLOR	PACKAGE AND QUANTITY	STD. CARTON QUANTITY	APPROX. SHIPPING WT. PER CARTON
<b>1/2" STRAP FOR 2, 3, AND 4 WIRE NM CABLE UP TO 10/3, UF CABLE UP TO 12/2, AND OTHER CABLE UP TO .500" WIDE</b>					
RA-1470P	1/2"	White	Plastic Bag of 50	2000	10 lbs.
RA-1477P	1/2"	White	Plastic Bag of 100	1000	5 lbs.
RA-1577	1/2"	White	Box of 100	1000	5 lbs.
RA-1580	1/2"	White	Bulk	5000	23 lbs.
RA-1581	1/2"	White	Plastic Pail of 1000	1000	5 lbs.
RA-1582	1/2"	White	Plastic Pail of 2000	2000	11 lbs.
RA-1585	1/2"	White	Plastic Pail of 5000	5000	24 lbs.
RA-1588 or RA-1588UV	1/2"	White Black	Kraft Bag of 500	5000	24 lbs.
<b>1/2" STACKER STRAPS FOR SECURING MORE THAN ONE NM OR UF CABLE</b>					
<ul style="list-style-type: none"> <li>Secure combinations of NM and UF Cable to narrow structural members with one strap.</li> <li>The height of these straps has been reduced to better fit the new, smaller NM and UF Cable.</li> <li>Color coded for easy identification.</li> </ul>					
<b>For two 2 wire NM or UF Cables stacked up to 3/8" high</b>					
RA-1588/2	1/2"	Tan	Box of 50	500	5 lbs.
RA-1582/2	1/2"	Tan	Plastic Pail of 1000	1000	10 lbs.
<b>For three 2 wire cables or combinations of 2, 3, &amp; 4 wire cables stacked up to 1/2" high</b>					
RA-1588/3	1/2"	Gray	Box of 50	500	5 lbs.
RA-1582/3	1/2"	Gray	Plastic Pail of 1000	1000	10 lbs.
<b>For four 2 wire cables or combinations of 2, 3, &amp; 4 wire cables stacked up to 11/16" high</b>					
RA-1588/4	1/2"	White	Box of 50	500	6 lbs.
RA-1582/4	1/2"	White	Plastic Pail of 1000	1000	11 lbs.
<b>5/8" STRAP FOR 10/2 NM AND UF CABLE, 14/3 UF CABLE, AND OTHER CABLE UP TO .625" WIDE</b>					
RA-6250	5/8"	White	Box of 100	1000	6 lbs.

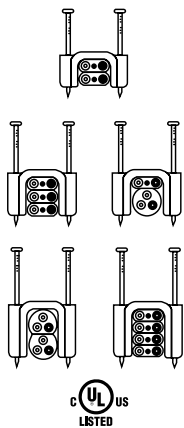

## Straps for Nonmetallic-Sheathed and Underground Feeder Cable [Con't.]



CAT. NO.	MAXIMUM CABLE SIZE	COLOR	PACKAGE AND QUANTITY	STD. CARTON QUANTITY	APPROX. SHIPPING WT. PER CARTON
<b>3/4" STRAP FOR 2 WIRE NM AND UF CABLE UP TO NO. 8, 3 WIRE UF CABLE UP TO NO. 12, AND OTHER CABLE UP TO .750" WIDE</b>					
RA-1450P	3/4"	White	Plastic Bag of 50	2000	11 lbs.
RA-1455P	3/4"	White	Plastic Bag of 100	1000	5 lbs.
RA-1555	3/4"	White	Box of 100	1000	6 lbs.
RA-1560	3/4"	White	Bulk	5000	25 lbs.
RA-1562	3/4"	White	Plastic Pail of 1500	1500	8 lbs.
RA-1566 or RA-1566UV	3/4"	White Black	Kraft Bag of 250	5000	26 lbs.

NEW



<b>STRAPS FOR 3 AND 4 WIRE NM CABLE</b>					
<ul style="list-style-type: none"> <li>We have revised our 1600 Series to better fit the new, smaller 3 and 4 wire NM Cable.</li> </ul>					
For 14/3, 12/3, and 14/4 NM Cable and other cable up to 5/16" (.312) Dia.					
RA-1610R	5/16" Dia.	White	Box of 100	1000	6 lbs.
For 10/3 and 12/4 NM Cable and other cable up to 13/32" (.406) Dia.					
RA-1620R	13/32" Dia.	White	Box of 100	1000	6 lbs.
For 8/3 NM Cable and other cable up to 1/2" (.500) Dia.					
RA-1630R	1/2" Dia.	White	Box of 100	1000	6 lbs.
For 6/3 NM Cable and other cable up to 9/16" (.562) Dia.					
RA-1640R	9/16" Dia.	White	Box of 50	500	5 lbs.
For other round cable and tubing up to 5/8" (.625) Dia.					
RA-1650R	5/8" Dia.	White	Box of 50	500	6 lbs.



<b>STRAPS FOR UF CABLE</b>					
<ul style="list-style-type: none"> <li>The standard color is gray with a UV stabilizer.</li> <li>For prolonged outdoor exposure, black colored straps with a UV stabilizer are also available.</li> </ul>					
For 8/3 UF Cable					
UF-2040	.336" x 1.077"	Gray	Box of 50	1000	13 lbs.
For 6/3 UF Cable					
UF-2050	.400" x 1.300"	Gray	Box of 50	1000	17 lbs.

NEW

## Straps for Armored Cable (AC) & Metal-Clad (MC) Cable



For AC & MC Cable from 3/8" (.375) to 1/2" (.500) Dia.					
ACMC-10	1/2" Dia.	Gray	Box of 50	500	5 lbs.
For AC & MC Cable from 1/2" (.500) to 5/8" (.625) Dia.					
ACMC-20	5/8" Dia.	Gray	Box of 50	500	6 lbs.

## Straps for Service Entrance Cable and EMT



CAT. NO.	MAXIMUM CABLE OR PIPE SIZE	COLOR	PACKAGE AND QUANTITY	STD. CARTON QUANTITY	APPROX. SHIPPING WT. PER CARTON
			<b>For #6 SER (4 Conductor) and 1/2" EMT</b>		
RA-1710	.718" Dia.	Gray	Box of 50	1000	16 lbs.
			<b>For #2 SER (4 Conductor) and 3/4" EMT</b>		
RA-1720	.937" Dia.	Gray	Box of 25	500	13 lbs.
			<b>For #1/0 SER (4 Conductor)</b>		
RA-1724	1.062" Dia.	Gray	Box of 25	500	15 lbs.
			<b>For #2/0 SER (4 Conductor) and 1" EMT</b>		
RA-1730	1.160" Dia.	Gray	Box of 25	500	16 lbs.
			<b>For #4/0 SER (4 Conductor)</b>		
RA-1740	1.438" Dia.	Gray	Box of 10	200	9 lbs.
<ul style="list-style-type: none"> <li>• The standard color is gray with a UV stabilizer.</li> <li>• For prolonged outdoor exposure, black colored straps with a UV stabilizer are also available.</li> </ul>					
			<b>For #6 SEU (3 Conductor)</b>		
RA-1750	.437" x .750"	Gray	Box of 100	2000	21 lbs.
			<b>For #2 SEU (3 Conductor)</b>		
RA-1760	.550" x .972"	Gray	Box of 50	1000	17 lbs.
			<b>For #2/0 SEU (3 Conductor)</b>		
RA-1765	.775" x 1.265"	Gray	Box of 25	500	16 lbs.
			<b>For #4/0 SEU (3 Conductor)</b>		
RA-1770	.855" x 1.500"	Gray	Box of 25	500	18 lbs.



## 2-Hole Plastic Straps for Electrical Plastic Conduit



PC-1210	1/2" EPC .840" Dia.	Gray	Box of 50	1000	10 lbs.
PC-1220	3/4" EPC 1.050" Dia.	Gray	Box of 50	1000	11 lbs.
PC-1230	1" EPC 1.312" Dia.	Gray	Box of 25	500	11 lbs.
PC-1240	1-1/4" EPC 1.670" Dia.	Gray	Box of 25	500	12 lbs.

## Protective Handy Plates



- Protect electrical cables passing through wood framing members.
- Conform to requirements of the National Electrical Code.

SA-10015	3" x 1-1/2" x 16 ga.	—	Box of 100	500	38 lbs.
----------	----------------------	---	------------	-----	---------