
 


 


Ground blocks with tension spring connection


WKFN 10 SL/35


- Ground block with tension spring connection for mounting on TS 35
- Nominal cross section 10 mm²
- Ex e I/II  II 2GD IM2
Follow the EX installation instructions on page 149

 
 

 


Description	Type	Part No.	Std. Pack
Ground block, green/yellow	WKFN 10 SL/35	56.710.9055.0	50
General data			
Width / length / height, incl. TS 7.5	10 mm / 72 mm / 50 mm		
Wire strip length	15 mm		
Approvals	PTB    PTB 06 ATEX 1075 U		
Technical data	IEC	UL	CSA 
	EN 60 947-7-2		EN 60 079-0/-7
Cross section fine-stranded	0.2–10 mm ²		0.2–10 mm ²
Cross section solid/stranded	1.5–16 mm ²		1.5–16 mm ²
Cross section, AWG		16–6	16–6
Rated current			
Rated voltage	1000 V	600 V	600 V
Rated impulse voltage	8 kV		
Pollution degree	3		
Accessories			
End plate, gray	APFN 10/35	07.313.0855.0	10


WKFN 10 D1/2/SL/35


- Duo ground block with tension spring connection for mounting on TS 35
- Nominal cross section 10 mm²
- Ex e I/II  II 2GD IM2
Follow the EX installation instructions on page 149

 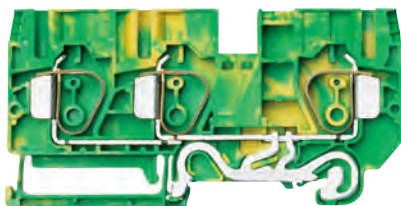


 


Description	Type	Part No.	Std. Pack
Ground block, green/yellow	WKFN 10 D1/2/SL/35	56.710.9355.0	50
General data			
Width / length / height, incl. TS 7.5	10 mm / 98 mm / 50 mm		
Wire strip length	15 mm		
Approvals	PTB    PTB 06 ATEX 1075 U		
Technical data	IEC	UL	CSA 
	EN 60 947-7-2		EN 60 079-0/-7
Cross section fine-stranded	0.2–10 mm ²		0.2–10 mm ²
Cross section solid/stranded	1.5–16 mm ²		1.5–16 mm ²
Cross section, AWG		16–6	
Rated current			
Rated voltage	1000 V		600 V
Rated impulse voltage	8 kV		
Pollution degree	3		
Accessories			
End plate, gray	APFN 10 D1/2	07.313.1055.0	10

WKFN 16 SL/35

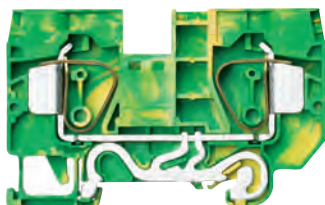- Ground block with tension spring connection for mounting on TS 35
- Nominal cross section 16 mm²
- Ex e I/II  II 2GD IM2
Follow the EX installation instructions on page 149



Description	Type	Part No.	Std. Pack
Ground block, green/yellow	WKFN 16 SL/35	56.716.9055.0	50
General data			
Width / length / height, incl. TS 7.5	12 mm / 79 mm / 50 mm		
Wire strip length	16 mm		
Approvals	PTB    PTB 06 ATEX 1075 U		
Technical data	IEC	UL	CSA 
	EN 60 947-7-2		EN 60 079-0/-7
Cross section fine-stranded	0.2–16 mm ²		0.2–16 mm ²
Cross section solid/stranded	1.5–25 mm ²		1.5–25 mm ²
Cross section, AWG		16–4	16–4
Rated current			
Rated voltage	1000 V	600 V	600 V
Rated impulse voltage	8 kV		
Pollution degree	3		
Accessories			
End plate, gray	APFN 16	07.313.1255.0	10