

Specifications

ISK3 Door Station



User control: Call key with amber backlight
 Volume control: Installer-adjustable potentiometer
 CAT-5 connector: 110 punch-down block
 Available finishes: Antique brass, brushed chrome
 Overall dimensions: 3" W x 5.125" H x 3.25" D
 (7.6 x 13.0 x 8.3 cm)
 Wall box required: Single gang, 22 cu in
 (360 cm³) minimum volume
 Weight: 8 oz (227 g)

ISK4 Camera Door Station



User control: Call button with amber backlight
 Audio input: Built-in microphone with automatic gain control
 Amplifier: Monaural (for system functions only)
 Amplifier power: 2 watts
 Volume control: Installer-adjustable potentiometer
 Audio output: Built-in speaker
 Video output: Composite, 75 ohms unbalanced
 Camera resolution: 600 horizontal lines, black and white
 Camera sensitivity: 0.1 lux minimum illumination
 Cover plate: Weatherproof plated die-cast zinc
 Intercom CAT-5 connector: 110 punch-down block
 Doorbell connector: 2-pole screw terminal
 Doorbell wire size: Up to 18 AWG (1.024 mm)
 Doorbell contact: 1 A @ 12 VDC
 Door station power requirement: 15 VDC 220 mA maximum (provided from ComPoint hub)
 Camera power requirement: 12 VDC regulated, 100 mA (use Russound 846C power supply)
 Dimensions: 4.8" W x 5.8" H x 2.9" D
 (12.1 x 14.8 x 7.3 cm)
 Fits UL/CSA-approved double-gang 32 ci (524 cm³) wall box
 Weight: 15.8 oz (448 g)

ISDR1 Door Strike Release Module



CAT-5 connectors: (2) 110 punch-down blocks
 Strike release relay: 1-pole double-throw (NC/NO)
 Relay contact rating: 5 A @ 12 VDC
 Mounting method: Surface
 Dimensions: 3" W x 1.875" H x 1" D
 (7.6 x 4.8 x 2.5 cm)
 Weight: 4.8 oz (136 g)

ISK1 Basic Keypad



User controls: 6 zone selection/indication keys
 Talk key
 2 door selection/indication keys
 DND selection/indication key
 Volume Up and Volume Down keys
 Key backlighting: Installer-selectable amber or green, with red function indication
 Min. load impedance: 6 ohms per channel
 Speaker relay: 4-pole double-throw
 Speaker relay rating: 50 watts RMS continuous
 Speaker wire size: Up to 14 AWG (1.63 mm)
 CAT-5 connector: 110 punch-down block
 Keypad style: Single-gang Decora®
 Available colors: White, almond, bone, brown, black
 Dimensions: 1.875" W x 4.188" H x 2.5" D
 (4.8 x 10.6 x 6.4 cm)
 Weight: 4.8 oz (136 g)

ISK2 Advanced Keypad



Display: 5-character backlit LCD panel
 User controls: Talk key
 Next and Previous keys
 DND selection/indication key
 Volume Up and Volume Down keys
 Backlighting: Installer-selectable amber or green, with red function indication
 Min. load impedance: 6 ohms per channel
 Speaker relay: 4-pole double-throw
 Speaker relay rating: 50 watts RMS continuous
 Speaker wire size: Up to 14 AWG (1.63 mm)
 CAT-5 connector: 110 punch-down block
 Keypad style: Single-gang Decora®
 Available colors: White, almond, bone, brown, black
 Dimensions: 1.875" W x 4.188" H x 2.625" D
 (4.8 x 10.6 x 6.7 cm)
 Weight: 5.6 oz (159 g)

ISH1 Hub



Keypad ports: (6) 8-pole modular RJ-45
 Door station ports: (2) 8-pole modular RJ-45
 Link ports: (2) 8-pole modular RJ-45
 Doorbell options: 7 selectable chime patterns plus no chime
 Mounting method: Surface or structured wiring panel
 Dimensions: 6.438" W x 5.125" H x 1.813" D
 (16.4 x 13.0 x 4.6 cm)
 Weight: 25.6 oz (0.73 kg)

ISSP Speaker

 


Device: Single-gang Decora®
 Grille: Perforated aluminum
 Driver: 1.25" x 2.5" (3.2 x 6.4 cm) water resistant treated paper cone
 Connection: Attached wire leads
 Power rating: 2 watts nominal, 5 watts maximum
 Impedance: 8 ohms
 Sensitivity: 86 dB SPL ± 3 dB at 1 watt/1 meter
 Frequency response: 240 Hz - 15 kHz ± 10dB
 Dimensions: 1.65" W x 4.13" H x 1.42" D
 (4.2 x 10.5 x 3.6 cm)
 Weight: 3 oz (85 g)

ComPoint System


Maximum zones: 36 (up to 6 hubs)
 Door stations: 2 maximum
 Communications cable: CAT-5/CAT-5e
 Maximum cable length: 250 feet (76 m)

Available keypad colors



Visit us online

For more information or product demonstrations on the Russound ComPoint Intercom system, or other multiroom audio-video systems and accessories, please our website at www.russound.com.

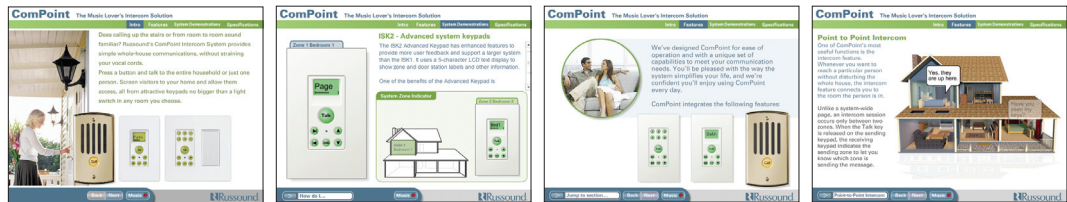

ComPoint interactive demo.



5 Forbes Road, Newmarket, New Hampshire 03857 USA

603.659.5170

www.russound.com

Since 1967, innovation, quality and reliability have been the core of the Russound product tradition. Today, Russound offers everything for enjoying multiroom audio-video in your home. All audio-video distributed solutions are built to high standards and designed with the unique consideration of making products that are a pleasure to live with and enjoy.

©2008 Russound. All rights reserved. All trademarks are the property of their respective owners. Specifications are subject to change without notice. Russound is not responsible for typographical errors or omissions.

LR2300-0002 06/08