



RS12-60KO Transformer



FEATURES



- Electronic transformer
- Class 2 approved
- 10.5oz. (300g)
- 50°C maximum ambient temperature
- 90°C maximum case temperature
- 120V, 50/60Hz input @ 0.5A
- 11.75Vac, 40kHz output @ 5A
- 60W maximum load
- 10W minimum load without dimming
- 20W minimum load with dimming
- 0.95 power factor
- Electronic internal resettable protection, patented auto heat regulation that also automatically acts as over load protection, auto-rest thermal cut-off @ 125°C




RS12-60KO-Specs • Subject to change without notice • Rev 2018.07.09 • 1/3

Features

 
DIMENSIONS

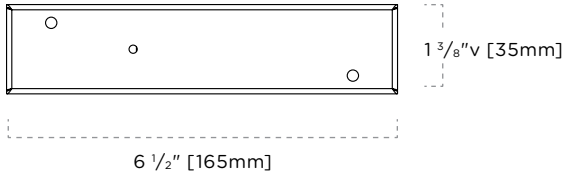

OUTPUT VOLTAGE VS. LOAD @ 120V

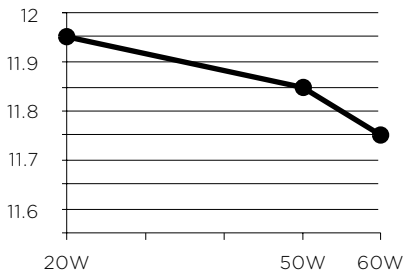

OUTPUT VOLTAGE VS. INPUT @ MAX LOAD

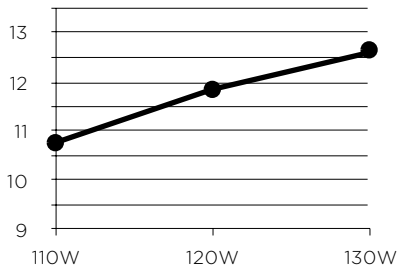

RS12-60KO Transformer

Project

Type

Notes

Product Code

1

2

1. Transformer

RS12-60KO

2. Voltage

120

RS12-60KO-Specs • Subject to change without notice • Rev 2018.07.09 • 3/3
