



2-120-T Aurora MR16



With a myriad of reflector, trim, and color temperature combinations, Aurora blends discretely with any décor. The 2 1/2" regressed lamp delivers high lumens without glare, while 35° aiming increases flexibility in locating luminaires.

FEATURES

- Utilizes MR16
- 35° aiming
- Die-cast aluminum fixture
- Powder coated and plated trim ring finishes
- Trim clips designed for 5/8" ceiling thickness
- Accepts up to 2 optional media
- Clear glass lens included
- Trimless version available (see separate specifications)

DETAILS


Trim Class: 4"
Category: Recessed Downlight
Shape: Round
Adjustability: Tilt




2-120-T-Aurora-MR16-Specs • Subject to change without notice • Rev 2018.11.16 • 1/4

Features & Lighting

DIMENSIONS

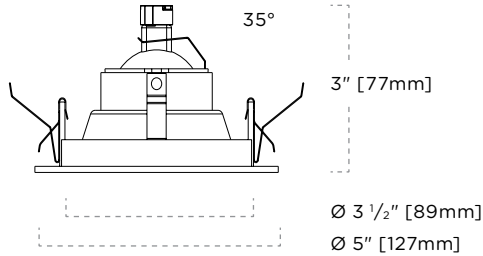

CEILING CUTOUT

 

FLANGE FINISHES

- White
- Chrome Plated
- Black
- Matte Silver
- Bronze
- Gold Plated
- Matte Nickel

REFLECTOR FINISHES

- Black Open
- Black Specular
- Black Stepped Baffle
- Champagne Specular
- Copper Specular
- Gold Specular
- Mocha Brushed
- Silver Specular
- White Open
- White Stepped Baffle
- Champagne Satin
- Copper Satin
- Gold Satin
- Nickel Satin
- Silver Satin

2-120-T-Aurora-MR16-Specs • Subject to change without notice • Rev 2018.11.16 • 2/4

2-120-T Aurora MR16

Project

Type

Notes

Product Code

1 2 3 4 5 6

1. Trim

2-120-T Aurora

2. Lamp

MR16 Halogen

3. Flange Finish

- 01** White
- 02** Chrome Plated
- 04** Black
- 05** Matte Silver
- 06** Bronze
- 09** Gold Plated
- 11** Matte Nickel
- CC** Custom Color¹

4. Reflector Finish

- BLO** Black Open
- BA** Black Specular
- BLS** Black Stepped Baffle
- CHA** Champagne Specular
- CHAS** Champagne Satin
- COPA** Copper Specular
- COPAS** Copper Satin
- GA** Gold Specular
- GAS** Gold Satin
- MOCH** Mocha Brushed
- NICS** Nickel Satin
- SA** Silver Specular
- SAS** Silver Satin
- WHO** White Open
- WHS** White Stepped Baffle

5. Optional Media (2 Maximum)

- CL** Clear
- EL** Elongating
- FRO** Frosted
- HC** Honeycomb
- PER** Perimeter Frosted
- SL** Solite Softening
- SPDL** Spread

6. Options

- EXT** Extension Clips (Maximum 2")

Notes

¹ CC custom color requires consultation with Lightheaded sales personnel.

2-120-T-Aurora-MR16-Specs • Subject to change without notice • Rev 2018.11.16 • 4/4