

## 2-550-T Nemo XTM



The small Nemo trim, with its sealed and flush glass face, brings nuanced architectural lighting to wet locations: baths, covered walkways, entryways, and outdoor living spaces. The Xicato module produces a light consistency within 2 SDCM (MacAdam Ellipse).

### FEATURES

- Utilizes Xicato XTM LED
- Lumen output: 700-2700
- Wet location listed
- Die-cast aluminum fixture
- Powder coated and plated trim ring finishes
- Trim clips designed for 5/8" ceiling thickness
- Accepts up to 2 optional media
- L80 @ 50,000 hours

### DETAILS


Trim Class: 4"  
Category: Recessed Downlight  
Shape: Square  
Adjustability: Fixed




2-550-T-Nemo-XTM-Specs • Subject to change without notice • Rev 2016.12.19 • 1/6

# Features & Lighting

## 3 SERIES

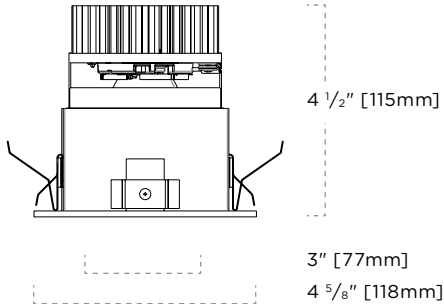


## 5, 7 & 9 SERIES

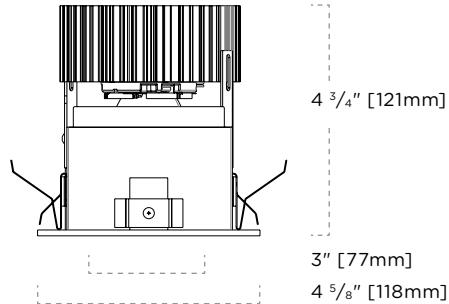


### 24 TITLE 24 COMPLIANT
 
### CEILING CUTOUT



### BEAM SPREADS

 

### FLANGE FINISHES

- White
- Chrome Plated
- Black
- Matte Silver
- Bronze
- Matte Nickel

### GLASS

- Frosted
- Clear

### COLOR TEMPERATURES

- 2700
- 2700 Beauty
- 3000
- 3000 Vibrant
- 3500
- 4000

### CRI & LUMENS

SERIES	3		5		7		9	
CRI VALUE	83	98	83	98	83	98	83	98
LUMEN OUTPUT	1000	700	1500	1000	2000	1300	2700	2100
LED WATTAGE	10	9	14	12	20	17	24	24
TITLE 24	—	24	—	24	—	—	—	—

# 2-550-T Nemo XTM

Project

Type

Notes

Product Code

1	2	3	4	5	6	7	8	
<b>1. Trim</b> <b>2-550-T</b> Nemo				<b>5. Color Temperature</b> <b>27</b> 2700K <b>30</b> 3000K <b>35</b> 3500K <b>40</b> 4000K <b>BM27</b> Beauty 2700K <sup>2</sup> <b>VB30</b> Vibrant 3000K		<b>7. Optional Media (2 Maximum)</b> <b>CL</b> Clear <b>EL</b> Elongating <b>FRO</b> Frosted <b>HC</b> Honeycomb <b>PER</b> Perimeter Frosted <b>SL</b> Solite Softening <b>SPDL</b> Spread		
<b>2. Flange Finish</b> <b>01</b> White <b>02</b> Chrome Plated <b>04</b> Black <b>05</b> Matte Silver <b>06</b> Bronze <b>11</b> Matte Nickel <b>CC</b> Custom Color <sup>1</sup>				<b>6. CRI, Lumens, Series</b> <b>8310</b> 83 CRI, 1000 lm, 3 Series <b>9807</b> 98 CRI, 700 lm, 3 Series <b>8315</b> 83 CRI, 1500 lm, 5 Series <b>9810</b> 98 CRI, 1000 lm, 5 Series <sup>3</sup> <b>8320</b> 83 CRI, 2000 lm, 7 Series <b>9813</b> 98 CRI, 1300 lm, 7 Series <b>8327</b> 83 CRI, 2700 lm, 9 Series <b>9821</b> 98 CRI, 2100 lm, 9 Series		<b>8. Options</b> <b>WP</b> White Trim Interior <sup>4</sup>		
<b>3. Glass</b> <b>C</b> Clear Glass <b>F</b> Frosted Glass								
<b>4. Module &amp; Beam Spread</b> <b>XTM28</b> 28° Beam <b>XTM40</b> 40° Beam <b>XTM60</b> 60° Beam								

Notes

<sup>1</sup> **CC** custom color requires consultation with Lightheaded sales personnel.

<sup>2</sup> **WP** white trim interior. Trim interior is painted black standard.

<sup>3</sup> **BM27** beauty color temperature is only available in **9807, 9810, 9813**.

<sup>4</sup> When selecting a housing, 5 series L, LE and LH dimming is not available in Title 24.