


If you don't see it, call us. We can make it and ship it within 24 hours!


Hangers and Straps

All-Round Strapping

1001 Uses!

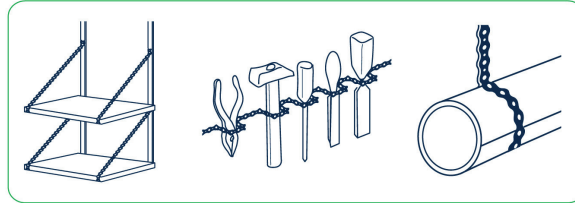

Handy Dispenser Carton

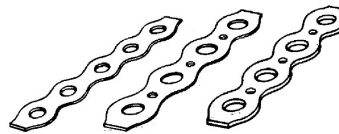

1/2" - 22GA | 3/4" - 24GA | 3/4" - 20GA

- 1/2" straps have 3/16" bolt holes
- 3/4" straps have large holes for 1/4" bolts and small holes for screw or nails.

GALVANIZED STEEL

Description	Max Load lbs	Part Number	List US\$
1/2" x 25' 24 Gauge	95	9049	5.92
3/4" x 10' 24 Gauge	130	9043	3.09
3/4" x 25' 24 Gauge	130	9047	6.46
3/4" x 100' 24 Gauge	130	9048	22.61
3/4" x 25' 20 Gauge	210	9040	7.10
3/4" x 100' 20 Gauge	210	9045	29.30

NYLON COATED (Galvanized Steel)

Description	Max Load lbs	Part Number	List US\$
1/2" x 10' 24 Gauge	110	9090	8.73
1/2" x 25' 24 Gauge	110	9080	20.48
3/4" x 25' 24 Gauge	130	9085	21.54

SOLID COPPER

Description	Max Load lbs	Part Number	List US\$
1/2" x 10' 22 Gauge	60	9053	11.55
1/2" x 25' 22 Gauge	60	9050	24.25
3/4" x 25' 24 Gauge	55	9060	25.83
3/4" x 25' 20 Gauge	130	9070	37.90

STEEL

Description	Max Load lbs	Part Number	List US\$
1/2" x 10' 22 Gauge	110	9015	2.88
1/2" x 25' 22 Gauge	110	9010	4.25
3/4" x 10' 24 Gauge	130	9021	2.98
3/4" x 25' 24 Gauge	130	9020	5.03
3/4" x 100' 24 Gauge	130	9025	19.93
3/4" x 25' 20 Gauge	210	9030	7.50
3/4" x 100' 20 Gauge	210	9035	28.80
1/2" x 100' 22 Gauge	110	90100	25.40

* INDICATED MAXIMUM LOAD IS APPROXIMATELY 1/3 OF BREAKING LOAD FOR SINGLE STRAPS.

ANG = Angle, STR = Straight, CP = Chrome Plated, RB = Rough Brass