



## SPLITTER BOXES TYPE 3R


### FEATURES AND BENEFITS

- CSA Type 3R Enclosure (Weatherproof)
- Screw on lift off cover c/w padlock provision
- Cu/Al lugs with main and 6x secondaries
- Designed for post or wall mounting
- Rural service box
- Galvanized steel construction
- Non-powder coated finish
- 600V Rating
- Ground lug type A (See page 9)

### OPTIONS AVAILABLE (Consult Factory)

- Steel, stainless steel, or aluminum construction
- Custom sizes
- Custom cutouts
- Custom lugs
- Higher Amperages

**STOCKED ITEM**

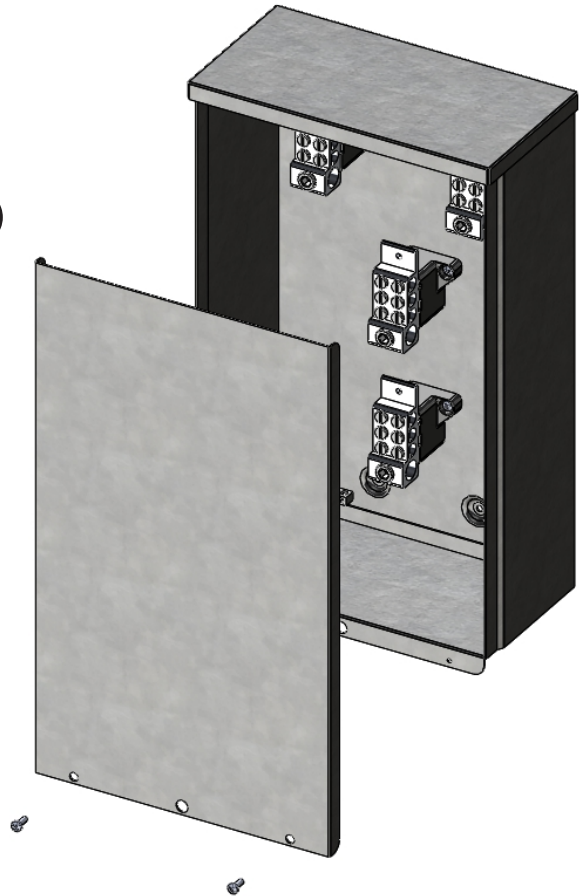

\* 4W Indicates 4 Wire

Model #	Amp	Mains	Secondaries	Description
APS 100	125	(1) #14 to 1/0	#14 to #2	14"H x 9"W x 3 1/2"D
APS 100-4W	125	(1) #14 to 1/0	#14 to #2	18 1/4"H x 9"W x 3 1/2"D
APS 200	225	(1) #6 to 300 MCM	#14 to 2/0	14"H x 11"W x 5 1/2"D
APS 200-OS	225	(1) #6 to 300 MCM	#14 to 2/0	18 1/4"H x 11"W x 5 1/2"D
APS 200-4W	225	(1) #6 to 300 MCM	#14 to 2/0	18 1/4"H x 11"W x 5 1/2"D
APS 200M	225	(2) #6 to 300 MCM	#14 to 2/0	14"H x 11"W x 5 1/2"D
APS 400	400	#4 to 600 MCM or (2) 250 MCM to 1/0	4) #6 to 4/0 2) #14 to 3/0	20"H x 16"W x 7"D
APS 400-4W	400	#4 to 600 MCM or (2) 250 MCM to 1/0	4) #6 to 4/0 2) #14 to 3/0	24"H x 16"W x 7"D

