



## VAKS100CG WEATHER PROOF

*The VAKS100CG fixture is weather proof rated for use indoors and outdoors. Great for use in industrial applications or for residential and commercial applications where you want an industrial look with a bit of flair with a painted finish and coloured glass. For custom versions of this and other weather proof fixtures please visit our web site and look under architectural in the products section.*

**BOX** Cast zinc with 3 plugs 1/2" npt (also available with 3/4" npt), ground screw and cork gasket.

**FITTER** Threaded die cast with cork gaskets.

**SOCKET** Porcelain, medium base, 4KV pulse rated socket with a nickle-plated screw shell and a spring-loaded centre contact.

**GLOBE** Standard unit comes with clear globe, also available are clear prismatic, frosted and coloured globes. There are two types of coloured globes available. The GL glass is painted on the inside. The second type of glass is the RGL series, which has a more brilliant colour. This is achieved by having the colour added while the glass is being made. Both types of glass are available in the following colours amber, blue, green, red and white.

**GUARD** Die cast, threaded with set screw for locking guard in place.



**MAXIMUM WATTAGE** 100 watt incandescent.

**APPROVAL** CSA

**LAMP** Not included

**FINISH** Standard finish is raw. Also available with a powder coat paint finish. Some of the most common colours are black, red, white and blue. For other colours please consult factory.



[www.rabdesign.ca](http://www.rabdesign.ca)

## Catalog Code

**VAKS**

GL100 - CLEAR  
 GL100CL-RIB - PRISMATIC  
 GL100SB - FROSTED

### PAINTED GLOBES

GL100A - AMBER  
 GL100G - GREEN  
 GL100R - RED  
 GL100B - BLUE

### RGL GLOBES

RGL100A - AMBER  
 RGL100G - GREEN  
 RGL100R - RED  
 RGL100B - BLUE

IF RAW FINISH LEAVE BLANK


BLK - BLACK  
 RD - RED  
 WH - WHITE  
 BL - BLUE  
 CC - CUSTOM COLOUR

FINISH

**CG**

CG - CAST GUARD

## Dimensions

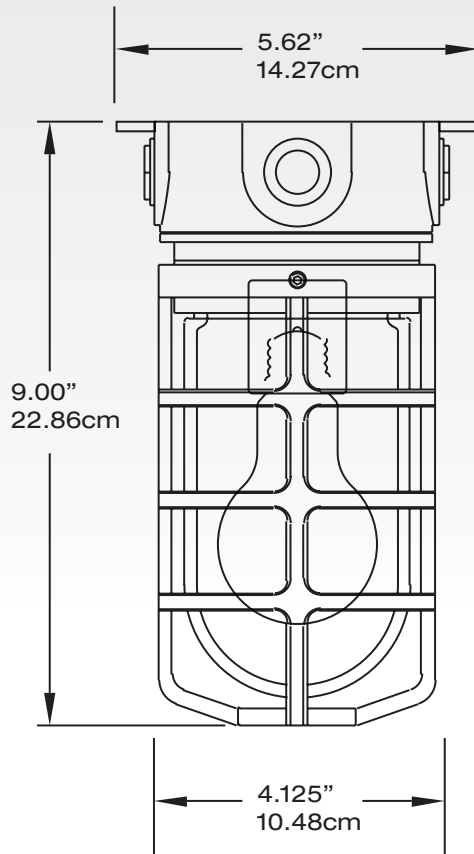

GL100  
CLEAR



GL100CL-RIB  
PRISMATIC



GL100SB  
FROSTED



GL100G  
GREEN



GL100A  
AMBER



GL100B  
BLUE



GL100R  
RED



RGL100A  
AMBER



RGL100G  
GREEN



RGL100R  
RED



RGL100B  
BLUE

