



## FW4-2T8 WET LOCATION FLUORESCENT

*The FW4 fluorescent fixture is designed for rough service and wet location applications. The FW4 has a low profile 3-3/4" (10cm) polycarbonate enclosure and lens, which is vandal resistant and UV stabilized. All hardware is rust proof. Ideal for tunnels, canopies, shipping docks, refrigerated areas or any non-hazardous environment that requires a wet location listing. Each unit is shipped with spare lens clips. Every box has a template for ease of marking for a faster installation. Also available in a 2 foot version T8 please see FW2-2T8. For a 4 foot version in T5 please see FW4-2T5.*

**HOUSING** Polycarbonate, UV stabilized. Conduit entries at either end.

**LENS** Polycarbonate, UV stabilized, and is retained to the housing with ten clips.

**REFLECTOR** Specular aluminum reflector and is tethered to the housing for ease of installation.

**BALLAST** Electronic instant start 120/277, 347 ballast for 2 T8 lamps. Ballast has quick disconnects for ease of ballast replacement.



**INSTALLATION** For ceiling, surface or pendant mounting.

**HARDWARE** All hardware is rust proof.

**LAMPS** Not included.

**OPTIONS** Stainless steel clips, shipped separately.

**APPROVAL** cULus

**RATING** IP65

## Catalog Code

FW4

2T8

2T8 - 32 watt T8 lamps\*


LAMP

120/277 - 120/277 electronic ballast

BALLAST 347 - 347 electronic ballast

\* Lamps not included

## Dimensions

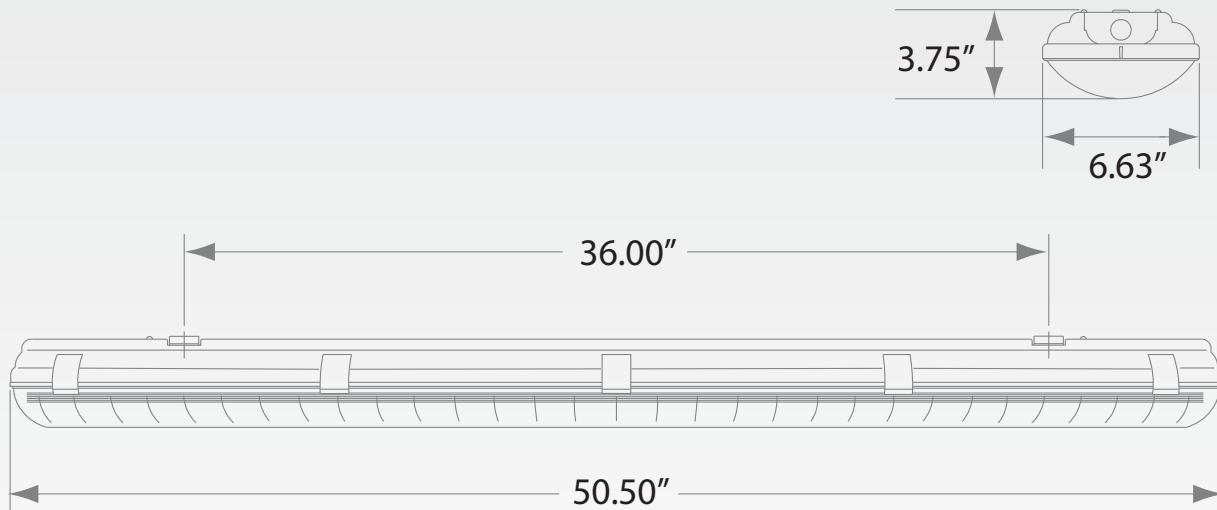

1208