



MS518-2 180 DEGREE OUTDOOR SENSOR

MS518-2 sensor has a 180 degree view and comes with 2 Par holders and mounting plate. Turns lights on from 5 seconds to 12 minutes. Unit can be wired in parallel. Whenever the motion sensor detects motion the floodlights automatically turn on. Tested at -20°C start temperature. Available in black or white.

PHOTOELECTRIC CONTROL Deactivates lights during daylight. Fully adjustable for 24 hour operation or custom applications.

POWER CONSUMPTION 5.3 watts (sensor only).

TIME ADJUSTMENTS 5 seconds to 12 minutes.

PAR HOLDER Injection molded plastic. Maximum 150 watt PAR38 lamp per socket.

MOUNTING PLATE Injection molded plastic with gasket.

WIDE SENSITIVITY CONTROL Adjustable from 100% to 30%


DETECTION 180 degrees.

SWITCHING CAPACITY 300 watts maximum. Incandescent @ 120 volts.

VOLTAGE 120 volts AC 60 Hertz.
Approval UL and CUL



DETECTION PATTERN

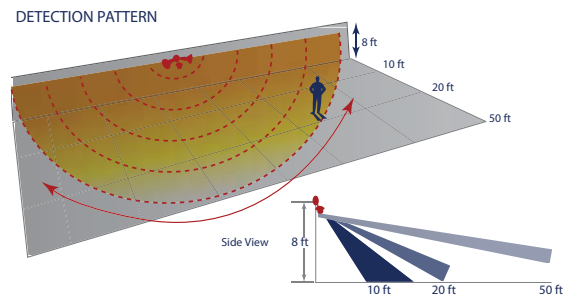

Catalog Code

MS518-2

BLK - BLACK
WH - WHITE

FINISH

RAB
DESIGN



Dimensions

