




Wall Lite 12W LED

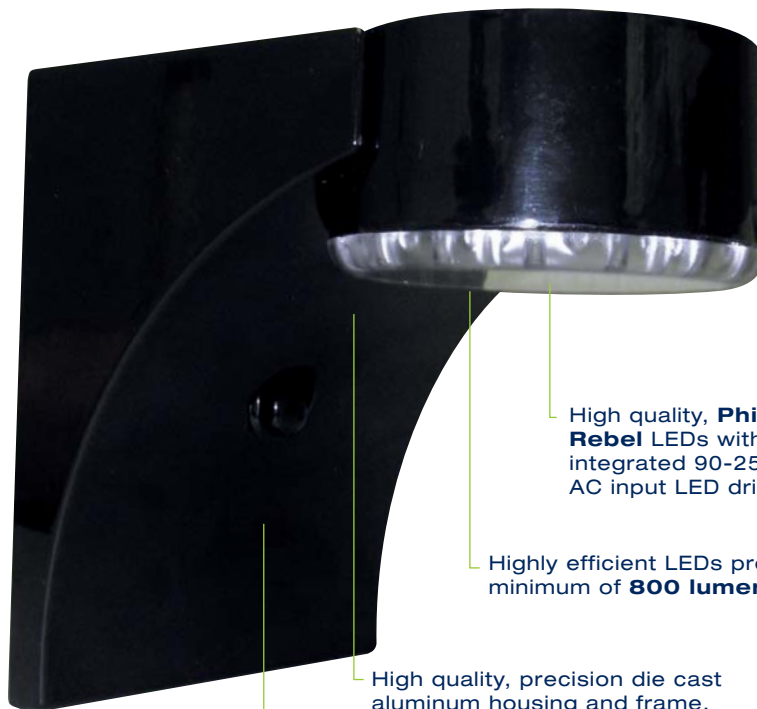


High quality, **Philips Rebel** LEDs with integrated 90-250V AC input LED driver.

Highly efficient LEDs produce a minimum of **800 lumens**.

High quality, precision die cast aluminum housing and frame.

Chip and fade resistant polyester powder coat finish.

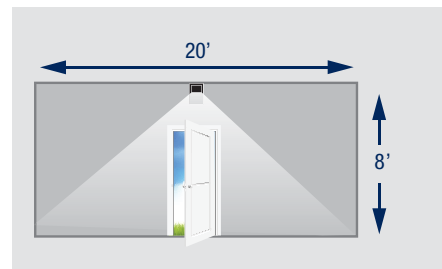

Available in black, bronze, white and hammertone grey. Custom colours available.



AREA LIGHT

DESCRIPTION

LED Module custom designed and built in Canada

Cast aluminum thermal management for optimal heat sinking

Precision die cast aluminum housing and frame

Suitable for wet locations. Ideal mounting height 8 - 10 feet

All RAB Design LED luminaires are mercury and UV free

LED will deliver 70% of its initial lumens for a minimum 50,000 hours of operation.

RAB Design LED luminaires comply with the IESNA LM79 testing procedure, which measures performance qualities of LED luminaires to allow for a true comparison of luminaires regardless of the light source.

Dimmable with standard TRIAC dimmer

APPLICATION

Ideal for entry and area lighting.



**PROUDLY
Made In Canada**



Wall Lite 12W LED

BENEFITS

HIGHLY EFFICIENT LED

The Wall Lite 12W LED uses fully tested high quality Phillips Rebel LEDs that produce a minimum of 800 lumens.

Standard colour is a natural white 4000K, consult factory for other colour temperatures.

DARK SKY FRIENDLY


The Wall Lite meets international dark sky standards as a full cutoff, full shielded luminaire.

This fixture can be used to achieve LEED credits for light pollution.

EXCELLENT LUMEN PERFORMANCE

Highly efficient heat sink maintains the junction temperature significantly below the recommended maximum ratings which allows the fixture to maintain 70% of initial lumens for at least 50,000 hours, well beyond the useful life of traditional incandescent light sources.

DIMENSIONAL DATA

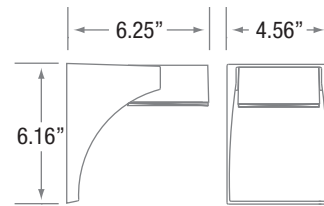

TECH DATA

PRODUCT	WL-LED (Natural White)
LED Quantity	6 pcs
LED Power Consumption	12W
Input Voltage	90-250VAC
Colour Temperature	4000K
Light Output	Min 800 Lumens
Colour Rendering Index (CRI)	> 70
Lamp Life (L70)	> 50,000H / approx. 17 years (with typical 8 hour daily usage)
Working Temperature	-30 to 50 °C
Ingress Protection Grade	IP65
Complies with CUL and CSA Standards	

ORDERING INFO example: WL-LED-12W-120-NW-BZ-PC

SERIES	DESCRIPTION	LED	VOLTS	LED Colour		FINISH		OPTIONS	
WL-LED	Wall Mount Area Light	12W	90-250VAC	NW	Natural White 4000K	HG	Hammertone Grey	PC	Photocell
						BZ	Bronze		
						BLK	Black		
						WH	White		
						C	Custom		



Visit rabdesign.ca to view our entire collection.

RAB Design Lighting Inc. 222 Islington Ave., Toronto, ON M8V 3W7
TEL. 416-252-9454 / 800-268-0381 | FAX. 416-252-9664 / 800-668-5517

