

Ideal for security lighting above entryways, stairwells and pedestrian areas.





WALL LITE WL

WALL LITE Glass WLG

MINI PACK MP



WL - Shown with optional wire cage

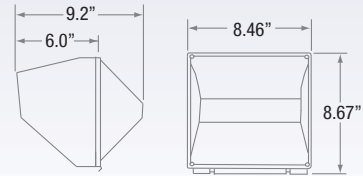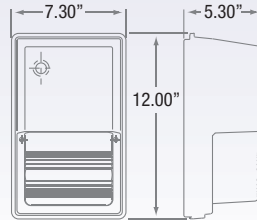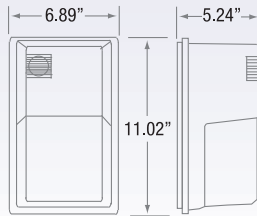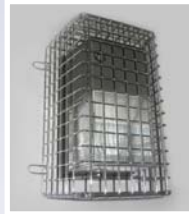

*** Heavy-duty, steel plated wire cage is available.**

WALL LITE & WALL LITE GLASS

HOUSING	LENS - WL	LENS - WLG	REFLECTOR	SOCKET	LAMP
Die cast aluminum with 1/2" bottom conduit knockout entry and box mounting template on back plate.	One piece durable polycarbonate with a clear prismatic portion.	Die cast aluminum frame with prismatic borosilicate glass refractor.	Die formed anodized aluminum reflector.	Medium base 4KV pulse-rated. CFL - Thermo plastic GX24q socket base.	All units come complete with lamp.

MINI PACK

HOUSING	LENS	REFLECTOR	SOCKET	LAMP
One piece die cast aluminum housing with 1/2" NPS tapped holes on top and both sides.	High impact heat resistant prismatic polycarbonate lens.	Die formed anodized aluminum reflector.	Medium base 4KV pulse-rated socket with a nickel-plated screw shell and a spring-loaded centre contact. CFL - Thermo plastic GX24q socket base.	All units come complete with lamp.

ORDERING INFO example: WL35HPS-120V-WH

SERIES	DESCRIPTION	HPS	MH	CFL	VOLTS	FINISH	OPTIONS
WL	Wall Lite	35W 50W 70W	-	42W ²	120V NPF ¹ 120V 347V ²	■ BZ Bronze □ WH White	PC Photocell ^F WC Wire Cage ³
WLG	Wall Lite Glass	50W 70W	50W 70W	-	120V NPF ¹ 120V HPF ¹ 120V 277V 347V	■ BZ Bronze □ WH White	PC Photocell ^F WC Wire Cage ³
MP	Mini Pack	35W 50W 70W 100W	50W ³ 70W ³	42W ²	120V NPF 120V HPF	■ BZ Bronze	PC Photocell ^F

¹ ONLY AVAILABLE IN HIGH PRESSURE SODIUM

² ELECTRONIC BALLAST 120V - 277V or 347V MINIMUM STARTING TEMP. -30°C

³ PLEASE CONSULT FACTORY

^F FACTORY INSTALLED

