

LED Multi-purpose Dusk-to-Dawn Luminaire




NEW LED Multi-purpose Dusk-to-Dawn Luminaire!

Hubbell Outdoor Lighting's all new LED multi-purpose dusk-to-dawn luminaire features multiple distributions, zero uplight performance and versatile mounting options in a single SKU. Stylish and rugged, this energy saving luminaire is designed to solve your security lighting needs.

Key Features & Benefits

- Zero uplight design for environmentally friendly installations
- Up to 3437 lumens with over 86 lumens per watt efficacy
- Refractor (included in carton) provides enhanced security and LED brightness control
- Symmetric LED lens installed standard; Field rotatable asymmetric LED lens included
- Rugged die-cast aluminum housing with textured gray powder paint provides corrosion resistance and clean finish
- Versatile mounting options include:
 - 24" aluminum mast arm (included)
 - Integral bracket adjusts to fit both 2-3/8" & 1-5/8" OD mast arms
 - Direct wall/surface mounting
- 120V operation
- 120V twist-lock style photocontrol included
- Meets DesignLights Consortium (DLC) qualifications

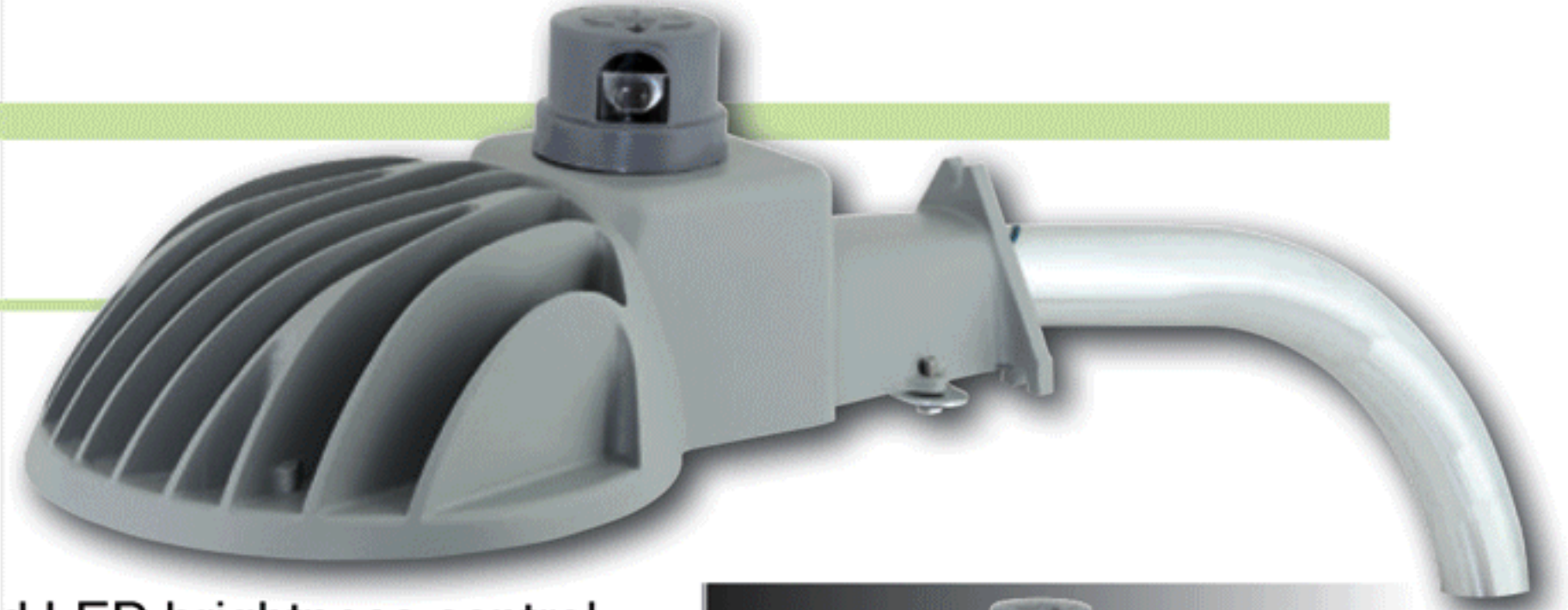

Shown with refractor installed



Catalog Number / UPC (120V photocontrol included standard)	Equivalency			Delivered Lumens	System Watts	Lumens Per Watt	Mounting Height	CCT	Voltage	Drive Current
	MH	HPS	CFL							
DDL-9L1 / 785988030699	175w	150w	85w	3437	40	86	up to 20 ft.	5100K	120V	1280mA

120V twist-lock photocontrol included

Die-cast housing with deep heat sink fins maximize heat dissipation

Three 1/4" slots for versatile wall/surface mount capability

24" aluminum mast arm included

Reversible mast arm clamp adjusts to 1-5/8" and 2-3/8" OD arms; Dual rows of serrated teeth ensure positive grip on mast arm



Field rotatable/exchangeable lenses included



Zero uplight performance



Field installable acrylic refractor for enhanced security and brightness control