



**HUBBELL**  
**Advantage**

- Put Power and Low Voltage Conveniently Where Needed
- Available With Nylon or Metal Cover
- Custom Configurable, Accepts Any Decorator Style Device
- RoHS Compliant



### Specifications

- Boxes comply with the NEC® for kitchen receptacles, with placement not more than 20 inches above the counter surface.
- Stamped steel
- Low profile
- UL Listed E31999 and CSA Certified under cabinet boxes

### Under Cabinet/Counter Power Distribution

Description	Color/Material	Dimensions	Catalog No.
Slim Box	Stainless Steel White Metal White Nylon	1.55" H x 5.57" W x 3.40" D	<b>RU100SS</b> <b>RU100W</b> <b>RU170W*</b>
GFCI Fit Box	Stainless Steel White Metal White Nylon	1.95" H x 5.57" W x 3.40" D	<b>RU200SS</b> <b>RU200W</b> <b>RU270W*</b>




RU100W




RU200SS

Note: \*Steel box with nylon cover.

### Vertical Mount

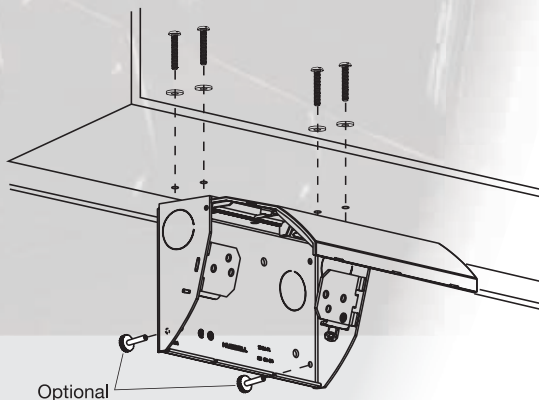

### Horizontal Mount

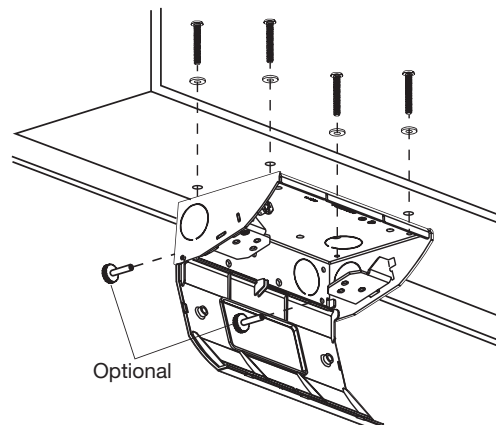

NEC® is a registered trademark of the National Fire Protection Association (NFPA).