

C9 / C12 Series


| | | |
|--------|------|-----------|
| Cat. # | | Approvals |
| Job | Type | |

APPLICATIONS

Ideal for ceiling mounted lighting.

SPECIFICATIONS

- Two sizes provide rugged service from 70-175 watt.
- Cast aluminum housing with protective powder paint.
- Vandal-resistant prismatic polycarbonate refractor.
- Gasketed to eliminate entry by insects.
- Typical mounting height is 8-15 ft. Spacing is typically 10-20 ft.
- 120/277/347V.
- Lamp included.

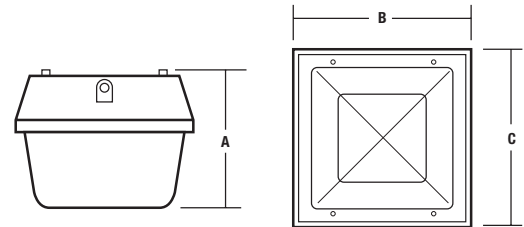

LISTINGS

- cUL listed for use in damp locations.

| | A | B | C |
|------------|-----------|------------|------------|
| C9 | 7.09 in. | 8.858 in. | 8.858 in. |
| | 180 mm | 225 mm | 225 mm |
| C12 | 8.858 in. | 12.362 in. | 12.362 in. |
| | 225 mm | 314 mm | 314 mm |

ORDERING INFORMATION

| Catalogue Number | Lamp Type / Wattage | Volts | Weight | UPC Code |
|------------------|---------------------|----------------|--------|-------------|
| C970HT | 70W MH | 120, 277, 347V | 7.0 | 80503504492 |
| C970ST | 70W HPS | 120, 277, 347V | 7.0 | 80503504493 |
| C12100HT | 100W MH | 120, 277, 347V | 10.0 | 80503504494 |
| C12175HT | 175W MH | 120, 277, 347V | 10.0 | 80503504495 |
| C12150ST | 150W HPS | 120, 277, 347V | 10.0 | 80503504496 |