

QUARTZ FLOODS

Q SERIES

Cat. #		Approvals
Job	Type	



APPLICATIONS

- General and accent flood lighting where short burning hours are planned. Instant on/off.

SPECIFICATIONS


- 150 to 500 watt capability.
- Die cast aluminum construction for long life.
- Single screw door closure for easy installation.
- Tempered glass lens protects lamp.
- 1/2" cast swivel knuckle fits standard boxes and covers.
- Wide, uniform beam for even illumination.
- 120 volt lamps are included.
- Units offered in dark bronze or white powder paint finish.

LISTINGS


- UL listed for use in wet locations.



Q150X

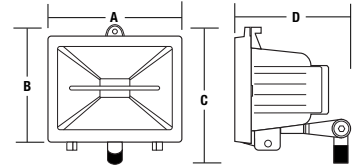

Q500X/Q300X

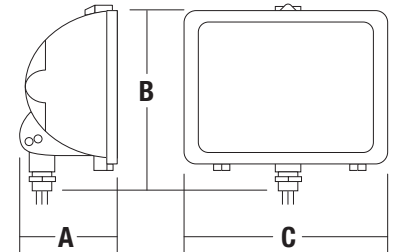

	A	B	C	D
Q150X	5 ⁷ / ₁₆ " 138 mm	3 ⁷ / ₈ " 98 mm	5 ¹ / ₂ " 139 mm	4" 100 mm
Q500X/Q300X	3 ⁵ / ₈ " 92 mm	7 ²³ / ₃₂ " 196 mm	8 ¹³ / ₁₆ " 227 mm	

ORDERING INFORMATION

Q SERIES - lamp included

Catalog Number	Wattage/Voltage	Finish	NEMA Beam Spread H° x V°	Weight		EPA	
				lbs	kg	ft	m
Q-150-B	150W/120V	Bronze	6(124°) x 6(124°)	1.4	.6	.14	.01
Q-150-W	150W/120V	White	6(124°) x 6(124°)	1.4	.6	.14	.01
Q-300-B	300W/120V	Bronze	6(109°) x 4(66°)	2.6	1.2	.6	.05
Q-300-W	300W/120V	White	6(109°) x 4(66°)	2.6	1.2	.6	.05
Q-500-B	500W/120V	Bronze	6(109°) x 4(66°)	2.6	1.2	.6	.05
Q-500-W	500W/120V	White	6(109°) x 4(66°)	2.6	1.2	.6	.05

PHOTOMETRIC REPORTS

Catalog Number	Report #
Q150X	HP06551A
Q500X	HP10062.IES

Due to our continued efforts to improve our products, product specifications are subject to change without notice.



Outdoor Lighting

Hubbell Outdoor Lighting • 701 Millennium Boulevard • Greenville, SC 29607 • PHONE: 864-678-1000

For more information visit our web site: www.hubbell-ltg.com