


# IBX/BX/RMNIC- 5/5S

# LiteBox®

## 5" IC & Non-IC Downlights

Line Voltage Incandescent Downlight IC OR Non-IC Rated 120V

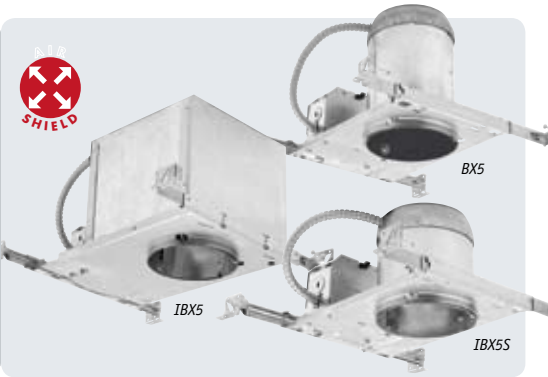

### FEATURES

- Ideal for residential and light commercial applications where a smaller aperture is desired for use with BR30 and PAR30 lamps
- The shallow IBX5S & RMNIC5S downlights are designed to fit into 2" X 6" joist construction and shallow plenums under 6"
- RMNIC5S housing is designed for use in IC remodel construction applications
- IBX5 & IBX5S are rated for direct contact with insulation and comply with air tight requirements in accordance with ASTM E283
- Nail included on bar hangers
- BX5 housing is designed for use in Non-IC, new construction applications
- Suitable for damp locations and through wiring
- Luminaires are certified by a National Recognized Testing Lab (NRTL), either UL or CSA.

### ORDERING INFORMATION

EXAMPLE: BX5-TB53-RC6

BX5		TB53		RC6	
<b>HOUSINGS</b>		<b>TRIMS</b>		<b>ACCESSORIES</b>	
<b>BX5</b>	5", line voltage Non-IC housing. New construction applications	<b>ADJUSTABLE</b>		<b>G5<sup>2,3</sup></b>	Ceiling gasket for 5" line housings. Seals housing to drywall opening
<b>IBX5</b>	5", line voltage IC rated housing. New construction applications. AirShield rated	<b>BAFFLE</b>		<b>ICBOX<sup>4</sup></b>	Recessed enclosure for Non-IC housings in IC applications. Refer to specification sheet FT-INC-005.
<b>IBX5S</b>	5", line voltage IC rated shallow plenum housing. New construction applications. AirShield rated	<b>TB53</b>	Black baffle. Metal flange. IC: 50W PAR30L, 65W BR30, 40W A19	<b>RC6<sup>5</sup></b>	Remodel clips. Three plaster frame clips for use in new construction frames in finished ceilings.
<b>RMNIC5S</b>	5", line voltage IC rated shallow plenum housing. Remodel applications.	<b>TBW53</b>	White baffle. Metal flange. IC: 50W PAR30L, 65W BR30, 40W A19		
		<b>TB54</b>	Black baffle 50W PAR30, 65W BR30		
		<b>TBW54</b>	White baffle 50W PAR30, 65W BR30		
		<b>LENSED</b>			
		<b>TL51<sup>8</sup></b>	Drop opal shower trim. IC: 50W PAR30, 40W A19 Non-IC: 60W A19, 75W PAR30		
		<b>OPEN</b>			
		<b>T050C<sup>6</sup></b>	Specular clear Alzak deep reflector. Metal flange. IC: 50W PAR30, 65W BR30 Non-IC: 75W PAR30, 85W BR30		
		<b>T051C<sup>7</sup></b>	Specular clear Alzak reflector. Metal flange. 50W PAR30, 65W BR30		
		<b>T059<sup>7</sup></b>	Open white trim. Metal flange. IC: 50W PAR30, 65W BR30 Non-IC: 75W PAR30, 85W BR30		
		<b>T058<sup>6</sup></b>	Open white deep reflector trim. Metal flange. IC: 50W PAR30, 65W BR30 Non-IC: 75W PAR30, 85W BR30		
		<b>T057<sup>6</sup></b>	Open white deep trim. Metal flange. IC: 50W PAR30L, 65W BR30, 40W A19 Non-IC: 75W PAR30L, 85W BR30, 40W A19		
		<b>OPEN SHOWER</b>			
		<b>T052WL<sup>1</sup></b>	Open white shower trim 50W PAR30L		

- ### NOTES
- <sup>1</sup> Indoor/outdoor lamp required.
  - <sup>2</sup> Not available on RMNIC5S
  - <sup>3</sup> Not available on BX5
  - <sup>4</sup> Not available on IBX5
  - <sup>5</sup> Only available on BX5
  - <sup>6</sup> Only available on IBX5 & BX5
  - <sup>7</sup> Only available on IBX5S & RMNIC5S
  - <sup>8</sup> Shower trims are wet location listed

