


# IBX/RMNIC 6" IC Rated Universal Downlights

LiteBox  
UNIVERSAL

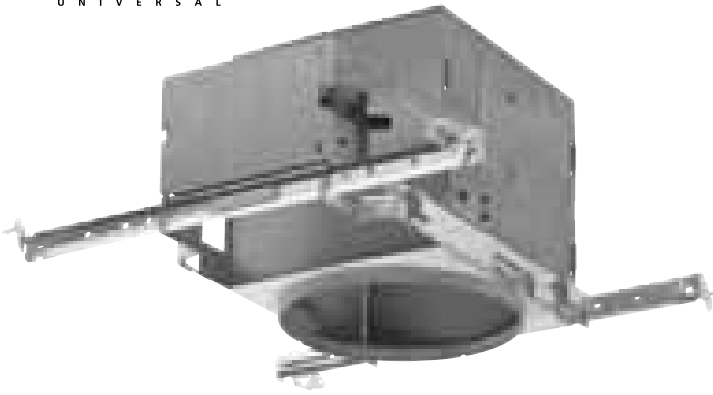

IBX shown

Order housing, trim, and accessories as separate line items. See ordering example on page 357.

## Features

The IBX downlight has been specifically designed for direct insulation contact in insulated ceilings and will accommodate several different trims, wattages, and lamp sources. The IBX will accommodate sloped ceiling, compact fluorescent, and LiteDeco™ trims.

The IBX downlight is ideal for general illumination in new construction ceilings where insulation is present. IBX may be used residentially in a single story home or the second level of a two story home; or commercially in such spaces as offices, single story retail, and hospitality environments. Due to the increased awareness of energy consumption, the LiteBox® IBX downlight utilizes Prescolite's Air Shield trims. Air Shield virtually eliminates air flow between the trim and the housing. Look for the Air Shield symbol (use with IBX only).

Rated for feed through wiring.

Listings: UL Listed  
CSA Certified  
N.Y. City Approved

	IBX
Length	11 1/2"
Width	7 1/2"
Height	7 1/2"
Ceiling Cutout	6 3/4"
Max. Ceiling Thickness	1 1/2"

Cat. No. Description

### Line 1 Order Housing:

Cat. No.	Description
IBX	6", New construction, IC housing rated for direct contact with insulation
RMNIC	6", Remodel, IC housing rated for direct contact with insulation

### Line 2 Order Trim:

Baffle	Cat. No.	Description	Cat. No.	Description
--------	----------	-------------	----------	-------------

	TB13	Shallow black baffle. 75W BR-30/PAR-30L		TB15  Deep black baffle. 65W BR-30/75W PAR-30L
	TBW13	Shallow white baffle. 75W BR-30/ PAR-30L		TBW15  Deep white baffle. 65W BR-30/75W PAR-30L

Wall Wash	Cat. No.	Description
-----------	----------	-------------

	TW44S	Open wall wash with specular Alzak® reflector. Rotatable. IBX only: 60W A-19
--	-------	--

Open	Cat. No.	Description	Cat. No.	Description
------	----------	-------------	----------	-------------

	TO1 TO1PB	Open trim. Available in white (TO1) or polished brass (TO1PB). 75W BR-30/ PAR-30		TO72S TO72G  Specular clear (S) or gold (G) Alzak reflector. 75W BR-30/PAR-30L
	TO2 TO2PB	Open trim. Available in white (TO2) or polished brass (TO2PB). 50W PAR-38.		TO83S TO83G  Specular clear (S) or gold (G) Alzak reflector. IBX: 75W A-19. RMNIC: 60W A-19
	TO8	White reflector trim. IBX: 75W BR-30/PAR-30/PAR-30L, 40W A-19, 50W PAR-38. RMNIC: 40W A-19, 50W PAR-30L/38/30, 75W BR-30		
	TO70 (S)(G)(B)	Clear (S), gold (G), or black (B) Alzak reflector. 50W PAR-30L/PAR-38		

Sloped Ceiling	Cat. No.	Description	Cat. No.	Description
----------------	----------	-------------	----------	-------------

	TSC30C TSC30G	Sloped ceiling trim. Clear (C) or gold (G) Alzak reflector. IBX only: 75W PAR-30. Slope: 15° to 30°		TSC30 (BF)(WBF) (B)	Sloped ceiling trim. Black Alzak reflector (B), black baffle (BF), or white baffle (WBF). IBX only: 75W PAR-30. Slope: 15° to 30°
--	------------------	---	--	---------------------------	---

Adjustable	Cat. No.	Description	Cat. No.	Description
------------	----------	-------------	----------	-------------

	TA20 TA20(PB)	Adjustable eyeball, available in white (TA20) or polished brass. (TA20PB) 50W R-20/PAR-20. Adjustability: 358° H x 30°V		TA21 TA21PB  Adjustable eyeball, available in white (TA21) or polished brass (TA21PB). Adjustability: 350° H x 30° V 75W BR-30.
--	------------------	---	--	--



Universal trims are interchangeable with IBX, PBX and RMN housings.  
 Denotes Air Shield rated with IBX housing and WESC gasket.

# IDBX

LiteBox  
UNIVERSAL



## 6" IC Rated High Wattage Universal Downlights

### Features

The IDBX downlight offers greater light output for spaces where insulation is present. The IDBX housing can accommodate up to 150 watts, making it one of the highest wattage type IC products in the industry.

The IDBX is ideal for new construction spaces where insulation is present. Greater levels of light output are possible for applications such as single story vaulted ceilings, high foyers, and office hallways. The IDBX utilizes Prescolite's Air Shield trims. Air Shield virtually eliminates air flow between the trim and the housing, which saves energy.

Rated for feed through wiring.

Listings: UL Listed  
CSA Certified  
N.Y. City Approved

	IDBX
Length	14 <sup>3</sup> / <sub>4</sub> "
Width	9 <sup>1</sup> / <sub>8</sub> "
Height	7 <sup>11</sup> / <sub>16</sub> "
Ceiling Cutout	6 <sup>7</sup> / <sub>8</sub> "
Max. Ceiling Thickness	1 <sup>1</sup> / <sub>2</sub> "

Order housing, trim, and accessories as separate line items. See ordering example on page 359.

Cat. No. Description

### Line 1 Order Housing:

IDBX 6", High wattage IC housing rated for direct contact with insulation

### Line 2 Order Trim:

Baffle	Cat. No.	Description	Cat. No.	Description
	<b>TB13</b>	ⓈⓂⓈ Shallow black baffle. 75W BR-30, 75W PAR-30L (IBX6 Only)	<b>TB16</b>	Black baffle with upper clear Alzak reflector. 90W PAR-38 (IDBX Only)
	<b>TBW13</b>	ⓈⓂⓈ Shallow white baffle. 75W BR-30, 75W PAR-30L (IBX6 Only)	<b>TB76</b>	ⓂⓈⓈ Black baffle with upper reflector. 100W A-19, 100W PAR-38, 120W BR-40 (IDBX Only)
	<b>TB15</b>	ⓈⓂⓈ Deep black baffle. 85W BR-30, 100W PAR-38 (IDBX Only)	<b>TBW76</b>	ⓂⓈⓈ White baffle with upper reflector. 100W A-19, 100W PAR-38, 120W BR-40 (IDBX Only)
	<b>TBW15</b>	ⓈⓂⓈ Deep white baffle. 85W BR-30, 100W PAR-38 (IDBX Only)		
Open	Cat. No.	Description	Cat. No.	Description
	<b>TO1</b> <b>TO1PB</b>	Ⓢ Open trim. Available in white (TO1) or polished brass (TO1PB). 75W PAR-30L, 85W BR-30. (IDBX Only)	<b>TO8</b>	ⓈⓂⓈⓈ Open white reflector trim. (IDBX Only) 60W A-19, 100W PAR-38, 120W BR-40
	<b>TO2</b> <b>TO2PB</b>	Ⓢ Open trim. Available in white (TO2) or polished brass (TO2PB). 100W BR-40/PAR-38 (IDBX Only)	<b>TO72S</b> <b>TO72G</b>	ⓈⓂⓈⓈ Specular clear (S) or gold (G) Alzak® reflector. 100W A-19, 120W PAR-38/BR-40 (IDBX Only)
Adjustable	Cat. No.	Description	Cat. No.	Description
	<b>TA20</b> <b>TA20PB</b>	Ⓢ Adjustable eyeball. Available in white (TA20) or polished brass (TA20PB). 50W R-20, 50W PAR-20. (IBX6 Only) Adjustability: 350° H x 30° V	<b>TA38C</b> <b>TA38G</b>	Clear (C) or gold (G) Alzak reflector with adjustable lamp. 100W PAR-38. Adjustability: 350°H x 35° V (IDBX Only)
	<b>TA21</b> <b>TA21PB</b> <b>TA21WS</b>	ⓈⓂⓈⓈ Adjustable eyeball. Available in white (TA21) or polished brass (TA21PB). (TA21WS incl. gasket, available in white only.) 85W BR-30. (IDBX Only) Adjustability: 350° H x 30° V	<b>TA38CMFC</b>	Adjustable lamp with American Matte™ reflector finish. Brushed aluminum trim ring. 100W PAR-38. Adjustability 350° H x 35° V (IDBX Only)
	<b>TA30</b> <b>(C)(B)</b> <b>(BF)(WBF)</b>	Ⓢ White baffle (WBF), black baffle (BF), clear (C), or Black (B) Alzak reflector with adjustable lamp. 75W PAR-30L Adjustability: 350° H x 35° V (IDBX Only)	<b>TA85</b> <b>TAW85</b>	Regressed eyeball. TA85 black baffle, TAW85 white baffle. 75W BR-30. Adjustability: 350°H x 35°V (IDBX Only)
Wall Wash	Cat. No.	Description	Cat. No.	Description
	<b>TW41</b>	Eyelid wall wash with black baffle and clear reflector. 40W A-19 (IDBX Only)	<b>TW44S</b>	Open wall wash downlight with clear Alzak reflector. 100W A-19 (IDBX Only)