

## PLASTIC EXIT

NRCan C860 registered  
LED 120/347VAC Input


**Approvals:**

CSA Certified to C22.2 #141 and C860

### DESCRIPTION

The EXPT series of commercial plastic exit signs is designed using durable and lightweight high impact thermoplastic. Signs and canopy quick snap together for speedy installations. Available in AC only, AC/DC and internally self-powered versions.

### CIRCUITRY - AC & AC/DC

- LED ultra bright light source
- 120/347VAC Input, field selectable
- 2.7 Watt power consumption single or double face
- Emergency DC wattages as follows:  
**6VDC** = 0.9W **12VDC** = 1.0W **24VDC** = 1.4W

### CIRCUITRY - SELF-POWERED


- LED ultra bright light source
- 120/347VAC Input, field selectable
- 2.7 Watt power consumption single or double face
- High-performance, sealed Ni-Cad battery
- 90 minutes emergency duration (standard)
- Solid state transfer and battery charger



### MECHANICAL

- High impact, UV stabilized, thermoplastic construction
- Quick snap faceplates, backplate and universal canopy for rapid and simple installation
- Snap out directional chevrons/arrows
- Universal spider knockout pattern stamped into backplate for junction box mounting
- Universal models include ceiling or end mount, field installable canopy kit c/w spider plate
- White color is standard

### DIMENSIONS

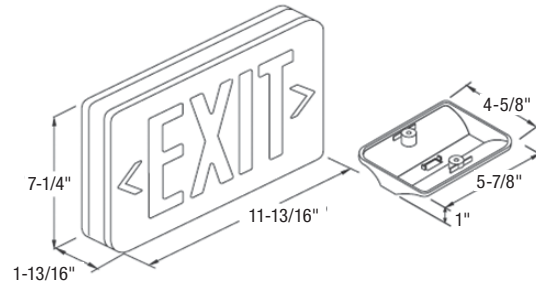

### ORDERING GUIDE

EXPT	U	M	WHT	/	
Series	Nbr of faces	Mounting	Color	DC Voltage	Options†
EXPT	U - Universal faces	M - Universal	WHT - White	<b>Blank</b> - AC only <b>UNVDC</b> - Universal DC backup voltage 6, 12 or 24VDC selectable <b>BAT</b> - Self-powered for 90 minutes	<b>WRG*, LXG</b>

† For detailed options descriptions, please consult the options page.

\* Specify mounting.