

CONTINUOUS HINGE WITH 3-POINT LATCH, TYPE 4X

INDUSTRY STANDARDS

 UL 508A Listed; Type 3R, 4, 4X, 12; File No. E61997
 cUL Listed per CSA C22.2 No 94; Type 3R, 4, 4X, 12; File No. E61997

 NEMA/EEMAC Type 3R, 4, 4X, 12, 13
 IEC 60529, IP66
 Meets NEMA Type 3RX requirements

APPLICATION

These enclosures feature Hoffman's exclusive POWERGLIDE™ Handle with 3-point latching, ideal for indoor or outdoor applications that require corrosion protection, convenient access, and padlocking security.

SPECIFICATIONS

- 14 gauge Type 304 or 316L stainless steel bodies and doors
- Seams continuously welded and ground smooth
- Seamless foam-in-place gasket
- Rolled lip around three sides of door
- Internal 3-point latch and Type 316L stainless steel padlocking POWERGLIDE Handle
- Remove door by pulling stainless steel continuous hinge pin
- Data pocket is high-impact thermoplastic
- Collar studs provided for mounting optional panels
- Exterior hardware on Type 316L stainless steel enclosures matches enclosure material
- Bonding provision on door; grounding stud on body

FINISH

Door, sides, top and bottom have smooth #4 brushed finish. Handle is electropolished.

ACCESSORIES

 See also *Accessories*.
 Panels for Type 3R, 4, 4X, 12 and 13 Enclosures
 Steel and Stainless Steel Window Kits
 H2OMIT™ Vent Drains, Type 4X
 H2OMIT™ Thermoelectric Dehumidifier

MODIFICATION AND CUSTOMIZATION

Hoffman excels at modifying and customizing products to your specifications. Contact your local Hoffman sales office or distributor for complete information.


BULLETIN: A4SW3

Standard Product

Catalog Number	AxBxC in./mm	Stainless Steel Type	F in./mm	Steel Panel	Conductive Panel	Stainless Steel Panel	Panel Size D x E in./mm	Data Pocket
A24H2006SSLP3PT	24.00 x 20.00 x 6.00 610 x 508 x 152	304	3.00 76	A24P20	A24P20G	A24P20SS6	21.00 x 17.00 533 x 432	Small
A24H2006SS6LP3PT	24.00 x 20.00 x 6.00 610 x 508 x 152	316L	3.00 76	A24P20	A24P20G	A24P20SS6	21.00 x 17.00 533 x 432	Small
A24H2008SSLP3PT	24.00 x 20.00 x 8.00 610 x 508 x 203	304	3.00 76	A24P20	A24P20G	A24P20SS6	21.00 x 17.00 533 x 432	Small
A24H2008SS6LP3PT	24.00 x 20.00 x 8.00 610 x 508 x 203	316L	3.00 76	A24P20	A24P20G	A24P20SS6	21.00 x 17.00 533 x 432	Small
A24H2408SSLP3PT	24.00 x 24.00 x 8.00 610 x 610 x 203	304	3.00 76	A24P24	A24P24G	A24P24SS6	21.00 x 21.00 533 x 533	Small
A24H2408SS6LP3PT	24.00 x 24.00 x 8.00 610 x 610 x 203	316L	3.00 76	A24P24	A24P24G	A24P24SS6	21.00 x 21.00 533 x 533	Small
A30H2408SSLP3PT	30.00 x 24.00 x 8.00 762 x 610 x 203	304	3.00 76	A30P24	A30P24G	A30P24SS6	27.00 x 21.00 686 x 533	Large
A30H2408SS6LP3PT	30.00 x 24.00 x 8.00 762 x 610 x 203	316L	3.00 76	A30P24	A30P24G	A30P24SS6	27.00 x 21.00 686 x 533	Large
A30H3008SSLP3PT	30.00 x 30.00 x 8.00 762 x 762 x 203	304	3.00 76	A30P30	A30P30G	A30P30SS6	27.00 x 27.00 686 x 686	Large
A30H3008SS6LP3PT	30.00 x 30.00 x 8.00 762 x 762 x 203	316L	3.00 76	A30P30	A30P30G	A30P30SS6	27.00 x 27.00 686 x 686	Large
A36H2408SSLP3PT	36.00 x 24.00 x 8.00 914 x 610 x 203	304	3.00 76	A36P24	A36P24G	A36P24SS6	33.00 x 21.00 838 x 533	Large
A36H2408SS6LP3PT	36.00 x 24.00 x 8.00 914 x 610 x 203	316L	3.00 76	A36P24	A36P24G	A36P24SS6	33.00 x 21.00 838 x 533	Large
A36H3008SSLP3PT	36.00 x 30.00 x 8.00 914 x 762 x 203	304	3.00 76	A36P30	A36P30G	A36P30SS6	33.00 x 27.00 838 x 686	Large
A36H3008SS6LP3PT	36.00 x 30.00 x 8.00 914 x 762 x 203	316L	3.00 76	A36P30	A36P30G	A36P30SS6	33.00 x 27.00 838 x 686	Large
A48H3608SSLP3PT	48.00 x 36.00 x 8.00 1219 x 914 x 203	304	3.00 76	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	Large
A48H3608SS6LP3PT	48.00 x 36.00 x 8.00 1219 x 914 x 203	316L	3.00 76	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	Large
A24H2010SSLP3PT	24.00 x 20.00 x 10.00 610 x 508 x 254	304	3.00 76	A24P20	A24P20G	A24P20SS6	21.00 x 17.00 533 x 432	Small

Catalog Number	AxBxC in./mm	Stainless Steel Type	F in./mm	Steel Panel	Conductive Panel	Stainless Steel Panel	Panel Size D x E in./mm	Data Pocket
A24H2010SS6LP3PT	24.00 x 20.00 x 10.00 610 x 508 x 254	316L	3.00 76	A24P20	A24P20G	A24P20SS6	21.00 x 17.00 533 x 432	Small
A36H3010SSLP3PT	36.00 x 30.00 x 10.00 914 x 762 x 254	304	3.00 76	A36P30	A36P30G	A36P30SS6	33.00 x 27.00 838 x 686	Large
A36H3010SS6LP3PT	36.00 x 30.00 x 10.00 914 x 762 x 254	316L	3.00 76	A36P30	A36P30G	A36P30SS6	33.00 x 27.00 838 x 686	Large
A42H3010SSLP3PT	42.00 x 30.00 x 10.00 1067 x 762 x 254	304	3.00 76	A42P30	A42P30G	A42P30SS6	39.00 x 27.00 991 x 686	Large
A48H3610SSLP3PT	48.00 x 36.00 x 10.00 1219 x 914 x 254	304	3.00 76	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	Large
A48H3610SS6LP3PT	48.00 x 36.00 x 10.00 1219 x 914 x 254	316L	3.00 76	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	Large
A24H2412SSLP3PT	24.00 x 24.00 x 12.00 610 x 610 x 305	304	3.00 76	A24P24	A24P24G	A24P24SS6	21.00 x 21.00 533 x 533	Small
A24H2412SS6LP3PT	24.00 x 24.00 x 12.00 610 x 610 x 305	316L	3.00 76	A24P24	A24P24G	A24P24SS6	21.00 x 21.00 533 x 533	Small
A30H2412SSLP3PT	30.00 x 24.00 x 12.00 760 x 610 x 305	304	3.00 76	A30P24	A30P24G	A30P24SS6	27.00 x 21.00 686 x 533	Large
A30H2412SS6LP3PT	30.00 x 24.00 x 12.00 762 x 610 x 305	316L	3.00 76	A30P24	A30P24G	A30P24SS6	27.00 x 21.00 686 x 533	Large
A36H3012SSLP3PT	36.00 x 30.00 x 12.00 914 x 762 x 305	304	3.00 76	A36P30	A36P30G	A36P30SS6	33.00 x 27.00 838 x 686	Large
A36H3012SS6LP3PT	36.00 x 30.00 x 12.00 914 x 762 x 305	316L	3.00 76	A36P30	A36P30G	A36P30SS6	33.00 x 27.00 838 x 686	Large
A36H3612SSLP3PT	36.00 x 36.00 x 12.00 914 x 914 x 305	304	3.00 76	A36P36	A36P36G	A36P36SS6	33.00 x 33.00 838 x 838	Large
A36H3612SS6LP3PT	36.00 x 36.00 x 12.00 914 x 914 x 305	316L	3.00 76	A36P36	A36P36G	A36P36SS6	33.00 x 33.00 838 x 838	Large
A42H3612SSLP3PT	42.00 x 36.00 x 12.00 1067 x 914 x 305	304	3.00 76	A42P36	A42P36G	A42P36SS6	39.00 x 33.00 991 x 838	Large
A48H3612SSLP3PT	48.00 x 36.00 x 12.00 1219 x 914 x 305	304	3.00 76	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	Large
A48H3612SS6LP3PT	48.00 x 36.00 x 12.00 1219 x 914 x 305	316L	3.00 76	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	Large
A60H3612SSLP3PT	60.00 x 36.00 x 12.00 1524 x 914 x 305	304	3.00 76	A60P36	A60P36G	A60P36SS6	57.00 x 33.00 1448 x 838	Large
A60H3612SS6LP3PT	60.00 x 36.00 x 12.00 1524 x 914 x 305	316L	3.00 76	A60P36	A60P36G	A60P36SS6	57.00 x 33.00 1448 x 838	Large
A48H3616SSLP3PT	48.00 x 36.00 x 16.00 1219 x 914 x 406	304	3.00 76	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	Large
A48H3616SS6LP3PT	48.00 x 36.00 x 16.00 1219 x 914 x 406	316L	3.00 76	A48P36	A48P36G	A48P36SS6	45.00 x 33.00 1143 x 838	Large
A60H3616SSLP3PT	60.00 x 36.00 x 16.00 1524 x 914 x 406	304	3.00 76	A60P36	A60P36G	A60P36SS6	57.00 x 33.00 1448 x 838	Large
A60H3616SS6LP3PT	60.00 x 36.00 x 16.00 1524 x 914 x 406	316L	3.00 76	A60P36	A60P36G	A60P36SS6	57.00 x 33.00 1448 x 838	Large

Purchase panels separately. Optional stainless steel, composite and aluminum panels are available for most sizes.

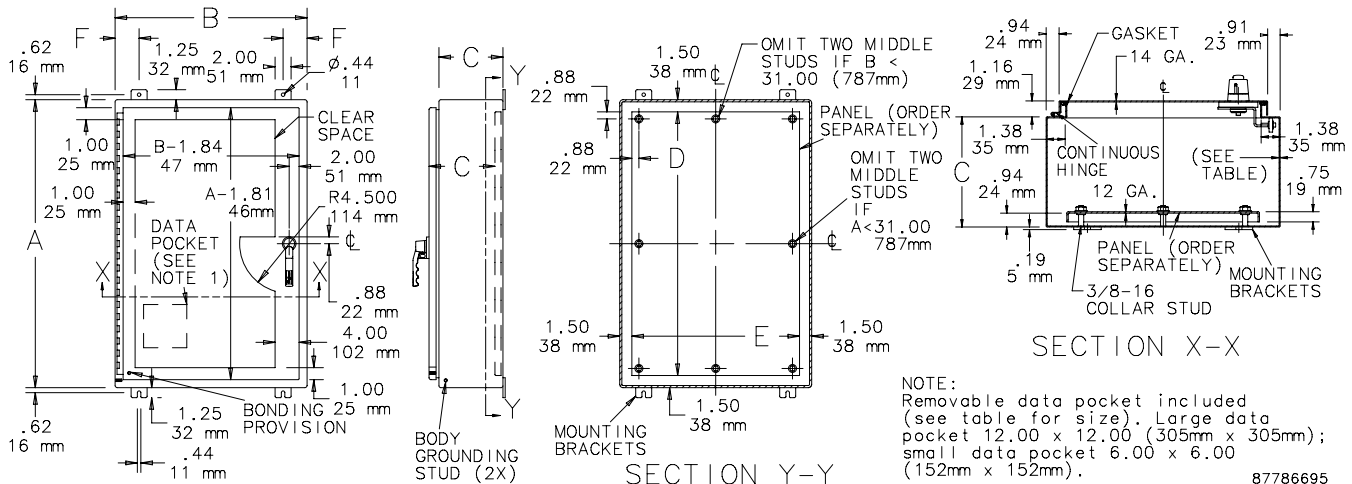

87786695