



C16 & C18 Series

Cat. #		Approvals
Job	Type	

SPECIFICATIONS

- Heavy duty die cast aluminum housing components with powder coat finish
- Heat and impact resistant tempered glass lens in a removable door frame
- Choose between two elegant housing styles, trapezoid or half moon. Both are surface mount, cutoff & low wattage H.I.D.
- Silicone rubber gasket included to prevent any water leakage from the outside
- Complete with stainless steel external hardware
- Dark bronze finish
- Wide throw distribution
- Complete with IMB (Intelligent Mounting Bracket) for quick and easy one person installation. The universal mounting plate comes standard with bubble level for accurate installation
- One piece anodized aluminum designed reflector for optimum light efficiency
- UL listed for wet location
- CUL certified for use in Canada.




C16 Series




C18 Series

C16 Series

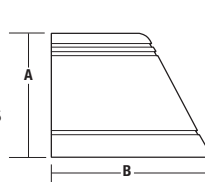

C18 Series

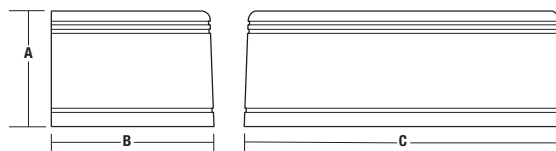

	A	B	C	D
C16	7.08 in.	9.25 in.	16.54 in.	13.98 in.
	180 mm	235 mm	420 mm	355 mm
C18	7.28 in.	9.06 in.	18.1 in.	
	185 mm	230 mm	460 mm	

ORDERING INFORMATION

Catalogue Number	Description	Voltage	Weight	Input Watts	Operating Current 120/277/347	Starting Current 120/277/347
C16175HT	175W MH, wide throw, bronze, includes ED17 lamp	120/277/347	12 lbs.	210W	1.8 / 0.8 / 0.7	1.9 / 1.9 / 1.9
C16150PT	150W PS, wide throw, bronze, includes ED17 lamp	120/277/347	12 lbs.	185W	3.7 / 1.6 / 1.3	2.5 / 2.5 / 2.5
C16150ST	150W HPS, wide throw, bronze, includes ED17 lamp	120/277/347	12 lbs.	188W	2.8 / 1.3 / 0.9	3.9 / 3.9 / 3.9
C18175HT	175W MH, wide throw, bronze, includes ED17 lamp	120/277/347	12 lbs.	210W	1.8 / 0.8 / 0.7	1.9 / 1.9 / 1.9
C18150PT	150W PS, wide throw, bronze, includes ED17 lamp	120/277/347	12 lbs.	185W	3.7 / 1.6 / 1.3	2.5 / 2.5 / 2.5
C18150ST	150W HPS, wide throw, bronze, includes ED17 lamp	120/277/347	12 lbs.	188W	2.8 / 1.3 / 0.9	3.9 / 3.9 / 3.9