


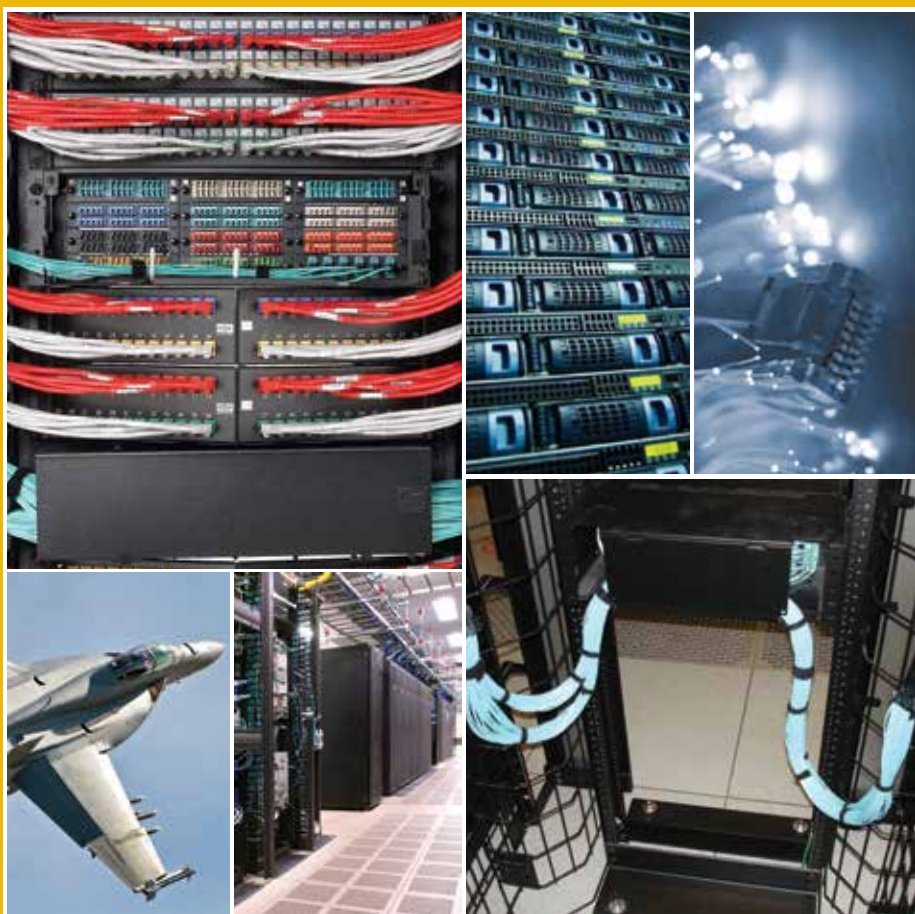

## FIBER | Connectivity


Hubbell optical fiber connectivity products offer a modular, standards-compliant solution for enterprise and data center cabling infrastructure. This section features high performance PROclick® pre-polished connectors, fusion splice connectors, adapters and keystone snap fittings. FSP Series panels and OC Series pre-terminated cassettes complete the end-to-end solution with a full range of densities, fiber types and adapter options.





## FIBER | Connectivity

Pre-Polished Connectors.....	G3
Fusion Splice Connectors.....	G4
Adhesive and Crimp Style Connectors .....	G5
LC Duplex Keystone Adapter Snap Fittings .....	G6
SC Simplex Keystone Adapter Snap Fittings .....	G7
Keystone Adapter Snap Fittings .....	G8
LC and SC Adapters.....	G9
Specialty Adapters.....	G10
MPO Cassettes .....	G11
FSP Adapter Panels .....	G12
OPPNL Panels and FTR Trays.....	G14
Termination Tools and Accessories .....	G15
Advanced Fiber Cleaning Supplies .....	G17
Keyed LC Products .....	G18

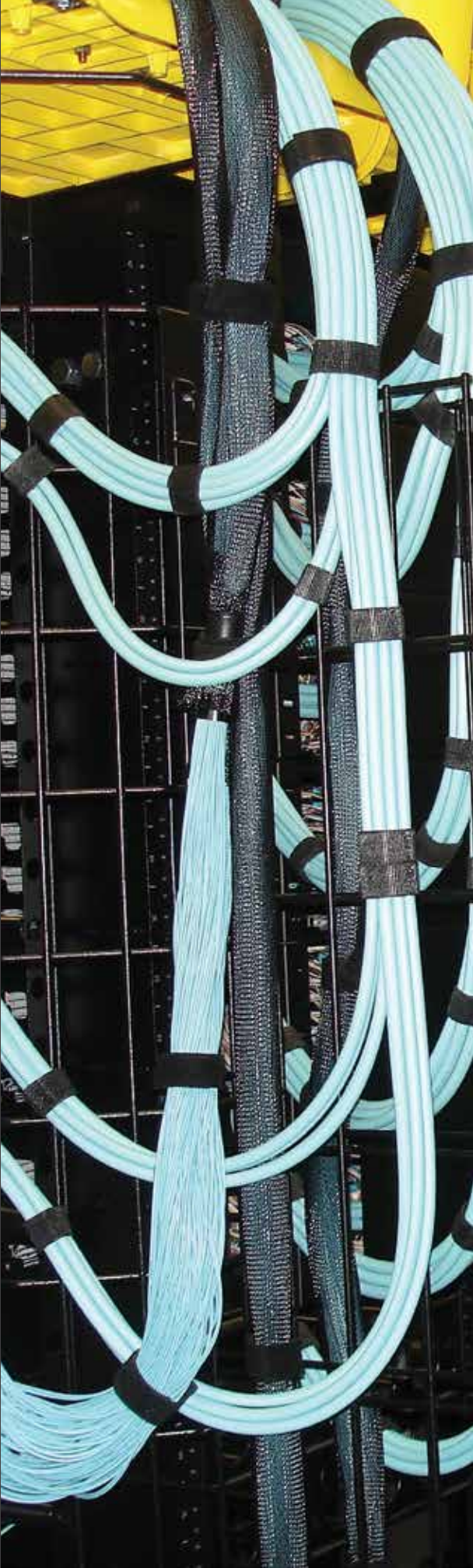



LC Pre-Polished  
FCLC900K50GM12



SC Pre-Polished  
FCSC900K62M12



2CLICK® ST  
FCSTSM12

### Standards

- ANSI/TIA-568.3-D
- TIA-604-FOCIS
- Telcordia GR-326-CORE

## Pre-Polished Connectors

900/250 μM cable, 10mm cleave length

### LC PROclick®

Color	Fiber Type	12-Pack	100-Pack
Aqua	50μM, OM3/OM4	<b>FCLC900K50GM12</b>	<b>FCLC900K50GM100</b>
Beige	62.5μM, OM1	<b>FCLC900K62M12</b>	<b>FCLC900K62M100</b>
Black	50μM, OM2	<b>FCLC900K50M12</b>	<b>FCLC900K50M100</b>
Blue	SM, OS2	<b>FCLC900KSM12</b>	<b>FCLC900KSM100</b>
Green		-	-

### SC PROclick®

Fiber Type	12-Pack	100-Pack
50μM, OM3/OM4	<b>FCSC900K50GM12</b>	<b>FCSC900K50GM100</b>
62.5μM, OM1	<b>FCSC900K62M12</b>	<b>FCSC900K62M100</b>
50μM, OM2	<b>FCSC900K50M12</b>	<b>FCSC900K50M100</b>
UPC SM, OS2	<b>FCSC900KSM12</b>	<b>FCSC900KSM100</b>
APC SM, OS2	<b>FCSC900KASM12</b>	-

### ST 2Click®

Color	Fiber Type	12-Pack
Aqua	50μM, OM3/OM4	<b>FCST50GM12</b>
Beige	62.5μM, OM1	<b>FCST62M12</b>
Black	50μM, OM2	<b>FCST50M12</b>
Blue	SM, OS2	<b>FCSTSM12</b>

### Fiber Cleaver

Description	Catalog No.
Multimode only	<b>OFCLV3</b>
SM or MM fiber, CT-30 style, with case	<b>OFCLV4</b>
SM or MM fiber, precision, with case	<b>OFCLV5</b>

### Universal Fiber Strip Tool

Description	Catalog No.
900 micron buffered 250 fiber acrylate buffer, loose tube and PVC jackets	<b>OFSTRIP2</b>

### Visual Fault Locator (ST, SC, LC)

Description	Catalog No.
Visual fault locator	<b>OFVFLKT1</b>

*TIP: Use a VFL during termination for optimum test results.*

## Four Easy Termination Steps



Strip



Wipe




Cleave




Insert and Click

Note: See page G14 for termination tools and accessories. Cleave tool OFCLV3 is suitable for multimode only. Visual Fault locator OFVFLKT1 recommended during termination. Precision cleave tool OFCLV4 or OFCLV5 is required for singlemode terminations. Use a precision cleave tool for optimum performance.

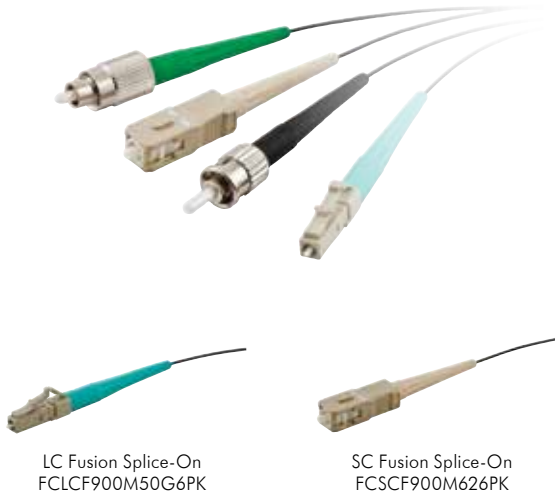

### Standards

- ANSI/TIA-568.3-D
- TIA-604-FOCIS
- Telcordia GR-326-CORE

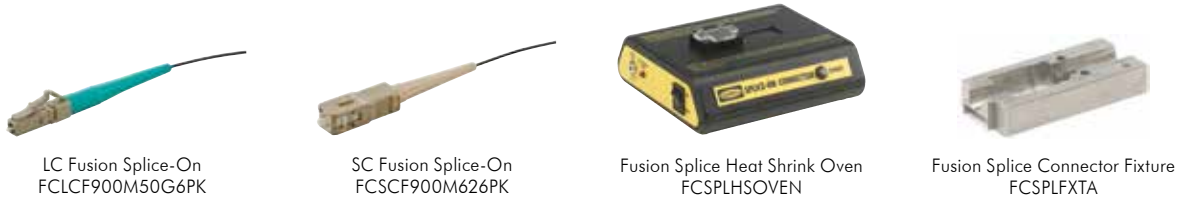

## Fusion Splice-On Connectors

6-Pack

Fiber Type	LC	SC	ST-Style	FC
Multimode 62.5 (OM1)	<b>FCLCF900M626PK</b>	<b>FCSCF900M626PK</b>	<b>FCSTF900M626PK</b>	<b>FCFCF900M626PK</b>
Multimode 50 (OM2)	<b>FCLCF900M506PK</b>	<b>FCSCF900M506PK</b>	<b>FCSTF900M506PK</b>	<b>FCFCF900M506PK</b>
Multimode 50 (OM3)	<b>FCLCF900M50G6PK</b>	<b>FCSCF900M50G6PK</b>	<b>FCSTF900M50G6PK</b>	<b>FCFCF900M50G6PK</b>
Singlemode UPC (OS2)	<b>FCLCF900SM6PK</b>	<b>FCSCF900SM6PK</b>	<b>FCSTF900SM6PK</b>	<b>FCFCF900SM6PK</b>
Singlemode APC (OS2)	-	<b>FCSCF900SMA6PK</b>	-	<b>FCFCF900SMA6PK</b>

Note: Pack of 6 connectors, each in a protective capsule with cleave protector, extended dust cap, 900µm boot and splice sleeve. Compatible with fusion splicers having a removable fiber holder. See application chart below. Metal holder fixture required (sold separately). See application table below. Hubbell fusion splice heat shrink oven, Catalog Number FCSPLHSOVEN is also required for termination.

## Fusion Splice Heat Shrink Oven

Catalog No.	<b>FCSPLHSOVEN</b>
-------------	--------------------

## Metal Splice Connector Fixture Application Chart

Fusion Splicer Manufacturer	Fusion Splicer Model No.	Splice-On Connectors Supported (900µ)	Metal Connector Fixture Catalog No.
AFL/Fujikura	FSM-11 (S/M)	LC, SC, ST, FC	<b>FCSPLFXSTAR</b>
	FSM-12S		<b>FCSPLFXTA</b>
	FSM-17S	LC, SC	
	FSM-18S, FSM-60 (S/R)	LC, SC, ST	
Furukawa/Fitel®	S122 (A/C/M)	LC, SC, ST, FC	<b>FCSPLFXTF</b>
	S121 (A/M)		
	S123 (C/M), S153, S178A, S178A		
Sumitomo®	Type-25e (U/S/M)	LC, SC, ST, FC	<b>FCSPLFXTS</b>
	Type-39FH		
	Type-46, 66		
	Quantum (Q101-CA)		
INNO™	IFS 10, IFS 15	LC, SC, ST, FC	<b>FCSPLFXTI</b>
Greenlee®	910 FS	LC, SC, ST, FC	<b>FCSPLFXTG</b>
FIS	SUPER COUGAR	LC, SC, ST, FC	<b>FCSPLFXTFIS</b>

Sumitomo is a registered trademark of Sumitomo Electric Lightwave. Fitel is a registered trademark of Furukawa Electric Co., LTD. INNO is a trademark of INNO Instrument Inc. Greenlee is a registered trademark of Greenlee Textron Inc.



SC Adhesive  
FCSCM12R  
FCSCS12R



ST and SC Crimp  
FCSTM12R  
FCSTS12R



LC Adhesive  
FCLCMM



Crimp Insert and 3mm Boot  
FCLCXX  
OFPCRKXX

## Adhesive Connectors

900µm termination

	SC		ST-Style	
Mode	12-Pack	100-Pack	12-Pack	100-Pack
Multimode	<b>FCSCM12R</b>	<b>FCSCM100R</b>	<b>FCSTM12R</b>	<b>FCSTM100R</b>
Singlemode	<b>FCSCS12R</b>	<b>FCSCS100R</b>	<b>FCSTS12R</b>	<b>FCSTS100R</b>

## LC Simplex Adhesive Connectors

900µm termination, LC connector, white boot and dust cap

Mode	6-Pack
Multimode	<b>FCLCMM</b>
Singlemode	<b>FCLCSM</b>

## Crimp Style Non-Adhesive Connectors

900µm termination

	SC		ST-Style	
Mode	12-Pack	100-Pack	12-Pack	100-Pack
Multimode	<b>FCSCMQ12R</b>	<b>FCSCMQ100R</b>	<b>FCSTMQ12RA</b>	<b>FCSTMQ100R</b>
Singlemode	<b>FCSCSQ12R</b>	<b>FCSCSQ100R</b>	<b>FCSTSQ12R</b>	<b>FCSTSQ100R</b>

Note: Includes 1 connector, dust cap, black boot (MM) or yellow boot (SM), and crimp insert.

## Crimp Inserts

Mode	12-Pack	100-Pack
Multimode/singlemode	<b>FCCI12</b>	<b>FCCI100</b>

## Crimp Rings/3mm Boots

(25) crimp sleeves and boots

Description	Catalog No.
Multimode	<b>OFPCRKM</b>
Singlemode	<b>OFPCRKS</b>

Note: SC/ST-style Hubbell OptiChannel connectors for 3mm jacketed cables, black boot (MM) or yellow boot (SM).

Note: OFCMT04 crimp tool required for SC and ST crimp or adhesive termination. See page G14 for termination tools and accessories sold separately.



LC Duplex, Flush Mount  
SFFLCBW



LC Duplex, Standard  
SFLCBBK

## LC Duplex Keystone Adapters

### Flush Mount, Phospor Bronze

Housing Color	Adapter Color							
	Aqua	Beige	Black	Blue	Green	Orange	Red	Yellow
Almond	<b>SFFLCAQAL</b>	<b>SFFLCBEAL</b>	<b>SFFLCBKAL</b>	<b>SFFLCBAL</b>	<b>SFFLCGNAL</b>	<b>SFFLCORAL</b>	<b>SFFLCRAL</b>	<b>SFFLCYAL</b>
Black	<b>SFFLCAQBK</b>	<b>SFFLCBEBK</b>	<b>SFFLCBKBK</b>	<b>SFFLCBBK</b>	<b>SFFLCGNBK</b>	<b>SFFLCORBK</b>	<b>SFFLCRBK</b>	<b>SFFLCYBK</b>
Gray	<b>SFFLCAQG</b>	<b>SFFLCBEG</b>	<b>SFFLCBKG</b>	<b>SFFLCBG</b>	<b>SFFLCGNG</b>	<b>SFFLCORG</b>	<b>SFFLCRG</b>	<b>SFFLCYG</b>
Ivory	<b>SFFLCAQEI</b>	<b>SFFLCBEEI</b>	<b>SFFLCBKEI</b>	<b>SFFLCBEI</b>	<b>SFFLCGNEI</b>	<b>SFFLCOREI</b>	<b>SFFLCREI</b>	<b>SFFLCYEI</b>
Light Almond	<b>SFFLCAQLA</b>	<b>SFFLCBELA</b>	<b>SFFLCBKLA</b>	<b>SFFLCBLA</b>	<b>SFFLCGNLA</b>	<b>SFFLCORLA</b>	<b>SFFLCRLA</b>	<b>SFFLCYLA</b>
Office White	<b>SFFLCAQOW</b>	<b>SFFLCBEOW</b>	<b>SFFLCBKOW</b>	<b>SFFLCBOW</b>	<b>SFFLCGNOW</b>	<b>SFFLCOROW</b>	<b>SFFLCROW</b>	<b>SFFLCYOW</b>
White	<b>SFFLCAQW</b>	<b>SFFLCBEW</b>	<b>SFFLCBKW</b>	<b>SFFLCBW</b>	<b>SFFLCGNW</b>	<b>SFFLCORW</b>	<b>SFFLCRW</b>	<b>SFFLCYW</b>

### Flush Mount, Zirconia Ceramic

Housing Color	Adapter Color							
	Aqua	Beige	Black	Blue	Green	Orange	Red	Yellow
Almond	<b>SFFLCSAQAL</b>	<b>SFFLCSBEAL</b>	<b>SFFLCSBKAL</b>	<b>SFFLCSBAL</b>	<b>SFFLCSGNAL</b>	<b>SFFLCSORAL</b>	<b>SFFLCSRAL</b>	<b>SFFLCSYAL</b>
Black	<b>SFFLCSAQBK</b>	<b>SFFLCSBEBK</b>	<b>SFFLCSBKBK</b>	<b>SFFLCSBBK</b>	<b>SFFLCSGNBK</b>	<b>SFFLCSORBK</b>	<b>SFFLCSRBK</b>	<b>SFFLCSYBK</b>
Gray	<b>SFFLCSAQG</b>	<b>SFFLCSBEG</b>	<b>SFFLCSBKG</b>	<b>SFFLCSBG</b>	<b>SFFLCSGNG</b>	<b>SFFLCSORG</b>	<b>SFFLCSRG</b>	<b>SFFLCSYG</b>
Ivory	<b>SFFLCSAQEI</b>	<b>SFFLCSBEEI</b>	<b>SFFLCSBKEI</b>	<b>SFFLCSBEI</b>	<b>SFFLCSGNEI</b>	<b>SFFLCSOREI</b>	<b>SFFLCSREI</b>	<b>SFFLCSYEI</b>
Light Almond	<b>SFFLCSAQLA</b>	<b>SFFLCSBELA</b>	<b>SFFLCSBKLA</b>	<b>SFFLCSBLA</b>	<b>SFFLCSGNLA</b>	<b>SFFLCSORLA</b>	<b>SFFLCSRLA</b>	<b>SFFLCSYLA</b>
Office White	<b>SFFLCSAQOW</b>	<b>SFFLCSBEOW</b>	<b>SFFLCSBKOW</b>	<b>SFFLCSBOW</b>	<b>SFFLCSGNOW</b>	<b>SFFLCSOROW</b>	<b>SFFLCSROW</b>	<b>SFFLCSYOW</b>
White	<b>SFFLCSAQW</b>	<b>SFFLCSBEW</b>	<b>SFFLCSBKW</b>	<b>SFFLCSBW</b>	<b>SFFLCSGNW</b>	<b>SFFLCSORW</b>	<b>SFFLCSRW</b>	<b>SFFLCSYW</b>

### Standard, Phospor Bronze

Housing Color	Adapter Color							
	Aqua	Beige	Black	Blue	Green	Orange	Red	Yellow
Almond	<b>SFLCAQAL</b>	<b>SFLCBEAL</b>	<b>SFLCBKAL</b>	<b>SFLCBAL</b>	<b>SFLCGNAL</b>	<b>SFLCORAL</b>	<b>SFLCRAL</b>	<b>SFLCYAL</b>
Black	<b>SFLCAQBK</b>	<b>SFLCBEBK</b>	<b>SFLCBKBK</b>	<b>SFLCBBK</b>	<b>SFLCGNBK</b>	<b>SFLCORBK</b>	<b>SFLCRBK</b>	<b>SFLCYBK</b>
Gray	<b>SFLCAQG</b>	<b>SFLCBEG</b>	<b>SFLCBKG</b>	<b>SFLCBG</b>	<b>SFLCGNG</b>	<b>SFLCORG</b>	<b>SFLCRG</b>	<b>SFLCYG</b>
Ivory	<b>SFLCAQEI</b>	<b>SFLCBEEI</b>	<b>SFLCBKEI</b>	<b>SFLCBEI</b>	<b>SFLCGNEI</b>	<b>SFLCOREI</b>	<b>SFLCREI</b>	<b>SFLCYEI</b>
Light Almond	<b>SFLCAQLA</b>	<b>SFLCBELA</b>	<b>SFLCBKLA</b>	<b>SFLCBLA</b>	<b>SFLCGNLA</b>	<b>SFLCORLA</b>	<b>SFLCRLA</b>	<b>SFLCYLA</b>
Office White	<b>SFLCAQOW</b>	<b>SFLCBEOW</b>	<b>SFLCBKOW</b>	<b>SFLCBOW</b>	<b>SFLCGNOW</b>	<b>SFLCOROW</b>	<b>SFLCROW</b>	<b>SFLCYOW</b>
White	<b>SFLCAQW</b>	<b>SFLCBEW</b>	<b>SFLCBKW</b>	<b>SFLCBW</b>	<b>SFLCGNW</b>	<b>SFLCORW</b>	<b>SFLCRW</b>	<b>SFLCYW</b>

### Standard, Zirconia Ceramic

Housing Color	Adapter Color							
	Aqua	Beige	Black	Blue	Green	Orange	Red	Yellow
Almond	<b>SFLCSAQAL</b>	<b>SFLCSBEAL</b>	<b>SFLCSBKAL</b>	<b>SFLCSBAL</b>	<b>SFLCSGNAL</b>	<b>SFLCSORAL</b>	<b>SFLCSRAL</b>	<b>SFLCSYAL</b>
Black	<b>SFLCSAQBK</b>	<b>SFLCSBEBK</b>	<b>SFLCSBKBK</b>	<b>SFLCSBBK</b>	<b>SFLCSGNBK</b>	<b>SFLCSORBK</b>	<b>SFLCSRBK</b>	<b>SFLCSYBK</b>
Gray	<b>SFLCSAQG</b>	<b>SFLCSBEG</b>	<b>SFLCSBKG</b>	<b>SFLCSBG</b>	<b>SFLCSGNG</b>	<b>SFLCSORG</b>	<b>SFLCSRG</b>	<b>SFLCSYG</b>
Ivory	<b>SFLCSAQEI</b>	<b>SFLCSBEEI</b>	<b>SFLCSBKEI</b>	<b>SFLCSBEI</b>	<b>SFLCSGNEI</b>	<b>SFLCSOREI</b>	<b>SFLCSREI</b>	<b>SFLCSYEI</b>
Light Almond	<b>SFLCSAQLA</b>	<b>SFLCSBELA</b>	<b>SFLCSBKLA</b>	<b>SFLCSBLA</b>	<b>SFLCSGNLA</b>	<b>SFLCSORLA</b>	<b>SFLCSRLA</b>	<b>SFLCSYLA</b>
Office White	<b>SFLCSAQOW</b>	<b>SFLCSBEOW</b>	<b>SFLCSBKOW</b>	<b>SFLCSBOW</b>	<b>SFLCSGNOW</b>	<b>SFLCSOROW</b>	<b>SFLCSROW</b>	<b>SFLCSYOW</b>
White	<b>SFLCSAQW</b>	<b>SFLCSBEW</b>	<b>SFLCSBKW</b>	<b>SFLCSBW</b>	<b>SFLCSGNW</b>	<b>SFLCSORW</b>	<b>SFLCSRW</b>	<b>SFLCSYW</b>

Note: Any green zirconia LC or SC adapter is suitable for APC applications.



SC Simplex, Flush Mount  
SFFSCBOW

## SC Simplex Keystone Adapters

### Flush Mount, Phospor Bronze

Housing Color	Adapter Color							
	Aqua	Beige	Black	Blue	Green	Orange	Red	Yellow
Almond	<b>SFFSCAQAL</b>	<b>SFFSCBEAL</b>	<b>SFFSCBKAL</b>	<b>SFFSCBAL</b>	<b>SFFSCGNAL</b>	<b>SFFSCORAL</b>	<b>SFFSCRAL</b>	<b>SFFSCYAL</b>
Black	<b>SFFSCAQBK</b>	<b>SFFSCBEBK</b>	<b>SFFSCBKBK</b>	<b>SFFSCBBK</b>	<b>SFFSCGNBK</b>	<b>SFFSCORBK</b>	<b>SFFSCRBK</b>	<b>SFFSCYBK</b>
Gray	<b>SFFSCAQG</b>	<b>SFFSCBEG</b>	<b>SFFSCBKG</b>	<b>SFFSCBG</b>	<b>SFFSCGNG</b>	<b>SFFSCORG</b>	<b>SFFSCRG</b>	<b>SFFSCYG</b>
Ivory	<b>SFFSCAQEI</b>	<b>SFFSCBEEI</b>	<b>SFFSCBKEI</b>	<b>SFFSCBEI</b>	<b>SFFSCGNEI</b>	<b>SFFSCOREI</b>	<b>SFFSCREI</b>	<b>SFFSCYEI</b>
Light Almond	<b>SFFSCAQLA</b>	<b>SFFSCBELA</b>	<b>SFFSCBKLA</b>	<b>SFFSCBLA</b>	<b>SFFSCGNLA</b>	<b>SFFSCORLA</b>	<b>SFFSCRLA</b>	<b>SFFSCYLA</b>
Office White	<b>SFFSCAQOW</b>	<b>SFFSCBEOW</b>	<b>SFFSCBKOW</b>	<b>SFFSCBOW</b>	<b>SFFSCGNOW</b>	<b>SFFSCOROW</b>	<b>SFFSCROW</b>	<b>SFFSCYOW</b>
White	<b>SFFSCAQW</b>	<b>SFFSCBEW</b>	<b>SFFSCBKW</b>	<b>SFFSCBW</b>	<b>SFFSCGNW</b>	<b>SFFSCORW</b>	<b>SFFSCRW</b>	<b>SFFSCYW</b>

### Flush Mount, Zirconia Ceramic

Housing Color	Adapter Color							
	Aqua	Beige	Black	Blue	Green	Orange	Red	Yellow
Almond	<b>SFFSCSAQAL</b>	<b>SFFSCSBEAL</b>	<b>SFFSCSBKAL</b>	<b>SFFSCSBAL</b>	<b>SFFSCSGNAL</b>	<b>SFFSCSORAL</b>	<b>SFFSCSRAL</b>	<b>SFFSCSYAL</b>
Black	<b>SFFSCSAQBK</b>	<b>SFFSCSBEBK</b>	<b>SFFSCSBKBK</b>	<b>SFFSCSBBK</b>	<b>SFFSCSGNBK</b>	<b>SFFSCSORBK</b>	<b>SFFSCSRBK</b>	<b>SFFSCSYBK</b>
Gray	<b>SFFSCSAQG</b>	<b>SFFSCSBEG</b>	<b>SFFSCSBKG</b>	<b>SFFSCSBG</b>	<b>SFFSCSGNG</b>	<b>SFFSCSORG</b>	<b>SFFSCSRG</b>	<b>SFFSCSYG</b>
Ivory	<b>SFFSCSAQEI</b>	<b>SFFSCSBEEI</b>	<b>SFFSCSBKEI</b>	<b>SFFSCSBEI</b>	<b>SFFSCSGNEI</b>	<b>SFFSCSOREI</b>	<b>SFFSCSREI</b>	<b>SFFSCSYEI</b>
Light Almond	<b>SFFSCSAQLA</b>	<b>SFFSCSBELA</b>	<b>SFFSCSBKLA</b>	<b>SFFSCSBLA</b>	<b>SFFSCSGNLA</b>	<b>SFFSCSORLA</b>	<b>SFFSCSRLA</b>	<b>SFFSCSYLA</b>
Office White	<b>SFFSCSAQOW</b>	<b>SFFSCSBEOW</b>	<b>SFFSCSBKOW</b>	<b>SFFSCSBOW</b>	<b>SFFSCSGNOW</b>	<b>SFFSCSOROW</b>	<b>SFFSCSROW</b>	<b>SFFSCSYOW</b>
White	<b>SFFSCSAQW</b>	<b>SFFSCSBEW</b>	<b>SFFSCSBKW</b>	<b>SFFSCSBW</b>	<b>SFFSCSGNW</b>	<b>SFFSCSORW</b>	<b>SFFSCSRW</b>	<b>SFFSCSYW</b>

### Standard, Phospor Bronze

Housing Color	Adapter Color							
	Aqua	Beige	Black	Blue	Green	Orange	Red	Yellow
Almond	<b>SFSCAQAL</b>	<b>SFSCBEAL</b>	<b>SFSCBKAL</b>	<b>SFSCBAL</b>	<b>SFSCGNAL</b>	<b>SFSCORAL</b>	<b>SFSCRAL</b>	<b>SFSCYAL</b>
Black	<b>SFSCAQBK</b>	<b>SFSCBEBK</b>	<b>SFSCBKBK</b>	<b>SFSCBBK</b>	<b>SFSCGNBK</b>	<b>SFSCORBK</b>	<b>SFSCRBK</b>	<b>SFSCYBK</b>
Gray	<b>SFSCAQG</b>	<b>SFSCBEG</b>	<b>SFSCBKG</b>	<b>SFSCBG</b>	<b>SFSCGNG</b>	<b>SFSCORG</b>	<b>SFSCRG</b>	<b>SFSCYG</b>
Ivory	<b>SFSCAQEI</b>	<b>SFSCBEEI</b>	<b>SFSCBKEI</b>	<b>SFSCBEI</b>	<b>SFSCGNEI</b>	<b>SFSCOREI</b>	<b>SFSCREI</b>	<b>SFSCYEI</b>
Light Almond	<b>SFSCAQLA</b>	<b>SFSCBELA</b>	<b>SFSCBKLA</b>	<b>SFSCBLA</b>	<b>SFSCGNLA</b>	<b>SFSCORLA</b>	<b>SFSCRLA</b>	<b>SFSCYLA</b>
Office White	<b>SFSCAQOW</b>	<b>SFSCBEOW</b>	<b>SFSCBKOW</b>	<b>SFSCBOW</b>	<b>SFSCGNOW</b>	<b>SFSCOROW</b>	<b>SFSCROW</b>	<b>SFSCYOW</b>
White	<b>SFSCAQW</b>	<b>SFSCBEW</b>	<b>SFSCBKW</b>	<b>SFSCBW</b>	<b>SFSCGNW</b>	<b>SFSCORW</b>	<b>SFSCRW</b>	<b>SFSCYW</b>

### Standard, Zirconia Ceramic

Housing Color	Adapter Color							
	Aqua	Beige	Black	Blue	Green	Orange	Red	Yellow
Almond	<b>SFSCSAQAL</b>	<b>SFSCSBEAL</b>	<b>SFSCSBKAL</b>	<b>SFSCSBAL</b>	<b>SFSCSGNAL</b>	<b>SFSCSORAL</b>	<b>SFSCSRAL</b>	<b>SFSCSYAL</b>
Black	<b>SFSCSAQBK</b>	<b>SFSCSBEBK</b>	<b>SFSCSBKBK</b>	<b>SFSCSBBK</b>	<b>SFSCSGNBK</b>	<b>SFSCSORBK</b>	<b>SFSCSRBK</b>	<b>SFSCSYBK</b>
Gray	<b>SFSCSAQG</b>	<b>SFSCSBEG</b>	<b>SFSCSBKG</b>	<b>SFSCSBG</b>	<b>SFSCSGNG</b>	<b>SFSCSORG</b>	<b>SFSCSRG</b>	<b>SFSCSYG</b>
Ivory	<b>SFSCSAQEI</b>	<b>SFSCSBEEI</b>	<b>SFSCSBKEI</b>	<b>SFSCSBEI</b>	<b>SFSCSGNEI</b>	<b>SFSCSOREI</b>	<b>SFSCSREI</b>	<b>SFSCSYEI</b>
Light Almond	<b>SFSCSAQLA</b>	<b>SFSCSBELA</b>	<b>SFSCSBKLA</b>	<b>SFSCSBLA</b>	<b>SFSCSGNLA</b>	<b>SFSCSORLA</b>	<b>SFSCSRLA</b>	<b>SFSCSYLA</b>
Office White	<b>SFSCSAQOW</b>	<b>SFSCSBEOW</b>	<b>SFSCSBKOW</b>	<b>SFSCSBOW</b>	<b>SFSCSGNOW</b>	<b>SFSCSOROW</b>	<b>SFSCSROW</b>	<b>SFSCSYOW</b>
White	<b>SFSCSAQW</b>	<b>SFSCSBEW</b>	<b>SFSCSBKW</b>	<b>SFSCSBW</b>	<b>SFSCSGNW</b>	<b>SFSCSORW</b>	<b>SFSCSRW</b>	<b>SFSCSYW</b>

Note: Any green zirconia LC or SC adapter is suitable for APC applications.



MT-RJ Flush Mount  
FAMTRJK



ST Simplex, Standard  
SFSTOW



SC Simplex, Standard  
SFSCAOW

## MT-RJ Keystone Adapters

### Standard

Housing Color	Adapter Color							
	Aqua	Beige	Black	Blue	Green	Orange	Red	Yellow
Almond	<b>SFMTRJAQAL</b>	<b>SFMTRJBEAL</b>	<b>SFMTRJBKAL</b>	<b>SFMTRJBAL</b>	<b>SFMTRJGNAL</b>	<b>SFMTRJORAL</b>	<b>SFMTRJRAL</b>	<b>SFMTRJYAL</b>
Black	<b>SFMTRJAQBK</b>	<b>SFMTRJBEBK</b>	<b>SFMTRJBKBK</b>	<b>SFMTRJBBK</b>	<b>SFMTRJGNBK</b>	<b>SFMTRJORBK</b>	<b>SFMTRJRBK</b>	<b>SFMTRJYBK</b>
Gray	<b>SFMTRJAQG</b>	<b>SFMTRJBEG</b>	<b>SFMTRJBKG</b>	<b>SFMTRJBG</b>	<b>SFMTRJGNG</b>	<b>SFMTRJORG</b>	<b>SFMTRJRG</b>	<b>SFMTRJYG</b>
Ivory	<b>SFMTRJAQEI</b>	<b>SFMTRJBEEI</b>	<b>SFMTRJBKEI</b>	<b>SFMTRJBEI</b>	<b>SFMTRJGNEI</b>	<b>SFMTRJOREI</b>	<b>SFMTRJREI</b>	<b>SFMTRJYEI</b>
Light Almond	<b>SFMTRJAQLA</b>	<b>SFMTRJBELA</b>	<b>SFMTRJBKLA</b>	<b>SFMTRJBLA</b>	<b>SFMTRJGNLA</b>	<b>SFMTRJORLA</b>	<b>SFMTRJRLA</b>	<b>SFMTRJYLA</b>
Office White	<b>SFMTRJAQOW</b>	<b>SFMTRJBEOW</b>	<b>SFMTRJBKOW</b>	<b>SFMTRJBOW</b>	<b>SFMTRJGNOW</b>	<b>SFMTRJOROW</b>	<b>SFMTRJROW</b>	<b>SFMTRJYOW</b>
White	<b>SFMTRJAQW</b>	<b>SFMTRJBEW</b>	<b>SFMTRJBKW</b>	<b>SFMTRJBW</b>	<b>SFMTRJGNW</b>	<b>SFMTRJORW</b>	<b>SFMTRJRW</b>	<b>SFMTRJYW</b>

## MT-RJ Keystone Adapters

### Flush Mount

Housing Color	
Almond	<b>FAMTRJKAL</b>
Black	<b>FAMTRJBK</b>
Gray	<b>FAMTRJQGY</b>
Ivory	<b>FAMTRJKEI</b>
Light Almond	<b>FAMTRJKLA</b>
Office White	<b>FAMTRJK</b>
Orange	<b>FAMTRJKO</b>
Telco Ivory	<b>FAMTRJKTI</b>
White	<b>FAMTRJKW</b>
Yellow	<b>FAMTRJKY</b>

## ST-Style to SC Simplex Keystone Adapters

Housing Color	Phosphor Bronze	Zirconia Ceramic
Almond	<b>SFSCSTAL</b>	<b>SFSCSTSAL</b>
Black	<b>SFSCSTBK</b>	<b>SFSCSTSBK</b>
Gray	<b>SFSCSTG</b>	<b>SFSCSTSG</b>
Ivory	<b>SFSCSTEI</b>	<b>SFSCSTSEI</b>
Light Almond	<b>SFSCSTLA</b>	<b>SFSCSTSLA</b>
Office White	<b>SFSCSTOW</b>	<b>SFSCSTSOW</b>
White	<b>SFSCSTW</b>	<b>SFSCSTSW</b>

Note: Adapter is blue

## ST-Style Keystone Adapters

Phosphor Bronze	Zirconia Ceramic
<b>SFSTAL</b>	<b>SFSTSAL</b>
<b>SFSTBK</b>	<b>SFSTSBK</b>
<b>SFSTG</b>	<b>SFSTSG</b>
<b>SFSTEI</b>	<b>SFSTSEI</b>
<b>SFSTLA</b>	<b>SFSTSLA</b>
<b>SFSTOW</b>	<b>SFSTSOW</b>
<b>SFSTW</b>	<b>SFSTSW</b>

Note: Adapter is black oxide

## SC/APC Simplex Keystone Adapters

Zirconia Ceramic
<b>SFSCAAL</b>
<b>SFSCABK</b>
<b>SFSCAG</b>
<b>SFSCAEI</b>
<b>SFSCALA</b>
<b>SFSCAOW</b>
-
-
<b>SFSCAW</b>
-

Note: Adapter is green

## MPO Flush Mount Keystone Adapter

Housing Color	Adapter Color			
	Aqua	Beige	Black	Green
Almond	<b>SFFMTPAQAL</b>	<b>SFFMTPBEAL</b>	<b>SFFMTPBKAL</b>	<b>SFFMTPGNAL</b>
Black	<b>SFFMTPAQBK</b>	<b>SFFMTPBEBK</b>	<b>SFFMTPBKBK</b>	<b>SFFMTPGNBK</b>
Gray	<b>SFFMTPAQG</b>	<b>SFFMTPBEG</b>	<b>SFFMTPBKG</b>	<b>SFFMTPGNG</b>
Ivory	<b>SFFMTPAQEI</b>	<b>SFFMTPBEEI</b>	<b>SFFMTPBKEI</b>	<b>SFFMTPGNEI</b>
Light Almond	<b>SFFMTPAQLA</b>	<b>SFFMTPBELA</b>	<b>SFFMTPBKLA</b>	<b>SFFMTPGNLA</b>
Office White	<b>SFFMTPAQOW</b>	<b>SFFMTPBEOW</b>	<b>SFFMTPBKOW</b>	<b>SFFMTPGNOW</b>
White	<b>SFFMTPAQW</b>	<b>SFFMTPBEW</b>	<b>SFFMTPBKW</b>	<b>SFFMTPGNW</b>





LC Duplex, Snap Mount  
FALCDMC6B



LC Duplex, Screw Mount  
FALCDMS6AQ



SC Duplex, Snap Mount  
FASCDMC6GN



SC Duplex, Screw Mount  
FASCDMS6B



SC Simplex, Snap Mount  
FASCSMC12B

## LC Adapters

**LC Duplex**; recommended cut out: 0.525" X 0.390"

Color	Snap mount, clip installed (6-pack)		Screw mount, clip installed, mounting screws included (6-pack)	
	Phosphor Bronze Sleeve	Zirconia Ceramic Sleeve	Phosphor Bronze Sleeve	Zirconia Ceramic Sleeve
Aqua	<b>FALCDMC6AQ</b>	<b>FALCDSC6AQ</b>	<b>FALCDMS6AQ</b>	<b>FALCDSS6AQ</b>
Beige	<b>FALCDMC6BE</b>	<b>FALCDSC6BE</b>	<b>FALCDMS6BE</b>	<b>FALCDSS6BE</b>
Black	<b>FALCDMC6BK</b>	<b>FALCDSC6BK</b>	<b>FALCDMS6BK</b>	<b>FALCDSS6BK</b>
Blue	<b>FALCDMC6B</b>	<b>FALCDSC6B</b>	<b>FALCDMS6B</b>	<b>FALCDSS6B</b>
Green	<b>FALCDMC6GN</b>	<b>FALCDSC6GN</b>	<b>FALCDMS6GN</b>	<b>FALCDSS6GN</b>
Orange	<b>FALCDMC6OR</b>	<b>FALCDSC6OR</b>	<b>FALCDMS6OR</b>	<b>FALCDSS6OR</b>
Red	<b>FALCDMC6R</b>	<b>FALCDSC6R</b>	<b>FALCDMS6R</b>	<b>FALCDSS6R</b>
Yellow	<b>FALCDMC6Y</b>	<b>FALCDSC6Y</b>	<b>FALCDMS6Y</b>	<b>FALCDSS6Y</b>

**LC Quad**; recommended cut out: 1.024" X 0.375"

Aqua	<b>FALCQMC6AQ</b>	<b>FALCQSC6AQ</b>	<b>FALCQMS6AQ</b>	<b>FALCQSS6AQ</b>
Beige	<b>FALCQMC6BE</b>	<b>FALCQSC6BE</b>	<b>FALCQMS6BE</b>	<b>FALCQSS6BE</b>
Black	<b>FALCQMC6BK</b>	<b>FALCQSC6BK</b>	<b>FALCQMS6BK</b>	<b>FALCQSS6BK</b>
Blue	<b>FALCQMC6B</b>	<b>FALCQSC6B</b>	<b>FALCQMS6B</b>	<b>FALCQSS6B</b>
Green	<b>FALCQMC6GN</b>	<b>FALCQSC6GN</b>	<b>FALCQMS6GN</b>	<b>FALCQSS6GN</b>
Orange	<b>FALCQMC6OR</b>	<b>FALCQSC6OR</b>	<b>FALCQMS6OR</b>	<b>FALCQSS6OR</b>
Red	<b>FALCQMC6R</b>	<b>FALCQSC6R</b>	<b>FALCQMS6R</b>	<b>FALCQSS6R</b>
Yellow	<b>FALCQMC6Y</b>	<b>FALCQSC6Y</b>	<b>FALCQMS6Y</b>	<b>FALCQSS6Y</b>

Note: Any green zirconia LC or SC adapter is suitable for APC applications.

## SC Adapters

**SC Duplex**; recommended cut out: 1.024" X 0.375"

Color	Snap mount, clip installed (6-pack)		Screw mount, clip installed, mounting screws included (6-pack)	
	Phosphor Bronze Sleeve	Zirconia Ceramic Sleeve	Phosphor Bronze Sleeve	Zirconia Ceramic Sleeve
Aqua	<b>FASCDMC6AQ</b>	<b>FASCDSC6AQ</b>	<b>FASCDMS6AQ</b>	<b>FASCDSS6AQ</b>
Beige	<b>FASCDMC6BE</b>	<b>FASCDSC6BE</b>	<b>FASCDMS6BE</b>	<b>FASCDSS6BE</b>
Black	<b>FASCDMC6BK</b>	<b>FASCDSC6BK</b>	<b>FASCDMS6BK</b>	<b>FASCDSS6BK</b>
Blue	<b>FASCDMC6B</b>	<b>FASCDSC6B</b>	<b>FASCDMS6B</b>	<b>FASCDSS6B</b>
Green	<b>FASCDMC6GN</b>	<b>FASCDSC6GN</b>	<b>FASCDMS6GN</b>	<b>FASCDSS6GN</b>
Orange	<b>FASCDMC6OR</b>	<b>FASCDSC6OR</b>	<b>FASCDMS6OR</b>	<b>FASCDSS6OR</b>
Red	<b>FASCDMC6R</b>	<b>FASCDSC6R</b>	<b>FASCDMS6R</b>	<b>FASCDSS6R</b>
Yellow	<b>FASCDMC6Y</b>	<b>FASCDSC6Y</b>	<b>FASCDMS6Y</b>	<b>FASCDSS6Y</b>

**SC Simplex**; recommended cut out: 0.525" X 0.390"

Aqua	<b>FASCSMC12AQ</b>	<b>FASCSSC12AQ</b>	<b>FASCSM12AQ</b>	<b>FASCSS12AQ</b>
Beige	<b>FASCSMC12BE</b>	<b>FASCSSC12BE</b>	<b>FASCSM12BE</b>	<b>FASCSS12BE</b>
Black	<b>FASCSMC12BK</b>	<b>FASCSSC12BK</b>	<b>FASCSM12BK</b>	<b>FASCSS12BK</b>
Blue	<b>FASCSMC12B</b>	<b>FASCSSC12B</b>	<b>FASCSM12B</b>	<b>FASCSS12B</b>
Green	<b>FASCSMC12GN</b>	<b>FASCSSC12GN</b>	<b>FASCSM12GN</b>	<b>FASCSS12GN</b>
Orange	<b>FASCSMC12OR</b>	<b>FASCSSC12OR</b>	<b>FASCSM12OR</b>	<b>FASCSS12OR</b>
Red	<b>FASCSMC12R</b>	<b>FASCSSC12R</b>	<b>FASCSM12R</b>	<b>FASCSS12R</b>
Yellow	<b>FASCSMC12Y</b>	<b>FASCSSC12Y</b>	<b>FASCSM12Y</b>	<b>FASCSS12Y</b>

Note: Any green zirconia LC or SC adapter is suitable for APC applications.



ST Duplex,  
Snap Mount  
FASTDMPB6



ST to SC Duplex,  
Snap Mount  
FASTSCMPB6



ST Simplex,  
Bulkhead  
FASTMPB12



MT-RJ  
Snap Mount  
FAMTRJMPB6



FC Simplex,  
Bulkhead  
FAFCS56



MPO Duplex,  
Screw Mount  
FAMTPDSBK

## ST-Style Duplex Adapters

Description	Recommended Cut-Out	Color	Phosphor Bronze Sleeve	Zirconia Ceramic Sleeve
Snap mount, clip installed, ST duplex*, 6-pack	Any SC duplex 1.024" x 0.375"	Beige	<b>FASTDMS6</b>	-
		Black	<b>FASTDMS6BK</b>	-
		Blue	<b>FASTDMPB6</b>	-
Screw mount, clip installed, ST duplex, 6-pack	1.024" x 0.375"	Blue	-	<b>FASTDSS6</b>
Bulkhead, ST simplex, 12-pack, with nuts and washers	Dia. 0.38", flat 0.31" (Double D)	Black Oxide, Metal	<b>FASTMPB12</b>	<b>FASTSS12</b>

\*These adapters can mount into unloaded FSP adapter panels (see page G11).

## SC to ST-Style Duplex Adapters

Description	Recommended SC Duplex Cut-Out	Color	Phosphor Bronze Sleeve	Zirconia Ceramic Sleeve
Snap mount, clip installed, 6-pack	1.024" x 0.375"	Aqua	<b>FASTSCDMC6AQ</b>	-
		Beige	<b>FASTSCDMC6</b>	-
		Black	<b>FASTSCDMC6BK</b>	-
		Blue	<b>FASTSCMPB6</b>	<b>FASTSCDSC6</b>
		Orange	<b>FASTSCDMC6OR</b>	<b>FASTSCDSC6OR</b>
		Red	<b>FASTSCDMC6R</b>	<b>FASTSCDSC6R</b>
		Yellow	<b>FASTSCDMC6Y</b>	<b>FASTSCDSC6Y</b>
Screw mount, clip installed, 6-pack	1.024" x 0.375"	Blue	<b>FASTSCMPB6</b>	-

## MPO Simplex Adapters

Description	Recommended MPO Simplex Cut-Out	Color	Snap Mount	Screw Mount
Fits any MPO simplex cut-out, 6-pack Compatible with 12- or 24-fiber MPO connectors	0.590" x 0.394"	Aqua	<b>FAMTPAQ</b>	<b>FAMTPSAQ</b>
		Beige	<b>FAMTPBE</b>	<b>FAMTPSBE</b>
		Black	<b>FAMTPBK</b>	<b>FAMTPSBK</b>
		Green	<b>FAMTPGN</b>	<b>FAMTPSGN</b>
		Gray*	<b>FAMTPRPGY*</b>	<b>FAMTPSRPGY*</b>
		Violet	<b>FAMTPVI</b>	<b>FAMTPSVI</b>

\*Reversed polarity

Note: Standard MPO polarity is key-up/key-down. Reversed polarity is key-up/key-up.

## MPO Duplex Adapters

Description	Recommended SC Duplex Cut-Out	Color	Snap Mount	Screw Mount
Fits any SC duplex cut-out, 6-pack	1.024" x 0.375"	Aqua	<b>FAMTPDAQ</b>	<b>FAMTPDSAQ</b>
		Beige	<b>FAMTPDBE</b>	<b>FAMTPDSBE</b>
		Black	<b>FAMTPDBK</b>	<b>FAMTPDSBK</b>
		Green	<b>FAMTPDGN</b>	<b>FAMTPDSGN</b>
		Violet	<b>FAMTPDVI</b>	<b>FAMTPDSVI</b>

## FC Adapters

Description	Recommended Cut-Out	Finish	Zirconia Ceramic Sleeve
Bulkhead, singlemode, 6-pack	Dia. 0.38", flat 0.31" (Double D)	Nickel Plated	<b>FAFCS56</b>

## MT-RJ Adapters

Description	Recommended Cut-Out	Color	Snap Mount
Snap mount, clip installed, 6-pack	0.525" x 0.390" (SC simplex)	Aqua	<b>FAMTRJC6AQ</b>
		Beige	<b>FAMTRJMPB6</b>
		Black	<b>FAMTRJC6BK</b>



SC Duplex, 12-Port, OM3  
OCSC50G



ST Duplex, 12-Port, OM2  
OCST50



LC Duplex, 12-Port, OS2  
OCLCSM



LC Quad, 24-Port, OM3  
OCLCQ50G



MT-RJ, 12-Port, OM2  
OCRJ50

**MPO 12- and 24-Fiber Cassettes**

Type A polarity

Fiber Type	Color	SC Duplex	ST-Style	LC Duplex 12F	LC Duplex 24F*	LC Quad 24F*	MT-RJ
50µm, OM2	Black	<b>OCSC50</b>	<b>OCST50</b>	<b>OCLC50</b>	<b>OCLCD50</b>	<b>OCLCQ50</b>	<b>OCRJ50</b>
50µm, OM3	Aqua	<b>OCSC50G</b>	-	<b>OCLC50G</b>	<b>OCLCD50G</b>	<b>OCLCQ50G</b>	<b>OCRJ50G</b>
50µm, OM4	Aqua	<b>OCSC50G4</b>	-	<b>OCLC50G4</b>	<b>OCLCD50G4</b>	<b>OCLCQ50G4</b>	-
62.5µm, OM1	Beige	<b>OCSC62</b>	<b>OCST62</b>	<b>OCLC62</b>	<b>OCLCD62</b>	<b>OCLCQ62</b>	<b>OCRJ62</b>
SM, OS2	Blue	<b>OCSCSM</b>	<b>OCSTSM</b>	<b>OCLCSM</b>	<b>OCLCDSM</b>	<b>OCLCQSM</b>	-

\*24 fibers, 2-12 fiber MPO receptacles in rear.

Note: See G16 for Keyed LC fiber cassettes. See page J3 for ultra compact high density cassettes used in the FCRHD1UBK enclosure.



LC Duplex, 6-Port  
FSPLCDM3AQ



LC Duplex, 24-Port  
FSPLCDM12AQ



LC Quad, 24-Port  
FSPLCQS6Y



SC Duplex, 6-Port  
FSPSCDM3B



SC Duplex, 12-Port  
FSPSCDS6Y



ST/SC Duplex, 6-Port  
FSPSCST3



ST/SC Duplex, 12-Port  
FSPSCST6

## LC Duplex FSP Adapter Panels

	LC 6-Port (3 LC Duplex)		LC 12-Port (6 LC Duplex)		LC 24-Port (12 LC Duplex)	
Color	Phosphor Bronze Multimode Only	Zirconia Ceramic Single/Multimode	Phosphor Bronze Multimode Only	Zirconia Ceramic Single/Multimode	Phosphor Bronze Multimode Only	Zirconia Ceramic Single/Multimode
Aqua	<b>FSPLCDM3AQ</b>	<b>FSPLCDS3AQ</b>	<b>FSPLCDM6AQ</b>	<b>FSPLCDS6AQ</b>	<b>FSPLCDM12AQ</b>	<b>FSPLCDS12AQ</b>
Beige	<b>FSPLCDM3BE</b>	<b>FSPLCDS3BE</b>	<b>FSPLCDM6BE</b>	<b>FSPLCDS6BE</b>	<b>FSPLCDM12BE</b>	<b>FSPLCDS12BE</b>
Black	<b>FSPLCDM3BK</b>	<b>FSPLCDS3BK</b>	<b>FSPLCDM6BK</b>	<b>FSPLCDS6BK</b>	<b>FSPLCDM12BK</b>	<b>FSPLCDS12BK</b>
Blue	<b>FSPLCDM3B</b>	<b>FSPLCDS3B</b>	<b>FSPLCDM6B</b>	<b>FSPLCDS6B</b>	<b>FSPLCDM12B</b>	<b>FSPLCDS12B</b>
Green	<b>FSPLCDM3GN</b>	<b>FSPLCDS3GN</b>	<b>FSPLCDM6GN</b>	<b>FSPLCDS6GN</b>	<b>FSPLCDM12GN</b>	<b>FSPLCDS12GN</b>
Orange	<b>FSPLCDM3OR</b>	<b>FSPLCDS3OR</b>	<b>FSPLCDM6OR</b>	<b>FSPLCDS6OR</b>	<b>FSPLCDM12OR</b>	<b>FSPLCDS12OR</b>
Red	<b>FSPLCDM3R</b>	<b>FSPLCDS3R</b>	<b>FSPLCDM6R</b>	<b>FSPLCDS6R</b>	<b>FSPLCDM12R</b>	<b>FSPLCDS12R</b>
Yellow	<b>FSPLCDM3Y</b>	<b>FSPLCDS3Y</b>	<b>FSPLCDM6Y</b>	<b>FSPLCDS6Y</b>	<b>FSPLCDM12Y</b>	<b>FSPLCDS12Y</b>

## LC Quad FSP Adapter Panels

	LC 12-Port (3 LC Quad)		LC 16-Port (4 LC Quad)		LC 24-Port (6 LC Quad)	
Color	Phosphor Bronze Multimode Only	Zirconia Ceramic Single/Multimode	Phosphor Bronze Multimode Only	Zirconia Ceramic Single/Multimode	Phosphor Bronze Multimode Only	Zirconia Ceramic Single/Multimode
Aqua	<b>FSPLCQM3AQ</b>	<b>FSPLCQS3AQ</b>	<b>FSPLCQM4AQ</b>	<b>FSPLCQS4AQ</b>	<b>FSPLCQM6AQ</b>	<b>FSPLCQS6AQ</b>
Beige	<b>FSPLCQM3BE</b>	<b>FSPLCQS3BE</b>	<b>FSPLCQM4BE</b>	<b>FSPLCQS4BE</b>	<b>FSPLCQM6BE</b>	<b>FSPLCQS6BE</b>
Black	<b>FSPLCQM3BK</b>	<b>FSPLCQS3BK</b>	<b>FSPLCQM4BK</b>	<b>FSPLCQS4BK</b>	<b>FSPLCQM6BK</b>	<b>FSPLCQS6BK</b>
Blue	<b>FSPLCQM3B</b>	<b>FSPLCQS3B</b>	<b>FSPLCQM4B</b>	<b>FSPLCQS4B</b>	<b>FSPLCQM6B</b>	<b>FSPLCQS6B</b>
Green	<b>FSPLCQM3GN</b>	<b>FSPLCQS3GN</b>	<b>FSPLCQM4GN</b>	<b>FSPLCQS4GN</b>	<b>FSPLCQM6GN</b>	<b>FSPLCQS6GN</b>
Orange	<b>FSPLCQM3OR</b>	<b>FSPLCQS3OR</b>	<b>FSPLCQM4OR</b>	<b>FSPLCQS4OR</b>	<b>FSPLCQM6OR</b>	<b>FSPLCQS6OR</b>
Red	<b>FSPLCQM3R</b>	<b>FSPLCQS3R</b>	<b>FSPLCQM4R</b>	<b>FSPLCQS4R</b>	<b>FSPLCQM6R</b>	<b>FSPLCQS6R</b>
Yellow	<b>FSPLCQM3Y</b>	<b>FSPLCQS3Y</b>	<b>FSPLCQM4Y</b>	<b>FSPLCQS4Y</b>	<b>FSPLCQM6Y</b>	<b>FSPLCQS6Y</b>

## SC Duplex FSP Adapter Panels

	SC 6-Port (3 SC Duplex)		SC 8-Port (4 SC Duplex)		SC 12-Port (6 SC Duplex)	
Color	Phosphor Bronze Multimode Only	Zirconia Ceramic Single/Multimode	Phosphor Bronze Multimode Only	Zirconia Ceramic Single/Multimode	Phosphor Bronze Multimode Only	Zirconia Ceramic Single/Multimode
Aqua	<b>FSPSCDM3AQ</b>	<b>FSPSCDS3AQ</b>	<b>FSPSCDM4AQ</b>	<b>FSPSCDS4AQ</b>	<b>FSPSCDM6AQ</b>	<b>FSPSCDS6AQ</b>
Beige	<b>FSPSCDM3BE</b>	<b>FSPSCDS3BE</b>	<b>FSPSCDM4BE</b>	<b>FSPSCDS4BE</b>	<b>FSPSCDM6BE</b>	<b>FSPSCDS6BE</b>
Black	<b>FSPSCDM3BK</b>	<b>FSPSCDS3BK</b>	<b>FSPSCDM4BK</b>	<b>FSPSCDS4BK</b>	<b>FSPSCDM6BK</b>	<b>FSPSCDS6BK</b>
Blue	<b>FSPSCDM3B</b>	<b>FSPSCDS3B</b>	<b>FSPSCDM4B</b>	<b>FSPSCDS4B</b>	<b>FSPSCDM6B</b>	<b>FSPSCDS6B</b>
Green	<b>FSPSCDM3GN</b>	<b>FSPSCDS3GN</b>	<b>FSPSCDM4GN</b>	<b>FSPSCDS4GN</b>	<b>FSPSCDM6GN</b>	<b>FSPSCDS6GN</b>
Orange	<b>FSPSCDM3OR</b>	<b>FSPSCDS3OR</b>	<b>FSPSCDM4OR</b>	<b>FSPSCDS4OR</b>	<b>FSPSCDM6OR</b>	<b>FSPSCDS6OR</b>
Red	<b>FSPSCDM3R</b>	<b>FSPSCDS3R</b>	<b>FSPSCDM4R</b>	<b>FSPSCDS4R</b>	<b>FSPSCDM6R</b>	<b>FSPSCDS6R</b>
Yellow	<b>FSPSCDM3Y</b>	<b>FSPSCDS3Y</b>	<b>FSPSCDM4Y</b>	<b>FSPSCDS4Y</b>	<b>FSPSCDM6Y</b>	<b>FSPSCDS6Y</b>

## SC to ST-Style Duplex FSP Panels

Description	Phosphor Bronze Sleeve	Zirconia Ceramic Sleeve
SC-ST 6-port, blue	<b>FSPSCST3</b>	<b>FSPSCSTDS3</b>
SC-ST 12-port, blue	<b>FSPSCST6</b>	<b>FSPSCSTDS6</b>

## ST-Style Duplex FSP Adapter Panels

Description	Phosphor Bronze Sleeve	Zirconia Ceramic Sleeve
ST duplex, 6-port, blue	<b>FSPSTD3</b>	<b>FSPSTD3S</b>
ST duplex, 12-port, blue	<b>FSPSTD6</b>	<b>FSPSTD6S</b>



FC Duplex, 6-Port  
FSPFC6



SC Simplex, 6-Port  
FSPSC6



SC/APC Simplex, 6-Port  
FSPSCA6



ST Simplex, 6-Port  
FSPST6



MPO Simplex, 6-Port  
FSPMTPAQ6



Jack-Pack®, 4-Port  
FSPHD4X

## FC Simplex

Nickle Plate

Description	Zirconia Ceramic Sleeve
FC 6-port (6 FC)	<b>FSPFC6</b>
FC 8-port (8 FC)	<b>FSPFCSS8</b>

## SC Simplex

Blue

Description	Phosphor Bronze Sleeve	Zirconia Ceramic Sleeve
SC 6-port (6 SC)	<b>FSPSC6</b>	<b>FSPSCSS6</b>
SC 8-port (8 SC)	<b>FSPSC8</b>	<b>FSPSCSS8</b>
SC 12-port (12 SC)	<b>FSPSC12</b>	<b>FSPSCSS12</b>

## SC Simplex, APC

Green

Description	Zirconia Ceramic Sleeve
SC 6-port (6 SC)	<b>FSPSCA6</b>
SC 8-port (8 SC)	<b>FSPSCA8</b>

## ST-Style Simplex

Yellow

Description	Phosphor Bronze Sleeve	Zirconia Ceramic Sleeve
ST-style 6-port	<b>FSPST6</b>	<b>FSPSTSS6</b>
ST-style 8-port	<b>FSPST8</b>	<b>FSPSTSS8</b>

## MT-RJ

Black

Description	Catalog No.
MT-RJ 6-port	<b>FSPMTRJ6</b>
MT-RJ 8-port	<b>FSPMTRJ8</b>

## JACK-PACK®, Unloaded

Description	Catalog No.
Keystone 4-port	<b>FSPHD4X</b>
Keystone 6-port	<b>FSPHD6X*</b>

\*Will not fit into FTU2 series, FTU4SP or FCR2U9SP enclosures.

## MPO, Standard Polarity\*

Color	Application	Simplex 6-Port (72 Fiber)	Duplex 8-Port (96 Fiber)	Duplex 12-Port (144 Fiber)
Aqua	OM3/OM4	<b>FSPMTPAQ6</b>	<b>FSPMTPDAQ4</b>	<b>FSPMTPDAQ6</b>
Beige	OM1/OM2	<b>FSPMTPBE6</b>	<b>FSPMTPDBE4</b>	<b>FSPMTPDBE6</b>
Black	Universal	<b>FSPMTPBK6</b>	<b>FSPMTPDBK4</b>	<b>FSPMTPDBK6</b>
Green	Singlemode	<b>FSPMTPGN6</b>	<b>FSPMTPDGN4</b>	<b>FSPMTPDGN6</b>
Violet	OM4	<b>FSPMTPVI6</b>	<b>FSPMTPDVI4</b>	<b>FSPMTPDVI6</b>

\*Standard MPO polarity is key-up/key-down. Reversed polarity is key-up/key-up.

Note: Compatible with 12- or 24-fiber MPO connectors.

## MPO, Reversed Polarity\*

Color	Simplex 6-Port (72 Fiber)
Gray	<b>FSPMTPRPGY6</b>



Blank Panel  
FSPB



SC Simplex, 6-Port  
FSPSC6X



SC Simplex, 6-Port  
FSPSC8X



SC Duplex, 6-Port  
FSPSCD3X




SC Duplex, 12-Port  
FSPSCD6X

## FSP Adapter Panels, Unloaded

Description	Catalog No.	Description	Catalog No.
Blank, snap-in	<b>FSPB</b>	4 SC duplex or LC quad	<b>FSPSCD4X</b>
6 SC simplex or LC duplex	<b>FSPSC6X</b>	6 SC duplex or LC quad	<b>FSPSCD6X</b>
8 SC simplex or LC duplex	<b>FSPSC8X</b>	6 ST-style	<b>FSPST6X</b>
12 SC simplex or LC duplex	<b>FSPSC12X</b>	8 ST-style	<b>FSPST8X</b>
3 SC duplex or LC quad	<b>FSPSCD3X</b>	6 MTP-style	<b>FSPSC6X</b>

Note: Use Hubbell snap mount or screw mount adapters (screws included).

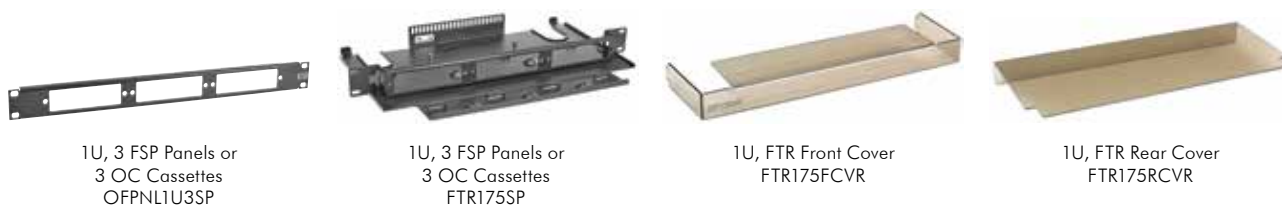

1U, 3 FSP Panels or  
3 OC Cassettes  
OFPNL1U3SP

1U, 3 FSP Panels or  
3 OC Cassettes  
FTR175SP

1U, FTR Front Cover  
FTR175FCVR

1U, FTR Rear Cover  
FTR175RCVR

## FTR Series Open Cabling Interconnect Trays, 19" Rack Mount

Rack Units	Height Inches (mm)	Width Inches (mm)	Depth Inches (mm)	FSP Panel Capacity	Splice Tray Capacity	Max LC Port Capacity	Catalog No.
1	1.75" (44)	17" (432)	12" (305)	3	2	72	<b>FTR175SP</b>

Note: Compatible with FSP Series panels and OC Series cassettes

## LEXAN® Covers for FTR Series Interconnect Trays

For FTR175SP, smoke tint

Description	Catalog No.
Front cover	<b>FTR175FCVR</b>
Rear cover	<b>FTR175RCVR</b>

## OFPNL Series Open Cabling Interconnect Panels, 19" Rack Mount

Rack Units	Height Inches (mm)	Width Inches (mm)	FSP Panel Capacity	Max LC Port Capacity	Catalog No.
1	1.75" (44)	17" (432)	3	72	<b>OFPNL1U3SP</b>
1	1.75" (44)	17" (432)	2	48	<b>OFPNL1U2SP</b>

Note: Compatible with FSP Series panels and OC Series cassettes

## Accessories

Description	Catalog No.
Cable management bar, 19" rack mount	<b>CMBR</b>
Cable management bar, 19", 3" offset	<b>ECMBR3</b>
Cable management bar, 19", 6" offset	<b>ECMBR6</b>
Cable management bar, 19", straight	<b>ECMBRS</b>
Blank FSP panel	<b>FSPB</b>

LEXAN is a registered trademark of General Electric Company.



Precision Cleaver  
OFCLV5



Buffer Strip Tool  
OFSTRIP



Fiber Test Set  
OFPM813, OFLS813



Fiber Microscope  
OFSCOPE1



Epoxy Termination Kit  
OFTK03C

## Fiber Cleavers

Description	Catalog No.
Multimode fiber only	<b>OFCLV3</b>
SM or MM fiber, CT-30 style, with case	<b>OFCLV4</b>
SM or MM fiber, precision, with case	<b>OFCLV5</b>

## Fiber Strip Tools

Description	Catalog No.
900 micron buffered fiber	<b>OFSTRIP</b>
Universal 250/900μ, 2.0, 2.5, 3.0mm cable	<b>OFSTRIP2</b>

## Kevlar® Cable Scissors

Description	Catalog No.
For cutting Kevlar reinforced cables up to 24-strand, non-armored	<b>OFSCRS</b>

## Visual Fault Locators (ST, SC, LC)

Includes: batteries, LC adapter, holster, wrist strap and end protectors

Description	Catalog No.
Visual fault locator	<b>OFVFLKT1</b>
LC adapter, separate	<b>OFVLCADP</b>

*TIP: Use a VFL during termination for optimum test results.*

## Multimode Test Set

Includes: (1) power meter, (1) dual wavelength LED source, (1) soft pouch, batteries

Description	Catalog No.
Complete tester kit	<b>OFPLK813A</b>
Power meter dual wavelength	<b>OFPM813</b>
LED light source dual wavelength, multimode	<b>OFLS813</b>

## Connector Installation Tool Pouch

Includes: sapphire scribe, scribe guide, black permanent marker, carbon fiber scissors, strip template and polishing fixture, ruler, buffer/cable jacket stripper, 200X microscope assembly, crimp tool and die

Description	Catalog No.
For SC/ST-style connectors crimp or adhesive termination	<b>OFTP02C</b>

## Microscope, 400X

Includes: built-in illuminator, batteries, SC/ST-style adapter, and soft pouch

Description	Catalog No.
SC/ST-style microscope	<b>OFSCOPE1</b>
LC adapter (400X microscope only)	<b>FOADPTLC</b>

## Microscope, 200X (ST, SC, LC)

Includes: batteries, LC adapter, and soft pouch

Description	Catalog No.
ST, SC, LC microscope	<b>OFSCOPE2</b>

## Termination Kits, Epoxy

Includes: canned air, 10oz, tool pouch (OFTP02C) with fiber and cable preparation tools, wipes, heat cure epoxy, anaerobic adhesive and primer, polishing paper, polishing pad, heat-cure epoxy oven, safety glasses, syringes, needles, cure adapters and clips

For SC/ST-style connectors	Catalog No.
16-Port (110V AC)	<b>OFTK03C</b>
8-Port (220V AC)	<b>OFTK04C*</b>

\*Does not contain canned air.

## Field Installation Tool Kit, Epoxy and Crimp Style

Includes:

- OFSTRIP2 fiber strip tool
- OFCMT04 crimp tool
- Universal 2.5mm and 1.25mm polishing pucks
- Polishing plate
- 70 durometer polishing pad
- Polishing paper
- 200X microscope with 2.5mm and 1.25mm universal adapters
- Carbon fiber scissors
- Reversible blade carbide scribe
- Permanent marker
- Protective glasses
- Debris bottle for fiber safety
- Alcohol wipes
- Lint free cleaning wipes
- Water bottle
- Alcohol bottle
- 6" ruler
- 10" long x 7" wide x 6.25" high carrying case with the lid functioning as a portable work surface

Description	Catalog No.
Field installation tool kit for SC/ST and LC connectors	<b>OFTK05</b>



Epoxy/Crimp Termination Kit  
OFTK05

Note: See PROclick® connectors on page G3 for termination tool applications. Kevlar is a registered trademark of E. I. du Pont de Nemours and Company.



Anaerobic Adhesive Kit  
OFCAP



Loose Tube Break-Out Kit  
OFBOKT6



Crimp Tool  
OFCMT04



Fiber Scribe  
OFSCRIBE



Cable Management Clip  
FBRMGTCPLK4

## Epoxy Adhesive Kit

Includes: (6) tubes 1g, (6) syringes/needles

Description	Catalog No.
Easy mix 1g tubes	<b>OFCEP</b>

## Anaerobic Adhesive Kit

Includes: Primer and adhesive, (10) syringes and (10) needles

Description	Catalog No.
Anaerobic adhesive kit cures in 6–10 seconds	<b>OFCAP</b>
Replacement bottle of primer only	<b>OFPRIME</b>

## Epoxy Cure Adapters

Includes: package of (6) adapters for heat cure oven

Description	Catalog No.
SC/ST-style	<b>OFCA</b>
LC	<b>OFCALC</b>

## Loose Tube OSP Cable Break-Out Kits

Includes: tube kit, break-out block and crimp bushing

Description	Catalog No.
6-fiber break-out kit	<b>OFBOKT6</b>
12-fiber break-out kit	<b>OFBOKT12</b>

## Fiber Cable Management Radius Clips

Includes: pack of (4) self-adhering clips with bend radius control element

Description	Catalog No.
Cable clips	<b>FBRMGTCPLK4</b>

## LC Duplex Connector Extraction Tool

Includes: (1) tool, individually packaged, ideal for servicing high density interconnections

Description	Catalog No.
Connector extraction tool	<b>OFLCDTOOL1</b>

## Crimp Tool

Dual hex cavity: 0.178"/0.151", flat crimp 0.052", hex crimp 0.136", hardened die

Description	Catalog No.
For SC/ST-style epoxy/anaerobic or crimp style connectors	<b>OFCMT04</b>

## Hand Scribe Tool

Includes: (1) tool and scribe guide

Description	Catalog No.
Sapphire blade	<b>OFSCRIBE</b>

## Scribe Guide Fixture

6-pack

Description	Catalog No.
Suitable for SC, ST-style, or LC connectors	<b>OFSG</b>

## Polishing Fixture

Includes: (1) stainless steel puck, polished surface; SC/ST-style or LC compatible

Description	Catalog No.
SC/ST-style	<b>OFPUCK</b>
LC	<b>OFPUCKLC</b>

## Polishing Film

Includes: (25) each of 5 $\mu$ , 1 $\mu$  and 0.3 $\mu$  sheets, (1) polishing pad

Description	Catalog No.
Replacement kit	<b>OFLFP</b>

## OPTISOK® Pulling Grips

Bundle Size Range

Range	Catalog No.
0.125–0.562"	<b>CCPS1</b>
0.250–0.750"	<b>CCPS2</b>
0.750–1.750"	<b>CCPS3</b>

## Fusion Splice Sleeves

25-pack

Description	Catalog No.
40mm length, 10mm cleave	<b>FSHST401025</b>
12-fiber ribbon	<b>FRSHST401025</b>

## Fiber Management Spool

2-pack

Description	Catalog No.
Adhesive mount, yellow	<b>OFSPPOOLPK2</b>

## Fusion Splice Trays

Description

Description	Catalog No.
Aluminum, 12-fiber	<b>STRAY12F</b>
Aluminum, 24-fiber	<b>STRAY24F</b>
Plastic, yellow, 24-fiber	<b>OFSPPLKT24F</b>





Cleaning Kit without Clicker Cleaners  
OFCLEANKT1



Cleaning Kit with Clicker Cleaners  
OFCLEANKT2



Clicker Cleaner  
LC/MU/APC  
OFCCLICK750LC



Cleaning Sticks  
SC/FC/APC  
OFSTIX50SC



Cloth Wipes  
Cartridge  
OFWIPES400

## Cleaning Kit 1 without Sticklers® CleanClicker®

Includes:

- Optical fiber cleaning fluid, 3oz, non-hazardous
- (2) packs of 50 LC/MU cleaning sticks
- (2) packs of 50 SC/FC cleaning sticks
- (1) box of 400 lint-free wipes
- (1) dispenser of 90 lint-free wipes
- Instructions on product packaging
- Protective carrying bag

Description	Catalog No.
Cleaning kit without clickers	<b>OFCLEANKT1</b>

## Cleaning Kit 2 with Sticklers® CleanClicker®

Includes:

- LC/MU clicker cleaner, 750 clicks
- SC/FC clicker cleaner, 750 clicks
- MPO clicker cleaner, 600 clicks
- Optical fiber cleaning fluid, 3oz, non-hazardous
- (2) packs of 50 LC/MU cleaning sticks
- (2) packs of 50 SC/FC cleaning sticks
- (1) box of 400 lint-free wipes
- (1) dispenser of 90 lint-free wipes
- Instructions on product packaging
- Protective carrying bag

Description	Catalog No.
Cleaning kit with LC, SC, MPO clickers	<b>OFCLEANKT2</b>

## Sticklers® CleanClicker®, SC/ST/FC/APC

Includes: (1) disposable cleaner tape cartridge

Description	Catalog No.
2.5mm, SC/FC/APC	<b>OFCCLICK750SC</b>

## Sticklers® CleanClicker®, LC/MU/APC

Includes: (1) disposable cleaner tape cartridge

Description	Catalog No.
2.5mm, LC/MU/APC	<b>OFCCLICK750LC</b>

## Sticklers® CleanClicker®, MPO/APC

Includes: (1) disposable cleaner tape cartridge

Description	Catalog No.
MPO male, female, flat/APC	<b>OFCCLICK600MPO</b>

## Sticklers® CleanStixx™, LC/MU/APC

Includes: (1) pack of 50 disposable cleaning sticks

Description	Catalog No.
LC/MU/APC 1.25mm port cleaning sticks	<b>OFSTIX50LC</b>

## Sticklers® CleanStixx™, SC/ST/FC/APC

Includes: (1) pack of 50 disposable cleaning sticks

Description	Catalog No.
SC/FC/APC 2.50mm port cleaning sticks	<b>OFSTIX50SC</b>

## Sticklers® Cleaning Fluid, Optical

Includes: (1) 3oz pump dispenser

Description	Catalog No.
3oz cleaning fluid, pump, non-hazardous	<b>OFCLEANER3OZ</b>

## Sticklers® CleanWipes™, Cartridge

Includes: (1) 4-slot box

Description	Catalog No.
Box of 100 lint-free sheets, 4 wipes/sheet	<b>OFWIPES400</b>

## Sticklers® CleanWipes™, Dispenser

Includes: (1) roll of 90 sheets

Description	Catalog No.
Tube of 90 lint-free sheets, multi-purpose	<b>OFWIPES90</b>

Sticklers, CleanClicker, CleanStixx and CleanWipes are trademarks of MicroCare.



Keyed LC, OS2  
FCKLCP50GM12BL



Keyed LC to SC, OM3  
KLCDFPSC50GM01YL

**Secure-IT Keyed LC Pre-Polished Connectors**

Housing Color	50μM, OM3 Aqua Boot	50μM, OM2 Black Boot	62.5μM, OM1 Beige Boot	SM, OS2 Blue Boot
Blue	<b>FCKLCP50GM12BL</b>	<b>FCKLCP50M12BL</b>	<b>FCKLCP62M12BL</b>	<b>FCKLCP5M12BL</b>
Green	<b>FCKLCP50GM12GN</b>	<b>FCKLCP50M12GN</b>	<b>FCKLCP62M12GN</b>	<b>FCKLCP5M12GN</b>
Red	<b>FCKLCP50GM12RD</b>	<b>FCKLCP50M12RD</b>	<b>FCKLCP62M12RD</b>	<b>FCKLCP5M12RD</b>
Yellow	<b>FCKLCP50GM12YL</b>	<b>FCKLCP50M12YL</b>	<b>FCKLCP62M12YL</b>	<b>FCKLCP5M12YL</b>

**LC Duplex Clip**

Black	<b>FCKLCDCLP12BK</b>
-------	----------------------

Note: Box of 12 individually bagged connectors with dust caps installed and termination instructions.  
Special Housing Colors also available: **AQ** (Aqua), **BR** (Brown), **OR** (Orange), **RO** (Rose), **SL** (Slate) and **VI** (Violet).  
Tip: PROclick® LC connectors may be used behind the wall with any hybrid snap fitting. See Keyed LC to LC Hybrid Snap Fittings below.

**Keyed LC 10GbE Multimode OM3 Patch Cords**

1 meter, 50μm, OM3, aqua cable jacket

Housing Color	Keyed LC to Keyed LC	Keyed LC to Standard LC	Keyed LC to Standard SC
Aqua	<b>KLCDFP50GM01AQ</b>	<b>KLCDFPLC50GM01AQ</b>	<b>KLCDFPSC50GM01AQ</b>
Blue	<b>KLCDFP50GM01BL</b>	<b>KLCDFPLC50GM01BL</b>	<b>KLCDFPSC50GM01BL</b>
Brown	<b>KLCDFP50GM01BR</b>	<b>KLCDFPLC50GM01BR</b>	<b>KLCDFPSC50GM01BR</b>
Green	<b>KLCDFP50GM01GN</b>	<b>KLCDFPLC50GM01GN</b>	<b>KLCDFPSC50GM01GN</b>
Orange	<b>KLCDFP50GM01OR</b>	<b>KKLCDFPLC50GM01OR</b>	<b>KLCDFPSC50GM01OR</b>
Red	<b>KLCDFP50GM01RD</b>	<b>KLCDFPLC50GM01RD</b>	<b>KLCDFPSC50GM01RD</b>
Rose	<b>KLCDFP50GM01RO</b>	<b>KKLCDFPLC50GM01RO</b>	<b>KLCDFPSC50GM01RO</b>
Slate	<b>KLCDFP50GM01SL</b>	<b>KKLCDFPLC50GM01SL</b>	<b>KLCDFPSC50GM01SL</b>
Violet	<b>KLCDFP50GM01VI</b>	<b>KKLCDFPLC50GM01VI</b>	<b>KLCDFPSC50GM01VI</b>
Yellow	<b>KLCDFP50GM01YL</b>	<b>KLCDFPLC50GM01YL</b>	<b>KLCDFPSC50GM01YL</b>

2 meters, 50μm, OM3, aqua cable jacket

Housing Color	Keyed LC to Keyed LC	Keyed LC to Standard LC	Keyed LC to Standard SC
Aqua	<b>KLCDFP50GM02AQ</b>	<b>KLCDFPLC50GM02AQ</b>	<b>KLCDFPSC50GM02AQ</b>
Blue	<b>KLCDFP50GM02BL</b>	<b>KLCDFPLC50GM02BL</b>	<b>KLCDFPSC50GM02BL</b>
Brown	<b>KLCDFP50GM02BR</b>	<b>KLCDFPLC50GM02BR</b>	<b>KLCDFPSC50GM02BR</b>
Green	<b>KLCDFP50GM02GN</b>	<b>KLCDFPLC50GM02GN</b>	<b>KLCDFPSC50GM02GN</b>
Orange	<b>KLCDFP50GM02OR</b>	<b>KKLCDFPLC50GM02OR</b>	<b>KLCDFPSC50GM02OR</b>
Red	<b>KLCDFP50GM02RD</b>	<b>KLCDFPLC50GM02RD</b>	<b>KLCDFPSC50GM02RD</b>
Rose	<b>KLCDFP50GM02RO</b>	<b>KKLCDFPLC50GM02RO</b>	<b>KLCDFPSC50GM02RO</b>
Slate	<b>KLCDFP50GM02SL</b>	<b>KKLCDFPLC50GM02SL</b>	<b>KLCDFPSC50GM02SL</b>
Violet	<b>KLCDFP50GM02VI</b>	<b>KKLCDFPLC50GM02VI</b>	<b>KLCDFPSC50GM02VI</b>
Yellow	<b>KLCDFP50GM02YL</b>	<b>KLCDFPLC50GM02YL</b>	<b>KLCDFPSC50GM02YL</b>

Note: Individually bagged with dust caps installed and factory test data.



Keyed LC to SC, OM3  
KLCDFPSC50GM01YL

## Keyed LC 10GbE Multimode OM3 Patch Cords

3 meters, 50µm, OM3, aqua cable jacket

Housing Color	Keyed LC to Keyed LC	Keyed LC to Standard LC	Keyed LC to Standard SC
Aqua	<b>KLCDFP50GM03AQ</b>	<b>KLCDFPLC50GM03AQ</b>	<b>KLCDFPSC50GM03AQ</b>
Blue	<b>KLCDFP50GM03BL</b>	<b>KLCDFPLC50GM03BL</b>	<b>KLCDFPSC50GM03BL</b>
Brown	<b>KLCDFP50GM03BR</b>	<b>KLCDFPLC50GM03BR</b>	<b>KLCDFPSC50GM03BR</b>
Green	<b>KLCDFP50GM03GN</b>	<b>KLCDFPLC50GM03GN</b>	<b>KLCDFPSC50GM03GN</b>
Orange	<b>KLCDFP50GM03OR</b>	<b>KKLCDFPLC50GM03OR</b>	<b>KLCDFPSC50GM03OR</b>
Red	<b>KLCDFP50GM03RD</b>	<b>KLCDFPLC50GM03RD</b>	<b>KLCDFPSC50GM03RD</b>
Rose	<b>KLCDFP50GM03RO</b>	<b>KKLCDFPLC50GM03RO</b>	<b>KLCDFPSC50GM03RO</b>
Slate	<b>KLCDFP50GM03SL</b>	<b>KKLCDFPLC50GM03SL</b>	<b>KLCDFPSC50GM03SL</b>
Violet	<b>KLCDFP50GM03VI</b>	<b>KKLCDFPLC50GM03VI</b>	<b>KLCDFPSC50GM03VI</b>
Yellow	<b>KLCDFP50GM03YL</b>	<b>KLCDFPLC50GM03YL</b>	<b>KLCDFPSC50GM03YL</b>

5 meters, 50µm, OM3, aqua cable jacket

Housing Color	Keyed LC to Keyed LC	Keyed LC to Standard LC	Keyed LC to Standard SC
Aqua	<b>KLCDFP50GM05AQ</b>	<b>KLCDFPLC50GM05AQ</b>	<b>KLCDFPSC50GM05AQ</b>
Blue	<b>KLCDFP50GM05BL</b>	<b>KLCDFPLC50GM05BL</b>	<b>KLCDFPSC50GM05BL</b>
Brown	<b>KLCDFP50GM05BR</b>	<b>KLCDFPLC50GM05BR</b>	<b>KLCDFPSC50GM05BR</b>
Green	<b>KLCDFP50GM05GN</b>	<b>KLCDFPLC50GM05GN</b>	<b>KLCDFPSC50GM05GN</b>
Orange	<b>KLCDFP50GM05OR</b>	<b>KKLCDFPLC50GM05OR</b>	<b>KLCDFPSC50GM05OR</b>
Red	<b>KLCDFP50GM05RD</b>	<b>KLCDFPLC50GM05RD</b>	<b>KLCDFPSC50GM05RD</b>
Rose	<b>KLCDFP50GM05RO</b>	<b>KKLCDFPLC50GM05RO</b>	<b>KLCDFPSC50GM05RO</b>
Slate	<b>KLCDFP50GM05SL</b>	<b>KKLCDFPLC50GM05SL</b>	<b>KLCDFPSC50GM05SL</b>
Violet	<b>KLCDFP50GM05VI</b>	<b>KKLCDFPLC50GM05VI</b>	<b>KLCDFPSC50GM05VI</b>
Yellow	<b>KLCDFP50GM05YL</b>	<b>KLCDFPLC50GM05YL</b>	<b>KLCDFPSC50GM05YL</b>

10 meters, 50µm, OM3, aqua cable jacket

Housing Color	Keyed LC to Keyed LC	Keyed LC to Standard LC	Keyed LC to Standard SC
Aqua	<b>KLCDFP50GM10AQ</b>	<b>KLCDFPLC50GM10AQ</b>	<b>KLCDFPSC50GM10AQ</b>
Blue	<b>KLCDFP50GM10BL</b>	<b>KLCDFPLC50GM10BL</b>	<b>KLCDFPSC50GM10BL</b>
Brown	<b>KLCDFP50GM10BR</b>	<b>KLCDFPLC50GM10BR</b>	<b>KLCDFPSC50GM10BR</b>
Green	<b>KLCDFP50GM10GN</b>	<b>KLCDFPLC50GM10GN</b>	<b>KLCDFPSC50GM10GN</b>
Orange	<b>KLCDFP50GM10OR</b>	<b>KKLCDFPLC50GM10OR</b>	<b>KLCDFPSC50GM10OR</b>
Red	<b>KLCDFP50GM10RD</b>	<b>KLCDFPLC50GM10RD</b>	<b>KLCDFPSC50GM10RD</b>
Rose	<b>KLCDFP50GM10RO</b>	<b>KKLCDFPLC50GM10RO</b>	<b>KLCDFPSC50GM10RO</b>
Slate	<b>KLCDFP50GM10SL</b>	<b>KKLCDFPLC50GM10SL</b>	<b>KLCDFPSC50GM10SL</b>
Violet	<b>KLCDFP50GM10VI</b>	<b>KKLCDFPLC50GM10VI</b>	<b>KLCDFPSC50GM10VI</b>
Yellow	<b>KLCDFP50GM10YL</b>	<b>KLCDFPLC50GM10YL</b>	<b>KLCDFPSC50GM10YL</b>

Note: Individually bagged with dust caps installed and factory test data.



Keyed LC, OM3  
KLCDFPYLLC50GM01YL



Keyed LC, Flush Snap Fitting  
SFFKLCBLW



Keyed LC Adapter  
FAKLCDSC6GN

### Keyed LC OM3 Patch Cords for High Security Networks

50µm, OM3, yellow cable jacket

	Length (meters)		
	1m	2m	3m
Keyed LC to Standard LC	<b>KLCDFPYLLC50GM01YL</b>	<b>KLCDFPYLLC50GM02YL</b>	<b>KLCDFPYLLC50GM03YL</b>
Keyed LC to Standard SC	<b>KLCDFPYLSC50GM01YL</b>	<b>KLCDFPYLSC50GM02YL</b>	<b>KLCDFPYLSC50GM03YL</b>
	5m	10m	15m
Keyed LC to Standard LC	<b>KLCDFPYLLC50GM05YL</b>	<b>KLCDFPYLLC50GM10YL</b>	<b>KLCDFPYLLC50GM15YL</b>
Keyed LC to Standard SC	<b>KLCDFPYLSC50GM05YL</b>	<b>KLCDFPYLSC50GM10YL</b>	<b>KLCDFPYLSC50GM15YL</b>

Note: Individually bagged with dust caps installed and factory test data.

### Keyed LC to LC Hybrid Snap Fittings

Flush Snap Fitting, Keyed LC to Standard LC

Housing Color	Adapter Color	
	Red	Yellow
Ivory	<b>SFFKLCHRDEI</b>	<b>SFFKLCHYLEI</b>
Office White	<b>SFFKLCHRDOWN</b>	<b>SFFKLCHYLOW</b>
White	<b>SFFKLCHRDW</b>	<b>SFFKLCHYLW</b>

Note: Individually bagged with dust caps installed. Standard LC end is black on all hybrid adapters.

### Keyed LC Adapters

Flush Snap Fitting, Keyed LC

Adapter Color	Catalog No.
Aqua	<b>FAKLCDSC6AQ</b>
Blue	<b>FAKLCDSC6BL</b>
Brown	<b>FAKLCDSC6BR</b>
Green	<b>FAKLCDSC6GN</b>
Orange	<b>FAKLCDSC6OR</b>
Red	<b>FAKLCDSC6RD</b>
Rose	<b>FAKLCDSC6RO</b>
Slate	<b>FAKLCDSC6SL</b>
Violet	<b>FAKLCDSC6VI</b>
Yellow	<b>FAKLCDSC6YL</b>

Note: Individually bagged with dust caps installed.

Contact Hubbell Premise Wiring for other configurations and special lengths custom quoted and made to order. Keyed LC trunk assemblies also custom made to order.



**Keyed LC Snap Fittings**

Flush Snap Fitting

Adapter Color	Housing Color					
	Almond	Black	Gray	Ivory	Office White	White
Aqua	<b>SFFKLCAQAL</b>	<b>SFFKLCAQBK</b>	<b>SFFKLCAQGY</b>	<b>SFFKLCAQEI</b>	<b>SFFKLCAQOW</b>	<b>SFFKLCAQW</b>
Blue	<b>SFFKLCBLAL</b>	<b>SFFKLCBLBK</b>	<b>SFFKLCBLGY</b>	<b>SFFKLCBLEI</b>	<b>SFFKLCBLOW</b>	<b>SFFKLCBLW</b>
Brown	<b>SFFKLCBRAL</b>	<b>SFFKLCBRBK</b>	<b>SFFKLCBRGY</b>	<b>SFFKLCBREI</b>	<b>SFFKLCBROW</b>	<b>SFFKLCBRW</b>
Green	<b>SFFKLCGNAL</b>	<b>SFFKLCGNBK</b>	<b>SFFKLCNGY</b>	<b>SFFKLCGNEI</b>	<b>SFFKLCGNOW</b>	<b>SFFKLCGNW</b>
Orange	<b>SFFKLCORAL</b>	<b>SFFKLCORBK</b>	<b>SFFKLCORGY</b>	<b>SFFKLCOREI</b>	<b>SFFKLCOROW</b>	<b>SFFKLCORW</b>
Red	<b>SFFKLCRDAL</b>	<b>SFFKLCRDBK</b>	<b>SFFKLCRDGY</b>	<b>SFFKLCRDEI</b>	<b>SFFKLCRDOW</b>	<b>SFFKLCRDW</b>
Rose	<b>SFFKLCROAL</b>	<b>SFFKLCROBK</b>	<b>SFFKLCROGY</b>	<b>SFFKLCROEI</b>	<b>SFFKLCROOW</b>	<b>SFFKLCROW</b>
Slate	<b>SFFKLCSLAL</b>	<b>SFFKLCSLBK</b>	<b>SFFKLCSLGY</b>	<b>SFFKLCLEI</b>	<b>SFFKLCLOW</b>	<b>SFFKLCSLW</b>
Violet	<b>SFFKLCVIAL</b>	<b>SFFKLCVIBK</b>	<b>SFFKLCVIGY</b>	<b>SFFKLCVIEI</b>	<b>SFFKLCVIOW</b>	<b>SFFKLCVIW</b>
Yellow	<b>SFFKLCYLAL</b>	<b>SFFKLCYLBK</b>	<b>SFFKLCYLGY</b>	<b>SFFKLCYLEI</b>	<b>SFFKLCYLOW</b>	<b>SFFKLCYLW</b>

Snap Fitting

Adapter Color	Housing Color					
	Almond	Black	Gray	Ivory	Office White	White
Aqua	<b>SFKLCAQAL</b>	<b>SFKLCAQBK</b>	<b>SFKLCAQGY</b>	<b>SFKLCAQEI</b>	<b>SFKLCAQOW</b>	<b>SFKLCAQW</b>
Blue	<b>SFKLCBLAL</b>	<b>SFKLCBLBK</b>	<b>SFKLCBLGY</b>	<b>SFKLCBLEI</b>	<b>SFKLCBLOW</b>	<b>SFKLCBLW</b>
Brown	<b>SFKLCBRAL</b>	<b>SFKLCBRBK</b>	<b>SFKLCBRGY</b>	<b>SFKLCBREI</b>	<b>SFKLCBROW</b>	<b>SFKLCBRW</b>
Green	<b>SFKLCGNAL</b>	<b>SFKLCGNBK</b>	<b>SFKLCNGY</b>	<b>SFKLCGNEI</b>	<b>SFKLCGNOW</b>	<b>SFKLCGNW</b>
Orange	<b>SFKLCORAL</b>	<b>SFKLCORBK</b>	<b>SFKLCORGY</b>	<b>SFKLCOREI</b>	<b>SFKLCOROW</b>	<b>SFKLCORW</b>
Red	<b>SFKLCRDAL</b>	<b>SFKLCRDBK</b>	<b>SFKLCRDGY</b>	<b>SFKLCRDEI</b>	<b>SFKLCRDOW</b>	<b>SFKLCRDW</b>
Rose	<b>SFKLCROAL</b>	<b>SFKLCROBK</b>	<b>SFKLCROGY</b>	<b>SFKLCROEI</b>	<b>SFKLCROOW</b>	<b>SFKLCROW</b>
Slate	<b>SFKLCSLAL</b>	<b>SFKLCSLBK</b>	<b>SFKLCSLGY</b>	<b>SFKLCLEI</b>	<b>SFKLCLOW</b>	<b>SFKLCSLW</b>
Violet	<b>SFKLCVIAL</b>	<b>SFKLCVIBK</b>	<b>SFKLCVIGY</b>	<b>SFKLCVIEI</b>	<b>SFKLCVIOW</b>	<b>SFKLCVIW</b>
Yellow	<b>SFKLCYLAL</b>	<b>SFKLCYLBK</b>	<b>SFKLCYLGY</b>	<b>SFKLCYLEI</b>	<b>SFKLCYLOW</b>	<b>SFKLCYLW</b>

Note: Individually bagged with dust caps installed.

Contact Hubbell Premise Wiring for other configurations and special lengths custom quoted and made to order. Keyed LC trunk assemblies also custom made to order.



Keyed LC Duplex, 12-Port  
FSPKLCDS6GN



Keyed LC Duplex, 12-Port  
FSPKLCDS6RD



Keyed LC to MPO, 12-Port  
OCKLCD50GS12YL



Keyed LC to MPO, 12-Port  
OCKLC50GS12BL

### Keyed LC Adapter Panels

LC duplex, ceramic

Housing Color	12-Port	24-Port
Blue	<b>FSPKLCDS6BL</b>	<b>FSPKLCDS12BL</b>
Green	<b>FSPKLCDS6GN</b>	<b>FSPKLCDS12GN</b>
Red	<b>FSPKLCDS6RD</b>	<b>FSPKLCDS12RD</b>
Yellow	<b>FSPKLCDS6YL</b>	<b>FSPKLCDS12YL</b>

Note: Individually bagged with dust caps installed.

Special Housing Colors also available: **AQ** (Aqua), **BR** (Brown),

**OR** (Orange), **RO** (Rose), **SL** (Slate) and **VI** (Violet).

### Keyed LC to MTP Cassette Panels

Housing Color	62.5 μm, OM1		50 μm, OM2	
	12-Port	24-Port	12-Port	24-Port
Blue	<b>OCKLCD62S12BL</b>	<b>OCKLCD62S24BL</b>	<b>OCKLCD50S12BL</b>	<b>OCKLCD50S24BL</b>
Green	<b>OCKLCD62S12GN</b>	<b>OCKLCD62S24GN</b>	<b>OCKLCD50S12GN</b>	<b>OCKLCD50S24GN</b>
Red	<b>OCKLCD62S12RD</b>	<b>OCKLCD62S24RD</b>	<b>OCKLCD50S12RD</b>	<b>OCKLCD50S24RD</b>
Yellow	<b>OCKLCD62S12YL</b>	<b>OCKLCD62S24YL</b>	<b>OCKLCD50S12YL</b>	<b>OCKLCD50S24YL</b>

Housing Color	50 μm, OM3		SM, OS2	
	12-Port	24-Port	12-Port	24-Port
Blue	<b>OCKLCD50GS12BL</b>	<b>OCKLCD50GS24BL</b>	<b>OCKLCDSS12BL</b>	<b>OCKLCDSS24BL</b>
Green	<b>OCKLCD50GS12GN</b>	<b>OCKLCD50GS24GN</b>	<b>OCKLCDSS12GN</b>	<b>OCKLCDSS24GN</b>
Red	<b>OCKLCD50GS12RD</b>	<b>OCKLCD50GS24RD</b>	<b>OCKLCDSS12RD</b>	<b>OCKLCDSS24RD</b>
Yellow	<b>OCKLCD50GS12YL</b>	<b>OCKLCD50GS24YL</b>	<b>OCKLCDSS12YL</b>	<b>OCKLCDSS24YL</b>

Note: Individually bagged and boxed with dust caps installed and factory test data.

Accessories shown on page H3. Contact Hubbell Premise Wiring for the full line of keyed LC patch cords and custom MTP cords made to order.

Special Housing Colors also available: **AQ** (Aqua), **BR** (Brown), **OR** (Orange), **RO** (Rose), **SL** (Slate) and **VI** (Violet).

### Accessories

Description	Catalog No.
Keyed LC crimp tool, with dies	<b>OFCMTKLC1</b>
Fiber strip tool, 250/900/2.0/3.0mm	<b>OFSTRIP2</b>
Cleave tool, keyed LC connectors	<b>OFCLVKLC1</b>
LC duplex clip, black	<b>FCKLCDCLP12BK</b>
Fiber microscope, 200X	<b>OFSCOPE2</b>
Laser visual fault locator	<b>OFVFLKT1</b>

### Keyed LC Termination Tool Kit

Includes: crimp tool with dies, cleave tool and 1/4" wrench, cable holder and clamp, termination training CD-ROM, Kevlar® shears and cable splitter, strip tool (combination), cleaning and inspection guide, soft carrying case

Description	Catalog No.
Keyed LC termination tool kit, complete	<b>OFTKLCPK1</b>

Kevlar is a registered trademark of DuPont/E.I. du Pont de Nemours and Company.