

# SD Series

## 100 AMP - MULTI POSITION





| CATALOGUE #      | DESCRIPTION                                | METER POSITIONS | ENCLOSURE SIZE A X B X C                    | WEIGHT  |
|------------------|--|-----------------|---|---------|
| <b>SD220PW</b>   | 2 gang, 200 Amp main, 100 Amp per position | 2               | 15" x 12" x 5"                              | 20 lbs. |
| <b>SD320PW</b>   | 3 gang, 200 Amp main, 100 Amp per position | 3               | 22 <sup>1</sup> / <sub>2</sub> " x 12" x 5" | 28 lbs. |
| <b>SD420PW</b>   | 4 gang, 200 Amp main, 100 Amp per position | 4               | 30" x 12" x 5"                              | 36 lbs. |
| <b>SD520PW</b>   | 5 gang, 200 Amp main, 100 Amp per position | 5               | 37 <sup>1</sup> / <sub>2</sub> " x 12" x 5" | 44 lbs. |
| <b>SD620PW</b>   | 6 gang, 200 Amp main, 100 Amp per position | 6               | 45" x 12" x 5"                              | 52 lbs. |
| <b>SD220PWBC</b> | 1 - 3" KO in bottom                        | 2               | 17 <sup>1</sup> / <sub>2</sub> " x 15" x 5" | 23 lbs. |

- Factory bussed - 200 Amp Mains
- 2 - 6 position horizontal
- 4 Jaw meter sockets
- 100 Amp - 600 VOLTS per position
- CSA enclosure 3
- Approved conductor range:  
Line No. 6-250 MCM CU/AL  
Load No. 6-1/0 AWG CU/AL
- Approved for overhead or underground use

- Field adaptable accessories
- 5th Jaw at 9 O'clock - SXX503
- For overhead order "SXC" hub separate
- Add suffix "RH" for right hand entry

| KNOCKOUT CODE | CONDUIT SIZE  |
|---------------|---|
| <b>D</b>      | 1 <sup>1</sup> / <sub>4</sub> ", 1 <sup>1</sup> / <sub>2</sub> ", 2"                                  |
| <b>G</b>      | 1 <sup>1</sup> / <sub>4</sub> ", 1 <sup>1</sup> / <sub>2</sub> ", 2", 2 <sup>1</sup> / <sub>2</sub> " |
| <b>AA</b>     | 1 <sup>1</sup> / <sub>2</sub> "   |

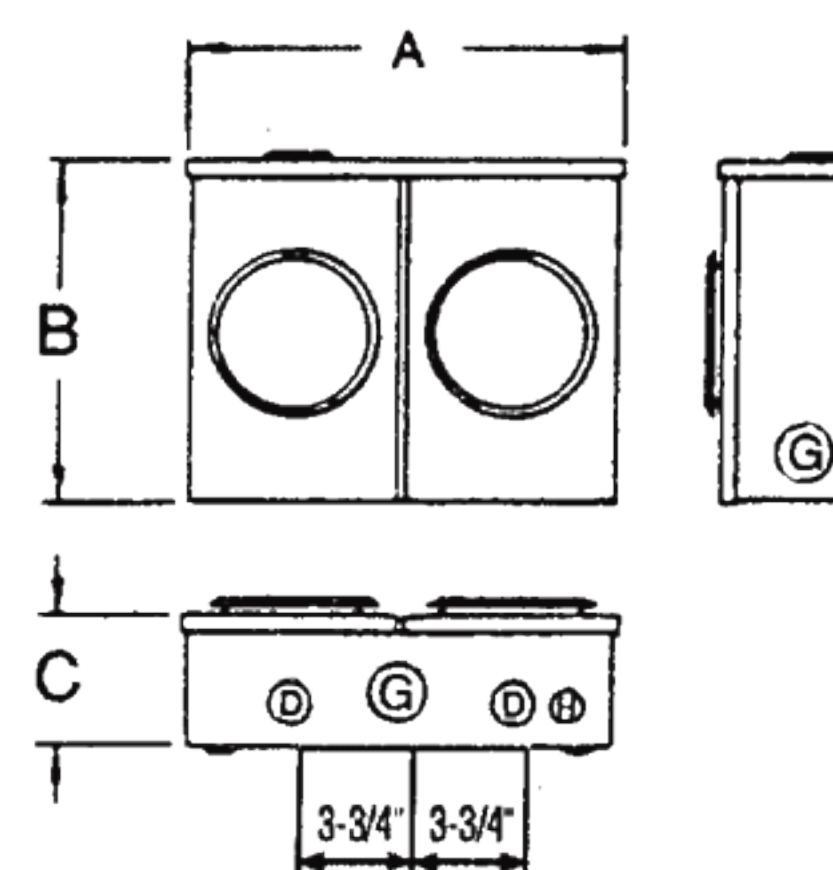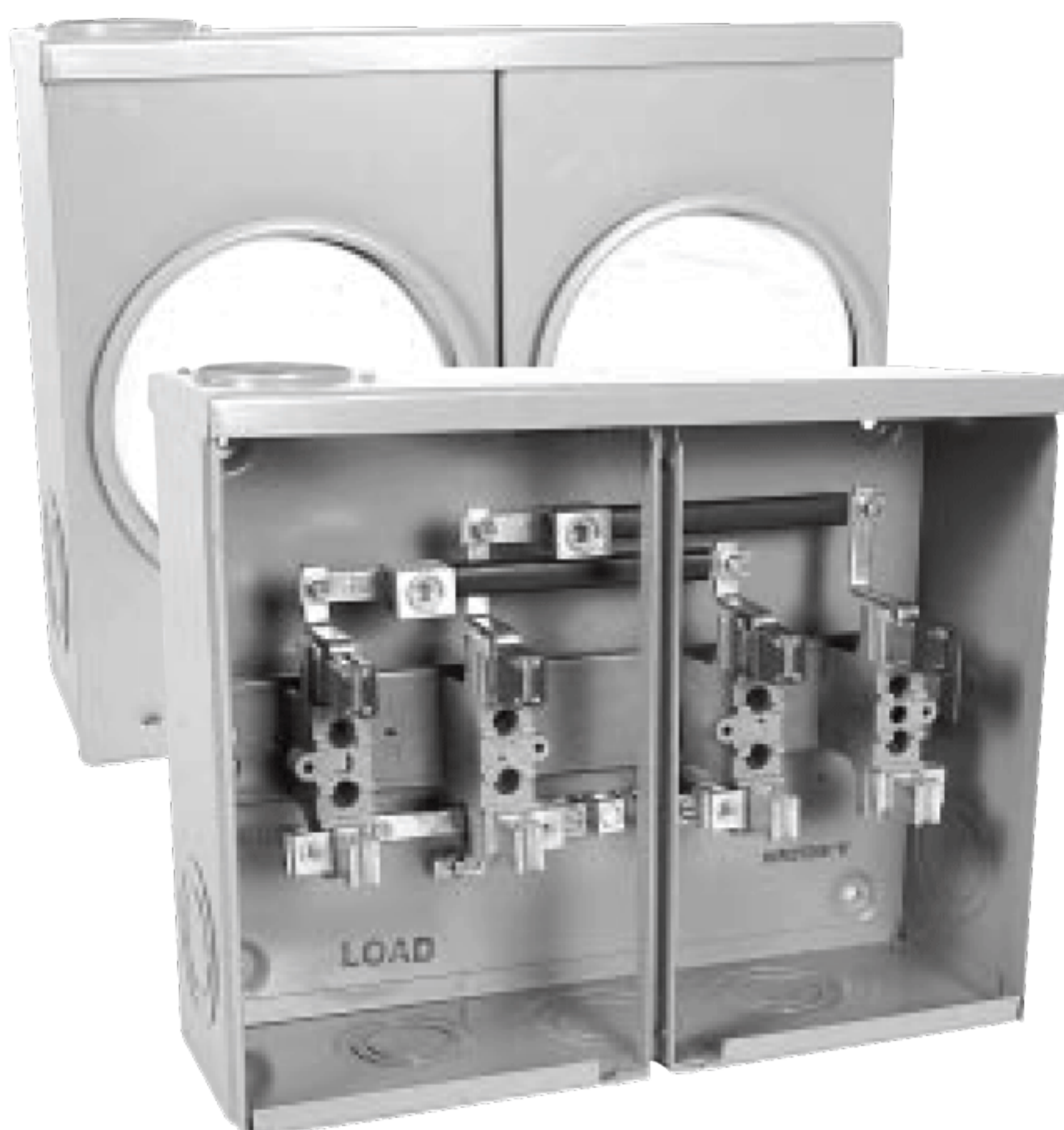

### SD220 Conversion Kit

To convert existing SD220PW to a two load single meter, meter socket ST911 - OH